


SmartRack Heavy-Duty Sliding Shelf (200 lbs / 90.7 kgs capacity; 28.3 in/719 mm Deep)

MODEL NUMBER: SRSHELF4PSLHD

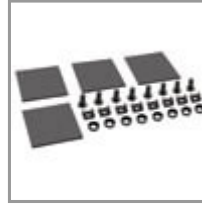

Highlights

- Heavy Duty Sliding Shelf supports up to 200 lbs (90.7 kgs)
- Designed for 4 post rack mounting
- 28.3 inch / 72 cm shelf depth
- Fully extendible shelf accommodates tower units, monitors, and other equipment
- Cold rolled steel with black finish
- Required mounting hardware included

Package Includes

- Shelf and mounting hardware

Description

Tripp Lite's SmartRack SRSHELF4PSLHD is a heavy duty sliding shelf for installation in rack cabinets. The SRSHELF4PSLHD has a 28.3 in. / 72 cm depth (29.5 in. / 74.9cm including handle) and can support up to 200 lbs (90.7 kgs). This fully extendible shelf can accommodate tower units, monitors and other equipment. It is designed for 4 post rack mounting and the required mounting hardware is included. Expandable mounting rails supports installation in racks with front to rear rail distances between 28 in. / 71cm minimum and 46 in. / 117cm maximum.

Features

- Heavy duty sliding shelf for installation in rack cabinets
- 28.3 in. / 72.4cm depth (29.5 in. / 74.9cm including handle)
- Supports up to 200 lbs (90.7 kgs)
- This fully extendible shelf can accommodate tower units, monitors and other equipment
- Designed for 4 post rack mounting and the required mounting hardware is included
- Expandable mounting rails supports installation in racks with front to rear rail distances between 28 in. / 71cm minimum and 46 in. / 117cm maximum

Specifications

OVERVIEW	
UPC Code	037332140654
Accessory Type	Rack Shelves
Accessory Class	Rack Accessories
PHYSICAL	
Shipping Dimensions (hwd / in.)	3.00 x 20.20 x 31.00



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

Shipping Dimensions (hwd / cm)	7.62 x 51.31 x 78.74
Shipping Weight (lbs.)	23.60
Shipping Weight (kg)	10.70
Unit Dimensions (hwd / in.)	2.36 x 18.98 x 30.11
Unit Dimensions (hwd / cm)	5.99 x 48.21 x 76.48
Unit Weight (lbs.)	24
Unit Weight (kg)	10.89
FEATURES & SPECIFICATIONS	
IP68 Rated	No
IP20 Rated	No
STANDARDS & COMPLIANCE	
Product Compliance	RoHS; EIA/ECA-310-E
WARRANTY	
Product Warranty Period (Worldwide)	5-year limited warranty

© 2022 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.

Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies:

<https://www.tripplite.com/products/product-certification-agencies>