


SmartRack 5U Low-Profile Vertical-Mount Switch-Depth Wall-Mount Structured Wiring Enclosure, Adjustable Equipment Brackets

MODEL NUMBER: SRWF10UMOD

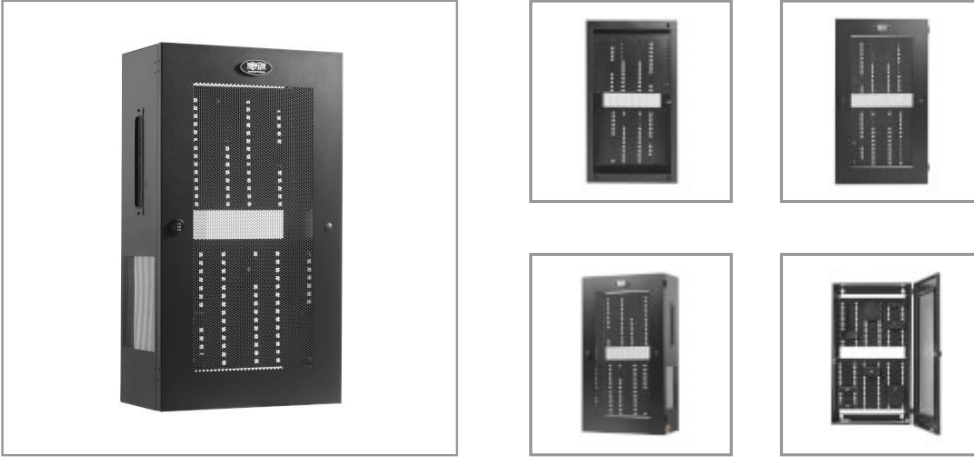

Secures and organizes rack equipment, as well as other equipment not typically stored in a rack, such as modems and routers.

Features

Rugged 5U Enclosure Ideal for Housing Regular Rack and Non-Rack Network Equipment This heavy-duty steel enclosure secures and houses both regular rack equipment and other equipment not typically mounted in an EIA-standard 19-inch rack. It is recommended for wiring closets, retail locations, classrooms, back offices and other areas with limited floor space where you need audio/video, voice and data infrastructure to be secure, organized and out of the way. Constructed with a durable black powder-coated finish, the vertical equipment rack has a maximum load capacity of 150 lbs (68 kgs).

Connect a Modem, Router and Other Non-Rack Equipment Inside the Enclosure Two pre-installed, but removable, 1U shelves with adjustable metal equipment brackets attach to the cabinet's square mounting holes. Just place your modem, router, firewall, switch, power block or other non-rack equipment on the brackets, and use the included thumbscrew to secure them to the rack. Four RJ45 jacks are built into the rack cabinet for connecting your devices to a network.

Low-Profile Design Accommodates Switches, Panels and Other Standard Rack Equipment Remove the two shelves to reveal two 5U areas for rack-mount equipment, one above the other, forming a total mounting space of 10U. The enclosure extends less than seven inches from the wall, while housing equipment up to 16.5 inches deep, including network switches and patch panels.

Keeps Important Equipment Secure and Easy to Access The reversible front door locks securely with a built-in combination lock to help prevent damage, tampering or theft. The vented cabinet allows air to flow freely and keep equipment cool. Brush-strip cable plates on both sides allow easy cable routing while preventing dust from entering.

Easy Enclosure Deployment and Equipment Installation The structured wiring cabinet comes fully assembled and ready to mount to the wall. The equipment brackets adjust easily and allow for flexibility in storing routers and other devices.

Meets Payment Card Industry Standards The SRWF10UMOD provides physical equipment and media security required for PCI DSS (Payment Card Industry Data Security Standard) compliance. This is essential for companies that process, store and/or transmit credit card information.

Highlights

- 2 removable 1U shelves with adjustable metal brackets secure non-rack equipment
- Houses 2 areas of 5U of rack equipment up to 16.5 in. deep (when 1U shelves are removed)
- Structured wiring cabinet extends less than 7 in. from wall with max capacity of 150 lbs (68 kgs)
- 4 built-in RJ45 jacks connect installed modem, router and other equipment to network
- Ships fully assembled for immediate installation in back office area or network closet

Applications

- Simplify the installation and maintenance of multiple network connections by storing equipment together
- Organize various A/V, voice and data network cable runs to cut down on cord clutter
- Protect valuable components from damage, tampering or theft to prevent costly downtime and equipment replacement

Package Includes

- SRWF10UMOD 5U Structured Wiring Enclosure
- (2) Pre-installed 1U shelves
- Adjustable equipment brackets
- Combination lock instructions

Specifications

| OVERVIEW | |
|-------------------------------------|-------------------------------------|
| UPC Code | 037332252876 |
| Device Compatibility | Network Switch; Patch Panel; Server |
| Rack Type | Small Enclosure |
| PHYSICAL | |
| Color | Black |
| Rack Height | 5U |
| Rack Depth | Shallow |
| Maximum Device Depth (cm) | 41.91 |
| Maximum Device Depth (in.) | 16.5 |
| Maximum Device Depth (mm) | 419 |
| Shipping Dimensions (hwd / in.) | 13.78 x 22.83 x 38.60 |
| Shipping Dimensions (hwd / cm) | 35.00 x 57.99 x 98.04 |
| Shipping Weight (lbs.) | 42.00 |
| Shipping Weight (kg) | 19.05 |
| Unit Dimensions (hwd / in.) | 35.560 x 20.000 x 10.700 |
| Unit Dimensions (hwd / cm) | 90.32 x 50.80 x 27.178 |
| Unit Weight (lbs.) | 42.0000 |
| Unit Weight (kg) | 19.05 |
| Weight Capacity - Stationary (kg) | 68 |
| Weight Capacity - Stationary (lbs.) | 150 |
| Number of Vertical Mounting Rails | 2 |
| FEATURES & SPECIFICATIONS | |
| Grounding Details | YES |
| Built-in Cable Management | No |
| Extra Wide | No |
| Pre-Installed Casters | No |
| STANDARDS & COMPLIANCE | |
| Product Compliance | RoHS; EIA/ECA-310-E |
| WARRANTY & SUPPORT | |
| Product Warranty Period (Worldwide) | 5-year limited warranty |



Powering Business Worldwide



1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.