


# 8U Wall-Mount Bracket for Small Switches and Patch Panels, Hinged

MODEL NUMBER: SRWO8UBRKT

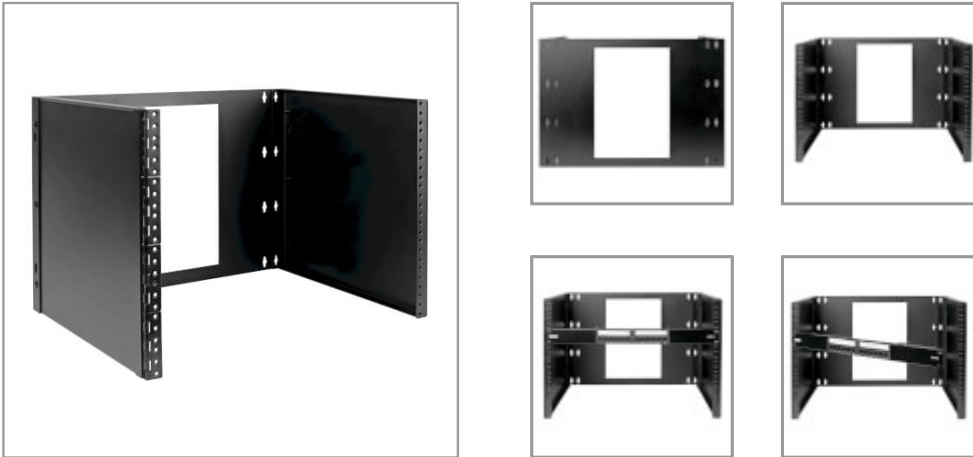

8U wall-mount bracket houses 19 in. rack equipment up to 14.75 in. deep, such as network switches and patch panels.

## Features

**Wall-Mount Bracket Is the Ideal Alternative to a Full-Size Rack Cabinet** If you don't have enough equipment to justify the purchase of a full-size rack or you don't have enough space for one, this SmartRack® bracket is the ideal alternative for your home office or small business. Made from heavy-duty laser-cut 14-gauge cold-rolled steel with a durable black powder-coated finish, this 8U wall-mount bracket easily attaches to the wall of your back office or closet with the included mounting screws.

**Hinged Bracket Supports EIA-Standard 19 in. Rack Equipment** The SRWO8UBRKT houses 8U of compatible 19-inch rack components, including EIA-compliant switches and patch panels by any manufacturer, up to 14.75 inches deep. The 8U wall-mount bracket is hinged to allow open, unrestricted access to equipment and cabling from either the left or right side. Maximum load capacity is 35 pounds (15.9 kg)

**Rear Cutout Eases Cable Installations** The wall-mount bracket features an open cutout in the rear that allows for cable feeds through the wall to streamline installations and reduce cable clutter. The laser-cut metal bracket's surfaces and edges are smooth to reduce wear on cable jackets and patch panel equipment.

**Easy Mounting with the Included Hardware** Rear keyhole mounting slots are 16 inches apart to align with standard wall-stud placement. Stamped horizontal reinforcement ribs on the back of the bracket provided extra stability. The 8U wall-mount bracket comes with mounting screws for installing the bracket and rack equipment.

**5-Year Warranty and Environmentally Responsible Design** The SRWO8UBRKT comes with a 5-year warranty. It's manufactured in compliance with strict RoHS specifications.

## Highlights

- Ideal for home office or small business with no floor space for full-size rack cabinet
- Steel construction with smooth laser-cut edges that won't damage cable jackets
- Supports universal mounting for left- or right-hinging to allow easy cable access
- Keyhole mounting slots spaced 16 in. apart to match standard wall-stud placement
- Includes hardware for immediate mounting of bracket and equipment

## Applications

- Mounting standard 19 in. rack equipment in a closet or back room too small to contain a full-size rack
- Mounting 8U of patch panels and network switches that don't need to be secured in a rack cabinet

## Package Includes

- SRWO8UBRKT 8U Wall-Mount Bracket for Small Switches and Patch Panels, Hinged
- (20) 12-24 mounting screws
- Assembly instruction sheet

## Specifications

OVERVIEW	
UPC Code	037332205629



Powering Business Worldwide



Device Compatibility	Patch Panel
Rack Type	Bracket
Accessory Type	Mounting Accessories
<b>PHYSICAL</b>	
Color	Black
Rack Height	8U
Rack Depth	Shallow
Maximum Device Depth (cm)	38.10
Maximum Device Depth (in.)	15
Maximum Device Depth (mm)	381
Shipping Dimensions (hwd / in.)	3.94 x 21.46 x 17.13
Shipping Dimensions (hwd / cm)	10.01 x 54.51 x 43.51
Shipping Weight (lbs.)	18.18
Shipping Weight (kg)	8.25
Unit Dimensions (hwd / in.)	0.000 x 0.000 x 0.000
Unit Dimensions (hwd / cm)	35.56 x 50.04 x 38.1
Unit Weight (lbs.)	11.00
Unit Weight (kg)	4.99
Weight Capacity - Stationary (kg)	16
Weight Capacity - Stationary (lbs.)	35
Number of Vertical Mounting Rails	2
Assembly Required	Yes
<b>FEATURES &amp; SPECIFICATIONS</b>	
Built-in Cable Management	No
Extra Wide	No
Pre-Installed Casters	No
<b>STANDARDS &amp; COMPLIANCE</b>	
Product Certifications	IEC 60297-3
Product Compliance	RoHS; EIA/ECA-310-E
<b>WARRANTY &amp; SUPPORT</b>	
Product Warranty Period (Worldwide)	5-year limited warranty



*Powering Business Worldwide*



1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.  
Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.