


SUPDMB710HW - UPS Accessory - Hardwire PDU Module

MODEL NUMBER: SUPDMB710HW

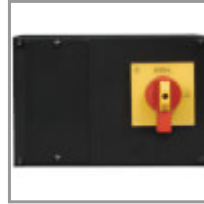

Description

The SUPDMB710HW hardwire input/output PDU module converts compatible SmartOnline Hot-Swappable Modular UPS Systems (models SU10000RT3U and SU8000RT3U) to a totally hardwired solution. Easy quick-connect terminal block allows installation of hardwire distribution module in minutes. Can accept input voltages of 208 or 240 VAC single phase power. Detachable hardwire module with manual bypass switch allows for effortless UPS maintenance without the need to power down connected loads and re-wire input/output connections.

Features

- Converts compatible SmartOnline Hot-Swappable Modular UPS Systems (models SU10000RT3U and SU8000RT3U) to a totally hardwired solution
- Easy quick-connect terminal block allows installation of hardwire distribution module in minutes
- Can accept input voltages of 208 or 240 VAC single phase power
- Detachable hardwire module with manual bypass switch allows for effortless UPS maintenance without the need to power down connected loads and re-wire input/output connections

Specifications

OVERVIEW	
UPC Code	037332136237
Accessory Type	PDU Module
Accessory Class	UPS Accessories
INPUT	
Nominal Input Voltage(s) Supported	208V AC; 240V AC
Input Connection Type	Hardwire
Voltage Compatibility (VAC)	208; 240

Highlights

- Converts compatible SmartOnline Hot-Swappable Modular UPS systems to hardwire input and output
- For use with SU10000RT3U and SU8000RT3U UPS Systems
- Easy quick-connect terminal block installation
- Manual bypass switch supports hot-swap UPS power module replacement

System Requirements

- Use with SU10000RT3U and SU8000RT3U SmartOnline Hot-Swappable Modular UPS Systems

Package Includes

- Hardwire PDU with Bypass Switch
- Mounting Hardware
- Owner's Manual



Powering Business Worldwide



OUTPUT	
Frequency Compatibility	50 / 60 Hz
Output Receptacles	Hardwire
Output Nominal Voltage	208/240V
PHYSICAL	
Material of Construction	Steel
Shipping Dimensions (hwd / in.)	10.60 x 7.80 x 9.10
Shipping Dimensions (hwd / cm)	26.92 x 19.81 x 23.11
Shipping Weight (lbs.)	9.80
Shipping Weight (kg)	4.45
Unit Dimensions (hwd / in.)	5.250 x 7.500 x 6.500
Unit Dimensions (hwd / cm)	13.3 x 19.1 x 16.5
Unit Weight (lbs.)	4.6
Unit Weight (kg)	2.09
FEATURES & SPECIFICATIONS	
IP68 Rated	No
IP20 Rated	No
STANDARDS & COMPLIANCE	
Product Certifications	CSA (Canada); UL 1778
Product Compliance	RoHS; CE (Europe); REACH; FCC (USA)
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	2-year limited warranty

1000 Eaton Boulevard
 Cleveland, OH 44122
 United States
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.
 Eaton is a registered trademark. All other trademarks
 are the property of their respective owners.