


## Protect It! 4-Outlet Home Computer Surge Protector Strip, 4-ft Cord, 450 Joules

MODEL NUMBER: TLP404

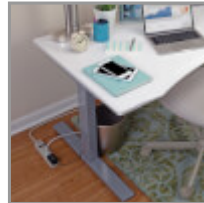

### Highlights

- 4 outlets / 4-ft. cord
- 450 joule rating

### Package Includes

- TLP404 surge suppressor
- Instruction manual with warranty information

### Description

Tripp Lite's TLP404 offers economical AC surge suppression for protection of workstations, desktop PCs, telecom systems and other sensitive electronics. Built-in AC surge suppression shields connected equipment from damage and performance problems due to transient surges. TLP404 offers 4 total outlets, 4 foot cord and diagnostic LED to warn of suppressor damage. AC suppression rated at 450 joules shields equipment from surges and line noise. Attractive light gray suppressor housing with keyhole mounting tabs and 1 designated transformer plug outlet offers convenient protection of desktop computer equipment and accessories. \$1,000 Ultimate Lifetime Insurance (U.S., Canada, and Puerto Rico only).

PLUG/OUTLETS: Input: NEMA5-15P/Output: 4 NEMA5-15R/4-ft. AC line cord

ELECTRICAL: 120V AC, 50/60Hz, 15A (Requires NEMA5-15R wall receptacle)

FORMAT: Corded multi-outlet strip with 1 transformer spaced outlet

SUPPRESSION: AC: 150V RMS Clamping/450 joules/500V UL1449 3rd Edition

### Features

- 4 outlets
- 4-ft. cord
- Surge suppression rating: 450 joules
- EMI/RFI noise filtering
- 15 amp resettable circuit breaker
- Diagnostic LED confirms surge protection status
- Includes full normal mode (H-N) and common mode (N-G/H-G) line surge suppression
- Can accommodate 1 large transformer plug without covering remaining outlets, 2 total transformers
- Keyhole supports for wall mounting
- Non-Lighted power switch
- \$1,000 Ultimate Lifetime Insurance (U.S., Canada, and Puerto Rico only)



- Automatic shutoff permanently cuts power to outlets if protection circuit is incapacitated, preventing equipment damage and indicating replacement is required

## Specifications

| OVERVIEW                           |  |
|------------------------------------|--|
| UPC Code                           | 037332119131   |
| OUTPUT                             |  |
| Frequency Compatibility            | 50 / 60 Hz   |
| Output Receptacles                 | (4) 5-15R  |
| Output (Watts)                     | 1800   |
| Circuit Breaker (amps)             | 15   |
| Overload Protection                | 15A resettable combo switch / circuit breaker                        |
| Transformer Accommodation          | (2) Yes  |
| Outlet Orientation                 | Single row of 4 outlets  |
| Right-Angle Outlets                | No   |
| INPUT                              |  |
| Nominal Input Voltage(s) Supported | 120V AC  |
| Recommended Electrical Service     | 120V (110-125V)  |
| Input Cord Length (ft.)            | 4  |
| Input Cord Length (m)              | 1.22   |
| Input Cord Gauge Type              | 14 gauge; SJT  |
| Voltage Compatibility (VAC)        | 120  |
| Maximum Surge Amps                 | 22500  |
| Input Plug Type                    | NEMA 5-15P   |
| Right-Angle Plug                   | No   |
| Integrated Cord Clip               | No   |
| USER INTERFACE, ALERTS & CONTROLS  |  |
| Diagnostic LED(s)                  | Yes  |
| Switches                           | Combination AC circuit breaker and 2 position on/off power switch    |
| Diagnostic LED Details             | Built-in LED confirms suppressor "protection present" (green) status |
| SURGE / NOISE SUPPRESSION          |  |



|  |  |
|--|--|
| AC Suppression Joule Rating                          | 450  |
| AC Suppression Response Time                         | < 1 ns   |
| Protection Modes                                     | Includes full normal mode (H-N) and common mode (N-G / H-G) line surge suppression |
| Clamping Voltage (RMS)                               | 150  |
| UL1449 Let Through Rating                            | 500V - UL Verified   |
| EMI / RFI Filtering                                  | Yes  |
| Auto Shut-Off  | Yes  |
| <b>DATALINE SURGE SUPPRESSION</b>                    |  |
| Telephone/DSL Protection                             | No   |
| Cable (Coax) Protection                              | No   |
| Network (Ethernet) Protection                        | No   |
| <b>PHYSICAL</b>                                      |  |
| Shipping Dimensions (hwd / in.)                      | 11.90 x 2.00 x 5.00  |
| Shipping Dimensions (hwd / cm)                       | 30.23 x 5.08 x 12.70   |
| Shipping Weight (lbs.)                               | 0.85   |
| Shipping Weight (kg)                                 | 0.39   |
| Unit Dimensions (hwd / in.)                          | 1.2 x 1.85 x 8.1   |
| Unit Dimensions (hwd / cm)                           | 3 x 4.7 x 20.6   |
| Unit Weight (lbs.)                                   | 1  |
| Unit Weight (kg)                                     | 0.45   |
| Material of Construction                             | Plastic  |
| Integrated Keyhole Mounting Slots                    | Yes  |
| Housing Color  | Light Gray   |
| Receptacle Color                                     | Light gray   |
| Color (AC Line Cord)                                 | Light Gray   |
| Color  | Light Gray   |
| Outlets Measurement (Center to Center)               | 28.6mm   |
| Keyhole Slot Mounting Measurement (Center to Center) | Distance between slots = 57.5mm; Distance between slot height = 26mm               |
| Anti-Microbial Protected                             | No   |
| <b>CERTIFICATIONS</b>                                |  |
| UL1449 3rd Edition (AC Suppression)                  | UL1449 3rd Edition   |
| UL1363 (Power Tap)                                   | UL1363   |



**Tripp Lite**  
1111 W. 35th Street  
Chicago, IL 60609 USA  
Telephone: 773.869.1234  
[www.tripplite.com](http://www.tripplite.com)

|  |  |
|--|--|
| Canada   | cUL  |
| Approvals  | Exceeds IEEE 587 category A&B specifications   |
| <b>WARRANTY</b>  |  |
| Product Warranty Period (Worldwide)                        | Lifetime limited warranty  |
| Connected Equipment Insurance (U.S., Canada & Puerto Rico) | \$1,000 <a class="insuranceLink" href="//www.tripplite.com/support/insurance-policy">Ultimate Lifetime Insurance</a> |

© 2019 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies: <https://www.tripplite.com/products/product-certification-agencies>