


## Protect It! 6-Outlet Clamp-Mount Surge Protector, 6 ft. (1.83 m) Cord, 2100 Joules, 2 x USB Charging ports (2.1A total)

MODEL NUMBER: TLP606DMUSB

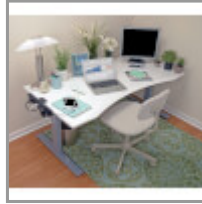

### Highlights

- 6 outlet / 6-ft. cord
- 2100 joule rating
- 2.1 amp dual port USB charger
- Clamps to attach to desk, workbench or table
- Clamp .39" - 1.38"

### Package Includes

- TLP606DMUSB surge suppressor
- Instruction manual with warranty information

### Description

The TLP606DMUSB offers economical AC surge suppression for protection of workstations, desktop PCs, telecom systems and other sensitive electronics. Built-in AC surge suppression shields connected equipment from damage and performance problems due to transient surges. USB charging ports offer fast charging for smartphones, tablets, MP3 players and other portable devices. TLP606DMUSB offers six total outlets, a six-foot (1.8-meter) cord, two USB charging ports and a diagnostic LED to warn of suppressor damage. AC suppression rated at 2100 joules shields equipment from surges and line noise. This matte black surge suppressor has clamps that attach to the side of the desk, workbench or table. Two knobs easily clamp to desk for better accessibility to four standard and two adapter-spaced plugs. \$40,000 Ultimate Lifetime Insurance (U.S., Canada, and Puerto Rico only).

### Features

- 6 outlets
- 6-ft. (1.83 m) cord
- 2 USB charging ports - 2.1 amp total
- Surge suppression rating: 2100 joules
- Clamps for attaching to desk, workbench or table. Clamp adjusts from .39 to 1.38"
- EMI/RFI noise filtering
- 15 amp resettable circuit breaker
- Green protection LED
- Includes full normal mode (H-N) and common mode (N-G/H-G) line surge suppression
- Can accommodate 2 large transformer plug without covering remaining outlets.
- 2 knobs to clamping to desk Lighted power switch
- \$40,000 Ultimate Lifetime Insurance (U.S., Canada, and Puerto Rico only)
- Automatic shutoff permanently cuts power to outlets if protection circuit is incapacitated, preventing equipment damage and indicating replacement is required

## Specifications

<b>OVERVIEW</b>	
UPC Code	037332180292
Product Type	Surge Protector
Charging Form Factor	Strip
Device Compatibility	Phone; Tablet; Amazon Kindle
<b>INPUT</b>	
Nominal Input Voltage(s) Supported	120V AC
Recommended Electrical Service	120V (110-125V)
Input Cord Gauge Type	14 gauge; SJT
Input Cord Gauge (AWG)	14
Voltage Compatibility (VAC)	120
Maximum Surge Amps	35500
Input Plug Type	NEMA 5-15P
Input Cord Details	SJT
Input Cord Length (ft.)	6
Right-Angle Plug	No
Input Cord Length (m)	1.83
Integrated Cord Clip	No
<b>OUTPUT</b>	
Frequency Compatibility	50 / 60 Hz
Output Receptacles	(6) 5-15R
Circuit Breaker (amps)	15
Overload Protection	15A resettable illuminated combo switch / circuit breaker
Transformer Accommodation	(3) Yes
Outlet Orientation	Single row of 6 outlets
Right-Angle Outlets	No
<b>USER INTERFACE, ALERTS &amp; CONTROLS</b>	
Diagnostic LED(s)	Yes
Switches	Combination AC circuit breaker and 2 position red illuminated on/off power switch
Diagnostic LED Details	Built-in LED confirms suppressor "protection present" (green) status
<b>CHARGING</b>	
Number of Charging Ports	2
Total Charging Watts	10.5



Powering Business Worldwide



Charging Method	USB
Charging Port Type	USB A (FEMALE)
Charging Ports / Amps	(2) 2.1A
Overcharge Protection	No
<b>SURGE / NOISE SUPPRESSION</b>	
AC Suppression Joule Rating	2100
AC Suppression Response Time	< 1 ns
Protection Modes	Includes full normal mode (H-N) and common mode (N-G / H-G) line suppression
UL1449 Let Through Rating	400V
EMI / RFI Filtering	Yes
Automatic Shut-Off	Yes
<b>DATALINE SURGE SUPPRESSION</b>	
Cable (Coax) Protection	No
Network (Ethernet) Protection	No
Telephone/DSL Protection	No
<b>PHYSICAL</b>	
Material of Construction	Plastic
Power Cord Color	Black
Housing Color	Black
Mounting Holes or Slots	No
Receptacle Color	Black
Shipping Dimensions (hwd / in.)	3.00 x 5.60 x 16.50
Shipping Dimensions (hwd / cm)	7.62 x 14.22 x 41.91
Shipping Weight (lbs.)	1.80
Shipping Weight (kg)	0.82
Unit Dimensions (hwd / in.)	2.890 x 13.600 x 2.870
Unit Weight (lbs.)	1.5
Unit Weight (kg)	0.68
<b>FEATURES &amp; SPECIFICATIONS</b>	
Rotatable Outlets	No
Antimicrobial	No
GaN Technology	No
<b>STANDARDS &amp; COMPLIANCE</b>	



Powering Business Worldwide



Product Certifications	CAN/CSA-C22.2 No. 269.3 (Canada); CAN/CSA-C22.2 No. 308 (Canada); CAN/CSA-C22.2 No. 42 (Canada); cUL Listed; UL 1449; UL 498; UL 1363; UL Listed
Product Compliance	RoHS
<b>WARRANTY &amp; SUPPORT</b>	
Product Warranty Period (Worldwide)	Lifetime limited warranty
Connected Equipment Insurance (U.S., Canada & Puerto Rico)	\$40,000 & <a href="https://tripplite.eaton.com/support/insurance-policy">Ultimate Lifetime Insurance</a>

1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.  
Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.