


TAA-Compliant Protect It! 6-Outlet Surge Protector, 6-ft Cord, 790 Joules, Diagnostic LED

MODEL NUMBER: TLP606TAA

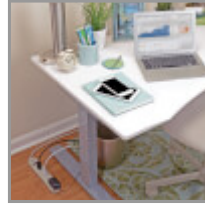

Highlights

- Compliant with the Federal Trade Agreements Act (TAA) for GSA Schedule purchases
- 6 outlet / 6-ft. cord
- 790 joule rating

Package Includes

- TLP606TAA surge suppressor
- Instruction manual with warranty information

Description

Tripp Lite's TLP606TAA is compliant with the Federal Trade Agreements Act (TAA) for GSA Schedule purchases. It offers economical AC surge suppression for protection of workstations, desktop PCs, telecom systems and other sensitive electronics. Built-in AC surge suppression shields connected equipment from damage and performance problems due to transient surges. Automatic shutoff permanently cuts power to outlets if protection circuit is incapacitated, preventing equipment damage and indicating replacement is required. TLP606TAA offers 6 total outlets, 6 foot cord and diagnostic LED to warn of suppressor damage. AC suppression rated at 790 joules shields equipment from surges and line noise. Attractive white suppressor housing with keyhole mounting tabs offer convenient protection of desktop computer equipment and accessories. \$20,000 Ultimate Lifetime Insurance (U.S., Canada, and Puerto Rico only).

PLUG/OUTLETS: Input: NEMA5-15P/Output: 6 NEMA5-15R/6-ft. AC line cord

ELECTRICAL: 120V AC, 60Hz, 15A (Requires NEMA5-15R wall receptacle)

FORMAT: Corded multi-outlet strip with 1 transformer spaced outlet

SUPPRESSION: AC: 150V RMS Clamping/790 joules/330V UL1449 3RD EDITION

Features

- Compliant with the Federal Trade Agreements Act (TAA) for GSA Schedule purchases
- 6 outlets
- 6-ft. cord
- Surge suppression rating: 790 joules
- EMI/RFI noise filtering
- 15 amp resettable circuit breaker
- Automatic shutoff permanently cuts power to outlets if protection circuit is incapacitated, preventing equipment damage and indicating replacement is required
- Green protection LED
- Includes full normal mode (H-N) and common mode (N-G/H-G) line surge suppression
- Can accommodate 1 large transformer plug without covering remaining outlets, 3 total transformers
- Keyhole support for wall mounting



- Lighted power switch
- \$20,000 Ultimate Lifetime Insurance (U.S., Canada, and Puerto Rico only)

Specifications

OVERVIEW	
UPC Code	037332159250
INPUT	
Nominal Input Voltage(s) Supported	120V AC
Recommended Electrical Service	120V (110-125V)
Input Cord Gauge Type	14 gauge; SJT
Voltage Compatibility (VAC)	120
Input Plug Type	NEMA 5-15P
Input Cord Length (ft.)	6
Right-Angle Plug	No
Input Cord Length (m)	1.83
Integrated Cord Clip	No
OUTPUT	
Frequency Compatibility	60 Hz
Output (Watts)	1800
Output Receptacles	(6) 5-15R
Circuit Breaker (amps)	15
Overload Protection	15A resettable illuminated combo switch / circuit breaker
Transformer Accommodation	(2) Yes
Outlet Orientation	Single row of 6 outlets
Right-Angle Outlets	No
USER INTERFACE, ALERTS & CONTROLS	
Diagnostic LED(s)	Yes
Switches	Combination AC circuit breaker and 2 position red illuminated on/off power switch
Diagnostic LED Details	Built-in LED confirms suppressor "protection present" (green) status
SURGE / NOISE SUPPRESSION	
AC Suppression Joule Rating	790



AC Suppression Response Time	< 1 ns
Protection Modes	Includes full normal mode (H-N) and common mode (N-G / H-G) line surge suppression
Clamping Voltage (RMS)	150
UL1449 Let Through Rating	400V - UL Verified
EMI / RFI Filtering	Yes
Automatic Shut-Off	No
DATALINE SURGE SUPPRESSION	
Telephone/DSL Protection	No
Cable (Coax) Protection	No
Network (Ethernet) Protection	No
PHYSICAL	
Antimicrobial Coating	No
Color	White
Color (AC Line Cord)	Light Gray
Integrated Keyhole Mounting Slots	Yes
Material of Construction	Plastic
Receptacle Color	Light gray
Shipping Dimensions (hwd / cm)	11.68 x 3.81 x 30.73
Shipping Dimensions (hwd / in.)	4.60 x 1.50 x 12.10
Shipping Weight (kg)	0.50
Shipping Weight (lbs.)	1.10
Unit Dimensions (hwd / cm)	3.20 x 4.19 x 26.67
Unit Dimensions (hwd / in.)	1.26 x 1.65 x 10.5
Unit Weight (kg)	0.48
Unit Weight (lbs.)	1.05
SPECIAL FEATURES	
Rotatable Outlets	No
STANDARDS & COMPLIANCE	
Canada	cUL
Approvals	Exceeds IEEE 587 category A&B specifications
UL1449 3rd Edition (AC Suppression)	UL1449 3RD EDITION
UL1363 (Power Tap)	UL1363



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

WARRANTY	
Product Warranty Period (Worldwide)	Lifetime limited warranty
Connected Equipment Insurance (U.S., Canada & Puerto Rico)	\$20,000 Ultimate Lifetime Insurance

© 2020 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies: <https://www.tripplite.com/products/product-certification-agencies>