


Protect It! 6-Outlet Surge Protector, 6 ft. (1.83 m) Cord, 990 Joules, 2 x USB Charging ports (2.1A), Gray Housing

MODEL NUMBER: TLP606USB

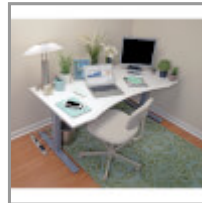

Highlights

- 6 outlet / 6-ft. cord
- 990 joule rating
- 2.1 amp dual port USB charger

Package Includes

- TLP606USB surge suppressor
- Instruction manual with warranty information

Description

Tripp Lite's TLP606USB offers economical AC surge suppression for protection of workstations, desktop PCs, telecom systems and other sensitive electronics. Built-in AC surge suppression shields connected equipment from damage and performance problems due to transient surges. USB charging ports offer fast charging for smartphones, tablets, MP3 players and other portable devices. TLP606USB offers 6 total outlets, 6-ft. (1.83 m) cord, 2 USB charging ports and diagnostic LED to warn of suppressor damage. AC suppression rated at 990 joules shields equipment from surges and line noise. Attractive cool grey suppressor housing with keyhole mounting tabs offer convenient protection of desktop computer equipment and accessories. \$20,000 Ultimate Lifetime Insurance (U.S., Canada, and Puerto Rico only).

PLUG/OUTLETS: Input: NEMA5-15P/Output: 6 NEMA5-15R/6-ft. (1.83 m) AC line cord

ELECTRICAL: 120V AC, 50/60Hz, 15A (Requires NEMA5-15R wall receptacle)

FORMAT: Corded multi-outlet strip with 1 transformer spaced outlet

SUPPRESSION: AC: 150V RMS Clamping/990 joules/400V UL1449 3rd Edition

Features

- 6 outlets
- 6-ft. (1.83 m) cord
- 2 USB charging ports - 2.1 amp total
- Surge suppression rating: 990 joules
- EMI/RFI noise filtering
- 15 amp resettable circuit breaker
- Green protection LED
- Includes full normal mode (H-N) and common mode (N-G/H-G) line surge suppression
- Can accommodate 1 large transformer plug without covering remaining outlets, 3 total transformers
- Keyhole support for wall mounting



- Lighted power switch
- \$20,000 Ultimate Lifetime Insurance (U.S., Canada, and Puerto Rico only)
- Automatic shutoff permanently cuts power to outlets if protection circuit is incapacitated, preventing equipment damage and indicating replacement is required

Specifications

OVERVIEW	
UPC Code	037332180285
Product Type	Surge Protector
Charging Form Factor	Strip
Device Compatibility	Phone; Tablet; Amazon Kindle
INPUT	
Nominal Input Voltage(s) Supported	120V AC
Recommended Electrical Service	120V (110-125V)
Input Cord Gauge Type	14 gauge; SJT
Voltage Compatibility (VAC)	120
Maximum Surge Amps	35500
Input Plug Type	NEMA 5-15P
Input Cord Length (ft.)	6
Right-Angle Plug	No
Input Cord Length (m)	1.83
Integrated Cord Clip	No
OUTPUT	
Frequency Compatibility	50 / 60 Hz
Output (Watts)	1800
Output Receptacles	(6) 5-15R
Circuit Breaker (amps)	15
Overload Protection	15A resettable illuminated combo switch / circuit breaker
Transformer Accommodation	(2) Yes
Outlet Orientation	Single row of 6 outlets
Right-Angle Outlets	No
USER INTERFACE, ALERTS & CONTROLS	
Diagnostic LED(s)	Yes



Switches	Combination AC circuit breaker and 2 position red illuminated on/off power switch
Diagnostic LED Details	Built-in LED confirms suppressor "protection present" (green) status
SURGE / NOISE SUPPRESSION	
AC Suppression Joule Rating	990
AC Suppression Response Time	< 1 ns
Protection Modes	Includes full normal mode (H-N) and common mode (N-G / H-G) line surge suppression
UL1449 Let Through Rating	400V
EMI / RFI Filtering	Yes
Automatic Shut-Off	Yes
CHARGING	
Number of Charging Ports	2
Charging Method	USB
Charging Port Type	USB A (FEMALE)
Charging Ports / Amps	(2) 2.1A
DATALINE SURGE SUPPRESSION	
Cable (Coax) Protection	No
Network (Ethernet) Protection	No
Telephone/DSL Protection	No
PHYSICAL	
Material of Construction	Plastic
Antimicrobial	No
Power Cord Color	Light Gray
Housing Color	Light Gray
Mounting Holes or Slots	Yes
Outlets Measurement (Center to Center)	28.5mm
Receptacle Color	Light gray
Shipping Dimensions (hwd / cm)	4.83 x 14.48 x 37.34
Shipping Dimensions (hwd / in.)	1.90 x 5.70 x 14.70
Shipping Weight (kg)	0.59
Shipping Weight (lbs.)	1.30
Unit Dimensions (hwd / cm)	3.18 x 4.75 x 33.02
Unit Dimensions (hwd / in.)	1.25 x 1.87 x 13



FEATURES & SPECIFICATIONS	
Rotatable Outlets	No
STANDARDS & COMPLIANCE	
Canada	cUL
Approvals	Exceeds IEEE 587 category A&B specifications
UL1449 3rd Edition (AC Suppression)	UL1449 3rd EDITION
UL1363 (Power Tap)	UL1363
WARRANTY	
Product Warranty Period (Worldwide)	Lifetime limited warranty
Connected Equipment Insurance (U.S., Canada & Puerto Rico)	\$20,000 Ultimate Lifetime Insurance

© 2021 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies: <https://www.tripplite.com/products/product-certification-agencies>