


USB 2.0 A to B Cable (M/M), Beige, 10 ft. (3.05 m)

MODEL NUMBER: U022-010-BE

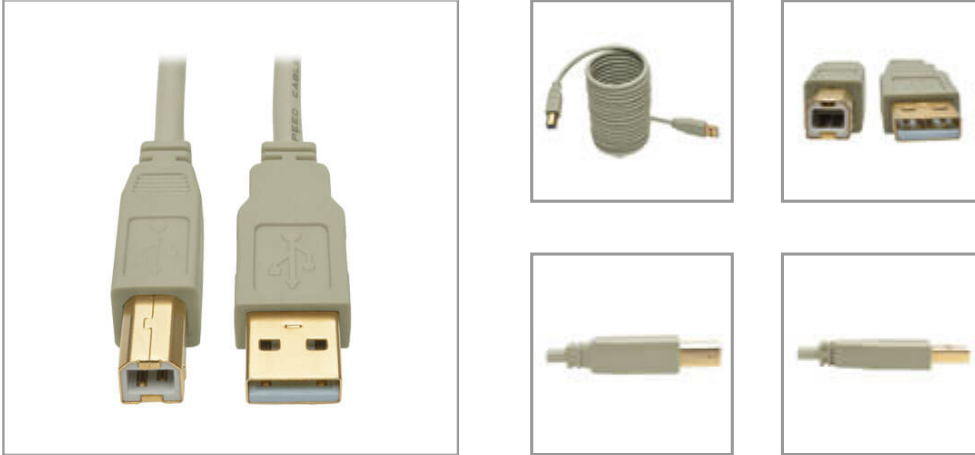

Connects high-speed USB 2.0 peripherals with a USB-B port to your computer, laptop or other compatible USB-A device. Recommended for printers and scanners.

Description

The U022-010-BE USB 2.0 Hi-Speed A/B Cable (M/M) connects your computer, laptop or other compatible USB-A device to a USB-B peripheral, such as printers and scanners. This 10-ft. (3.05 m) cable supports data transfer rates up to 480 Mbps for both low- and high-speed devices, including multimedia applications.

Premium foil and braid shielding delivers reliable, error-free signal quality and protection from EMI/RFI interference. Molded gold-plated connectors with gold-plated contacts ensure excellent conductivity. Integral strain relief ensures the cable and connectors last a long time. A rugged PVC jacket protects twisted 28 AWG data lines and 24 AWG power lines.

Features

Connect Your USB Type-B Peripherals to Your Computer

- Recommended for printers and scanners
- Supports data transfer rates up to 480 Mbps
- Backward compatible with earlier USB generations

First-Rate Construction for Superior Signal Transfer

- Premium foil and braid shielding for EMI/RFI noise protection
- Molded nickel-plated connectors for optimal signal quality
- Integral strain relief for long life
- Twisted 28/24 AWG data/power lines
- Flexible PVC jacket easy to install in tight spaces

Specifications

OVERVIEW	
UPC Code	037332198792
Technology	USB 2.0 (High Speed)

Highlights

- Supports data transfer rates up to 480 Mbps
- Premium foil and braid shielding
- Gold-plated connectors and contacts
- Twisted 28/24 AWG data/power lines
- Backward compatible with earlier USB generations

Package Includes

- U022-010-BE USB 2.0 Hi-Speed A/B Cable (M/M), Beige, 10-ft. (3.05 m)



Powering Business Worldwide

TRIPP LITE
SERIES

Cable Type	Passive
CONNECTIONS	
Side A - Connector 1	USB A (MALE)
Side B - Connector 1	USB B (MALE)
Connector Style	Straight
PHYSICAL	
Cable Jacket Color	Beige
Cable Length (ft.)	10
Cable Length (m)	3.05
Shipping Dimensions (hwd / in.)	0.50 x 6.70 x 8.00
Shipping Dimensions (hwd / cm)	1.27 x 17.02 x 20.32
Shipping Weight (lbs.)	0.30
Shipping Weight (kg)	0.14
Unit Dimensions (hwd / in.)	0.500 x 6.700 x 8.000
ENVIRONMENTAL	
Operating Temperature Range	14° to 122°F (-10° to 50°C)
Storage Temperature Range	5° to 140°F (-15° to 60°C)
Operating Humidity Range	0% to 90% RH, Non-Condensing
Storage Humidity Range	0% to 90% RH, Non-Condensing
FEATURES & SPECIFICATIONS	
USB Specification	USB 2.0 (up to 480 Mbps)
STANDARDS & COMPLIANCE	
Product Compliance	RoHS
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	Lifetime limited warranty

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2025 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.