


## USB 2.0 Panel Mount Cable, 5-Pin Motherboard IDC to USB Type-A (F/F), 3 ft.

MODEL NUMBER: **U024-003-5P-PM**

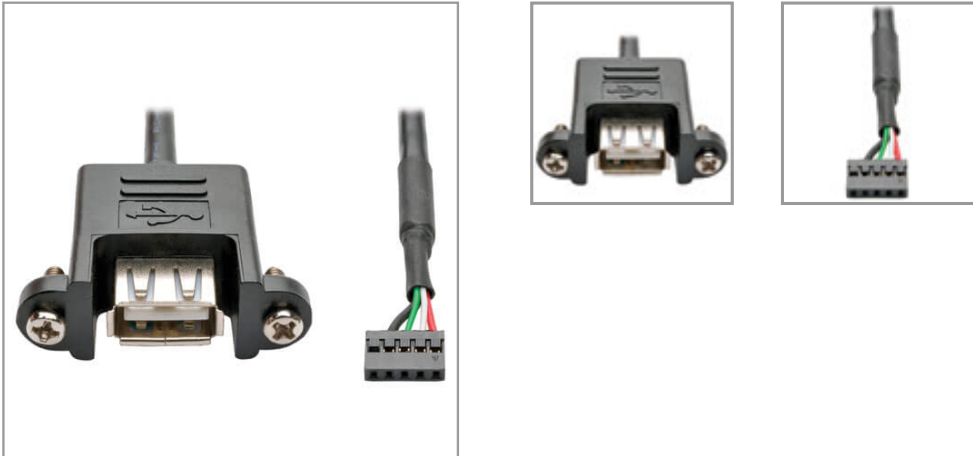

Connects your computer's motherboard to a panel-mounted USB-A port that can be installed in a computer, booth, kiosk or podium.

### Description

The U024-003-5P-PM USB 2.0 Hi-Speed Panel Mount Cable connects to a computer's motherboard to add a panel-mounted USB Type-A port. In addition to the front panel of a computer, the USB-A port can be installed in a trade show booth, retail kiosk or teacher's or lecturer's podium, allowing you to conveniently connect a thumb drive or other USB device. The PCB header terminates on almost any five-pin motherboard.

The three-foot cable supports data transfer rates up to 480 Mbps and is backward compatible with previous USB generations. Gold-plated contacts resist corrosion and ensure optimal signal transfer. Premium double-shielded cables with aluminum braid and aluminum Mylar foil feature twisted 28 AWG data lines and 24 AWG power lines. PVC jacket with molded connectors and integral strain relief provides durability and long life. Mounting screws included.

### Features

**Adds a Panel-Mounted USB-A Port** Allows convenient USB access from a trade show booth, retail kiosk or lecturer's podium  
**5-pin PCB header** terminates on computer's motherboard  
 Supports data transfer speeds up to 480 Mbps  
 Backward compatible with previous USB generations

**Premium Construction for Premium Performance** Corrosion-resistant gold-plated contacts for optimal signal transfer  
 Fully molded construction with strain relief for durability and long life  
 Flexible PVC jacket easy to install in tight spaces  
 Double shielding with aluminum braid, aluminum Mylar foil and twisted 28/24 AWG data/power lines  
 Mounting screws included

## Specifications

OVERVIEW	
UPC Code	037332191113
INPUT	

### Highlights

- Supports data transfer speeds up to 480 Mbps
- 5-pin PCB header connects to computer's motherboard
- USB-A port attaches with included screws
- Corrosion-resistant gold-plated contacts
- Backward compatible with previous USB generations

### System Requirements

- Computer with 5-pin motherboard connector

### Package Includes

- U024-003-5P-PM USB 2.0 Hi-Speed Panel Mount Cable, 3 ft.
- (2) Mounting screws



Cable Length (ft.)	3
Cable Length (m)	0.9
<b>PHYSICAL</b>	
Color	Black
Shipping Dimensions (hwd / cm)	17.78 x 22.86 x 1.27
Shipping Dimensions (hwd / in.)	7.00 x 9.00 x 0.50
Shipping Weight (kg)	0.05
Shipping Weight (lbs.)	0.12
<b>CONNECTIONS</b>	
Side A - Connector 1	5 PIN IDC (FEMALE)
Side B - Connector 1	USB A (FEMALE)
<b>FEATURES &amp; SPECIFICATIONS</b>	
Technology	USB 2.0 (High Speed); USB
<b>STANDARDS &amp; COMPLIANCE</b>	
Certifications	RoHS compliant
<b>WARRANTY</b>	
Product Warranty Period (Worldwide)	Lifetime limited warranty

© 2020 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.

Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies:

<https://www.tripplite.com/products/product-certification-agencies>