


USB 2.0 A Female to USB Motherboard 4-PIN IDC Header Cable, 6-in. (15.24 cm)

MODEL NUMBER: U024-06N-IDC

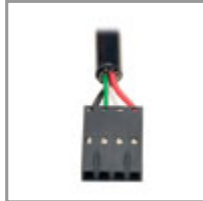

Highlights

- 6-inch USB "A" Female to 4-pin IDC motherboard connector
- Plug and Play

Package Includes

- 6" USB 2.0 A Female to USB Motherboard 4-PIN IDC Header Cable

Connect an internal USB device to a USB 4-pin motherboard header connector

Features

- 6-inch USB 2.0 Female to USB Motherboard 4-pin IDC Header cable
- USB 2.0 rated (480mbps)
- Allows motherboard connection for internal USB devices

Specifications

OVERVIEW	
UPC Code	037332185457
Technology	USB 2.0 (High Speed)
Cable Type	Passive
CONNECTIONS	
Side A - Connector 1	4 PIN (INTERNAL)
Side B - Connector 1	USB A (FEMALE)
Connector Style	Straight
PHYSICAL	
Cable Jacket Color	Black
Cable Length (ft.)	0.5
Cable Length (m)	0.15
Shipping Dimensions (hwd / in.)	9.00 x 7.00 x 0.50



Powering Business Worldwide

TRIPP LITE
SERIES

Shipping Dimensions (hwd / cm)	22.86 x 17.78 x 1.27
Shipping Weight (lbs.)	0.03
Shipping Weight (kg)	0.01
ENVIRONMENTAL	
Operating Temperature Range	14° to 122°F (-10° to 50°C)
Storage Temperature Range	5° to 140°F (-15° to 60°C)
Operating Humidity Range	0% to 90% RH, Non-Condensing
Storage Humidity Range	0% to 88% RH, Non-Condensing
STANDARDS & COMPLIANCE	
Product Compliance	RoHS
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	Lifetime limited warranty

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.