


## USB-C Cable (M/M) - USB 2.0, 5A (100W) Rated, 3 ft. (0.91 m)

MODEL NUMBER: **U040-003-C-5A**

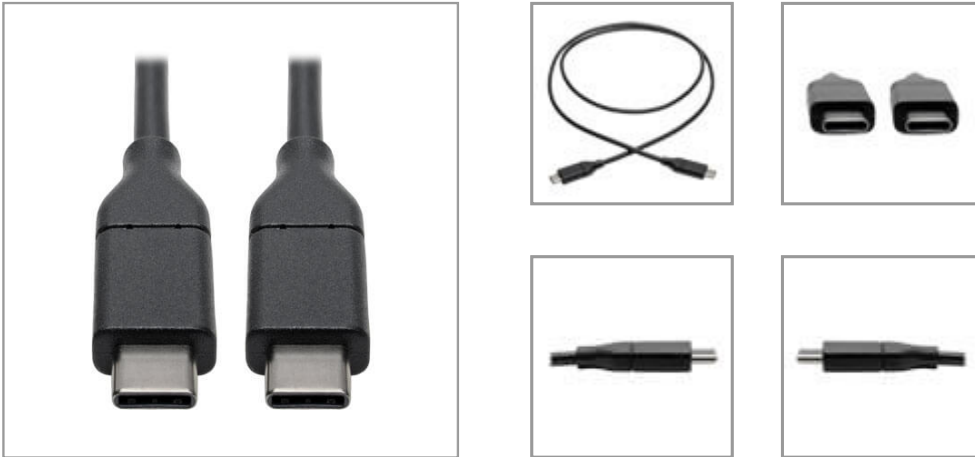

USB-C cable provides up to 20V 5A (100W) of power—more than enough to charge large-capacity mobile devices, such as the MacBook Pro®. Also connects smartphones, computers, wall chargers and other USB-C devices.

### Features

#### Connects 2 USB-C Devices

- Power output up to 20V 5A (100W) for fast-charging large mobile devices, such as MacBook Pro
- Recommended for connecting smartphones, tablets, computers, wall chargers and other USB-C devices
- Supports USB 2.0 data transfer speeds up to 480 Mbps
- Backward compatible with previous USB generations

#### Reversible USB-C Male Connectors

- Fumble-free reversible plugs connect in either direction to ensure fast, easy connection every time

#### Premium Construction

- Molded connectors and gold-plated contacts for maximum conductivity and minimum data loss
- Foil and braid shielding delivers reliable, error-free signal quality and EMI/RFI protection

## Specifications

OVERVIEW	
UPC Code	037332202864
Technology	USB 2.0 (High Speed)
Cable Type	Passive
CONNECTIONS	

### Highlights

- Power output up to 5A for fast-charging large mobile devices
- Supports data transfer speeds up to 480 Mbps
- Reversible USB-C plugs on both ends for fumble-free connection
- Integral strain relief protects against stress and cracking
- Backward compatible with previous USB generations

### System Requirements

- Devices with USB-C female connectors

### Package Includes

- U040-003-C-5A USB 2.0 Hi-Speed Cable with 5A Rating, USB-C to USB-C (M/M), 3 ft.



Powering Business Worldwide

TRIPP LITE  
SERIES

Side A - Connector 1	USB C (MALE)
Side B - Connector 1	USB C (MALE)
Connector Plating	Nickel
Contact Plating	Gold
Connector Style	Straight
<b>PHYSICAL</b>	
Material of Construction	PVC
Cable Jacket Color	Black
Cable Jacket Rating	VW-1
Cable Outer Diameter (OD)	3.8MM
Cable Length (ft.)	3
Cable Length (m)	0.91
Cable Length (in.)	36
Cable Length (cm)	91.4
Shipping Dimensions (hwd / in.)	0.50 x 6.00 x 9.00
Shipping Dimensions (hwd / cm)	1.27 x 15.24 x 22.86
Shipping Weight (lbs.)	0.20
Shipping Weight (kg)	0.09
<b>ENVIRONMENTAL</b>	
Operating Temperature Range	14° to 140°F (-10° to 60°C)
Storage Temperature Range	-4° to 185°F (-20° to 85°C)
Relative Humidity	10% to 85%, Non-Condensing
<b>FEATURES &amp; SPECIFICATIONS</b>	
USB Specification	USB 2.0 (up to 480 Mbps)
<b>STANDARDS &amp; COMPLIANCE</b>	
Product Compliance	RoHS; CE (Europe); REACH; FCC (USA)
<b>WARRANTY &amp; SUPPORT</b>	
Product Warranty Period (Worldwide)	3-year limited warranty

1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.  
Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.