


USB-C to USB-C Charging Cable (M/M) - 60W PD Charging, Slim Braided Jacket, White, 1 m (3.3 ft.), 2 Pack

MODEL NUMBER: **U040-B03-C-2**

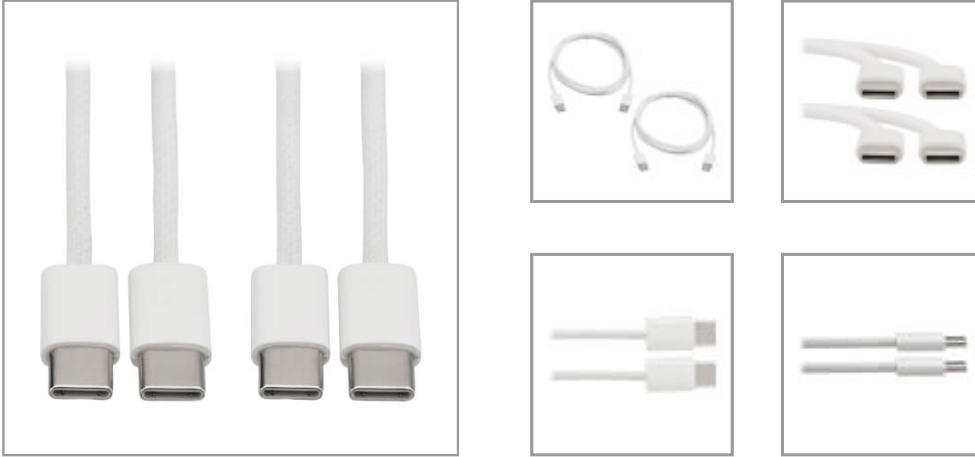

Connects to a compatible USB-C charger for syncing and high-speed charging of smartphones, tablets and other mobile devices.

Features

USB-C Cables Connect Devices for Charging or Transferring Data

This two-pack of USB-C charging cables (M/M) is compatible with any device with a USB-C port, including smartphones, tablets, handheld game consoles, e-readers, and laptops that accept 60W Power Delivery (PD) charging. Compatible devices include the MacBook Pro/Air, Chromebook, Windows laptop, Apple iPad Pro, iPad mini 6, iPhone 17, Samsung Galaxy S25, Google Pixel, Nintendo Switch 2 and Steam Deck.

Tested to Ensure Fast Charging and Reliable Data Transfer

The PD charging cable provides power output up to 20V 3A (60W) for fast-charging, syncing and powering the latest smartphones and tablets. It also supports USB 2.0 data transfer rates up to 480 Mbps. The USB Type-C to USB Type-C cable is backward compatible with previous USB generations, allowing you to use it with older devices. **Note:** *The U040-B03-C-2 cables are only intended for charging and data transfer purposes and cannot be used to transmit video.*

Built for Strength and Longevity with Premium Materials

The slim cables are made of a lightweight silicone core for flexibility and tangle resistance. A sleek braided jacket provides enhanced strength. The cables have been extensively tested with over 10,000 insertion/extraction cycles, 4,000 bend cycles and 500 flex cycles without performance loss.

USB-IF Certification Ensures Rigorous Testing and Top-of-the-Line Performance

The USB-C charge cables meet the high standards of USB-IF (USB Implementers Forum, Inc.), a non-profit organization consisting of companies that developed the USB specification. Receiving USB-IF certification means the U040-B03-C-2 meets the industry's highest environmental, mechanical and electrical standards. The cables operate with your USB-C devices with top efficiency and safety.

Specifications

OVERVIEW

Highlights

- Certified by USB-IF to ensure highest-grade construction and performance
- Supports USB 2.0 speeds up to 480 Mbps for syncing devices and transferring data
- Power Delivery cable provides 20V 3A (60W) for fast-charging large-capacity devices
- Slim silicon cable is covered by durable braiding and is tangle-resistant and lightweight
- Works with all USB-C devices including iPhone 17, iPad mini 6 and Samsung Galaxy S25

System Requirements

- Compatible with smartphones, tablets, laptops, handheld game consoles and other devices that can be charged via USB-C PD charging up to 60W (20V 3A)
- Requires a compatible USB-C power adapter or USB-C charging device with an available port

Package Includes

(2) USB-C to USB-C Charging Cables, M/M, White, 1 m (3.3 ft.)



Powering Business Worldwide

TRIPP LITE
SERIES

UPC Code	037332300683
Device Compatibility	Amazon Kindle; Chromebook; Laptop; Phone; Tablet; Video Game System
Technology	USB 2.0 (High Speed); USB
Country/Region	Global
Cable Type	Passive
INPUT	
Maximum Input Amps	3
Maximum Input Watts	60
POWER	
USB Power Delivery (PD) Charging Support	Yes
USB Power Delivery (PD) Charging Specification	20V/3A; 60W
CONNECTIONS	
Side A - Connector 1	USB C (MALE)
Side B - Connector 1	USB C (MALE)
Connector Plating	Nickel
Contact Plating	Gold
Connector Style	Straight
CHARGING	
Total Charging Amps	3
Total Charging Watts	60
Compatible Devices	Chromebook; Laptop; Portable Speaker; Smartphone; Tablet; Video Game Console
PHYSICAL	
Color	White
Material of Construction	PC/ABS + TPE
Cable Jacket Color	White
Connector Color	White
Cable Jacket Material	Silicone; TPE
Cable Jacket Rating	VW-1
Cable Outer Diameter (OD)	2.8MM
Wire Gauge (AWG)	25/32
Cable Length (ft.)	3.3
Cable Length (m)	1.01



Powering Business Worldwide

TRIPP LITE
SERIES

Cable Length (in.)	39.4
Cable Length (cm)	100
Shipping Dimensions (hwd / in.)	9.00 x 7.00 x 0.50
Shipping Dimensions (hwd / cm)	22.86 x 17.78 x 1.27
Shipping Weight (lbs.)	0.09
Shipping Weight (kg)	0.04
Unit Dimensions (hwd / in.)	9.000 x 7.000 x 0.500
Unit Packaging Type	Polybag
ENVIRONMENTAL	
Operating Temperature Range	14° to 140°F (-10° to 60°C)
Storage Temperature Range	-4° to 140°F (-20° to 60°C)
Relative Humidity	10% to 85%, Non-Condensing
Operating Humidity Range	10% to 85%, Non-Condensing
Storage Humidity Range	10% to 85%, Non-Condensing
Power Provided to Connected Device(s)	60W (20V/3A)
FEATURES & SPECIFICATIONS	
USB Specification	USB 2.0 (up to 480 Mbps)
STANDARDS & COMPLIANCE	
Product Certifications	USB-IF
Product Compliance	RoHS; CE (Europe); REACH; FCC (USA)
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	Lifetime limited warranty

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2026 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.