


4-Port USB Charging Station, 5V 6A/30W USB Charger Output, UK Version

MODEL NUMBER: **U280-004-UK**

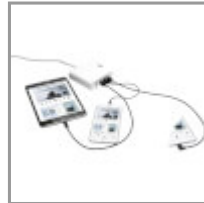

Charges up to 4 electronic devices at the same time via USB connection. Ideal for quick-charging tablets, cell phones, laptops and other mobile devices.

Description

Whether you're at home or in the office, Tripp Lite's U280-004-UK 4-Port USB Charging Station provides enough ports and power to keep your devices at 100% capacity. No more peering behind furniture to find an available outlet or unplugging one device to charge another. You can charge up to four tablets, cell phones, laptops and other devices at the same time. The U280-004-UK doesn't require a computer, so you can take it anywhere AC power is available.

The U280-004-UK simultaneously provides up to 5V, 1.5A of power per port at maximum capacity. Each individual port supports USB Battery Charging (BC) v1.2 and is capable of delivering up to 5V, 2.4A, which is enough for charging even battery-intensive devices like the Apple® iPad®.

To charge your USB devices, simply connect the 1.2-meter power cord's BS-1363 plug to an AC power outlet, and connect your devices to the available USB ports. The unit protects against overheating, overcurrent and overcharging—in fact, it stops charging as soon as your devices' batteries are at full capacity. A front LED indicates the unit is turned on and receiving AC power.

Features

Charges Up to 4 Devices at the Same Time Ideal for charging tablets, cell phones, laptops and other devices at home or work Connect devices to unit's USB ports for proficient charging Functions anywhere AC power is available—no computer required

Provides Plenty of Juice for Charging Each individual port supports USB Battery Charging (BC) v1.2 and is capable of delivering up to 5V, 2.4A, enough for charging battery-intensive devices like the Apple iPad Simultaneously provides up to 5V, 1.5A of power per port at maximum capacity Protects against overheating, overcurrent and overcharging

Easy to Use 1.2 m power cord with BS-1363 plug connects to AC outlet Front LED indicates when unit is turned on and receiving AC power

Highlights

- 5V, 2.4A per port for charging battery-intensive devices
- 5V, 1.5A per port simultaneously when at maximum capacity
- All four ports support USB Battery Charging (BC) specification v1.2
- Internal dual-voltage power supply with BS-1363 plug
- Protects against overheating, overcurrent and overcharging
- No computer required

Package Includes

- U280-004-UK 4-Port USB Charging Station
- C7 to BS-1363 power cord, 1.2 m
- Quick Start Guide

Specifications

OVERVIEW



UPC Code	037332192080
Product Type	Plug in Charger
Charging Form Factor	Charging Hub
Device Compatibility	Phone; Tablet; Amazon Kindle
Technology	USB
INPUT	
Nominal Input Voltage(s) Supported	120V AC; 230V AC
Plug Type	C7 to BS-1363
Voltage Compatibility (VAC)	100; 110; 120; 125; 127; 200; 208; 220; 230; 240
Input Frequency	50/60Hz
Input Plug Type	NEMA 1-15P (NON-POLARIZED)
Input Current	120V (0.8A) / 230V (0.4A)
OUTPUT	
Overload Protection	Yes
USER INTERFACE, ALERTS & CONTROLS	
LED Indicators	Blue (Power)
CHARGING	
Charging Ports / Amps	(4) 2.4A
Number of Charging Ports	4
Total Charging Amps	6A
Charging Method	USB
Charging Ports Detail	USB-A: 5V/6A
Charging Port Type	(4) USB A (FEMALE)
Charging Method Detail	5V - 1.5A (7W)
PHYSICAL	
Color	White
Shipping Dimensions (hwd / cm)	5.08 x 13.21 x 18.54
Shipping Dimensions (hwd / in.)	2.00 x 5.20 x 7.30
Shipping Weight (kg)	0.39
Shipping Weight (lbs.)	0.87
Unit Dimensions (hwd / cm)	3.1 x 10.6 x 10.1
Unit Dimensions (hwd / in.)	1.2 x 4.2 x 4.0



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

Unit Packaging Type	Box
Unit Weight (kg)	0.21
Unit Weight (lbs.)	0.46
ENVIRONMENTAL	
Operating Temperature Range	41°F to 95°F / 5°C to 35°C
Storage Temperature Range	-4°F to 122°F / -20°C to 50°C
Relative Humidity	20% to 80% RH, Non-Condensing
Power Consumption (Watts)	38
CONNECTIONS	
Ports	4
Side A - Connector 1	BS1363 UK PLUG
Side B - Connector 1	(4) USB A (FEMALE)
SPECIAL FEATURES	
Overcurrent Protection	Yes
Overvoltage Protection	Yes
GaN Technology	No
STANDARDS & COMPLIANCE	
Certifications	Tested to FCC, Reach, RoHs
Approvals	UL Listed
WARRANTY	
Product Warranty Period (Worldwide)	2-year limited warranty

© 2021 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.

Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies:

<https://www.tripplite.com/products/product-certification-agencies>