


65W USB-C 2-Port GaN Wall Charger - Ultra Slim, PD 3.0 Fast Charging, White

MODEL NUMBER: U280-WF2-65C2-G

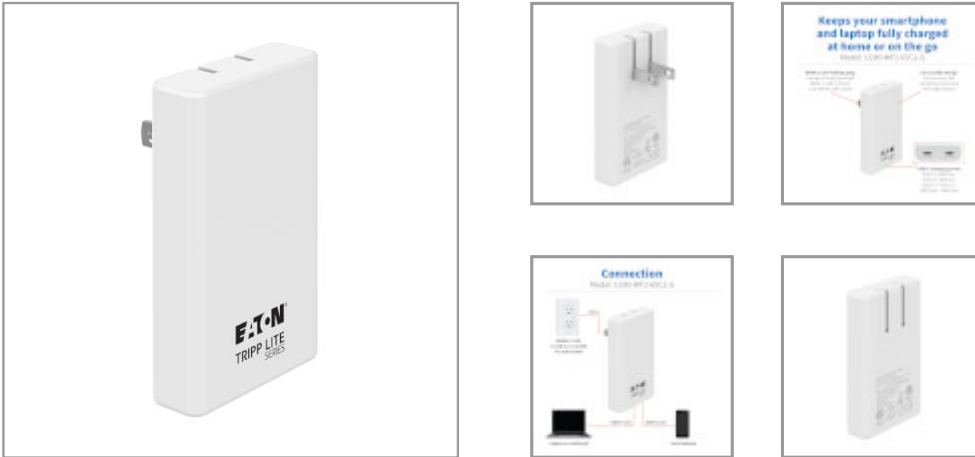

Travel-sized USB-C charger provides up to 65W to quickly and efficiently charge your smartphone and laptop at home or on the move.

Features

2-Port Charger Gets Your Mobile Devices Ready to Use, Wherever You Are

This USB-C wall charger quickly and safely charges your mobile devices, including smartphones, tablets, laptops, handheld gaming consoles, earbuds, smartwatches and e-readers. It plugs into any standard NEMA 1-15R, 5-15R or 5-15/20R AC wall outlet, making the U280-WF2-65C2-G compatible with most offices, homes, hotel rooms, dorms, classrooms, airports and cafes.

Supports Maximum Power Capacity of 65W for Charging

The USB-C1 port supports USB PD (Power Delivery) 3.0 fast-charging up to 5V 3A, 9V 3A, 15V 3A or 20V 3.25A (65W max). The USB-C2 port supports 5V 2A or 9V 2.22A (20W max). If you're charging two devices at the same time, the U280-WF2-65C2-G supports combined charging up to 45W (USB-C1) and 18W (USB-C2).

Gallium Nitride Technology Provides Charging Capacity in a Flat Package

This USB wall charger is smaller, lighter and more energy-efficient than most standard wall chargers that come with mobile devices. Ideal for travel, the U280-WF2-65C2-G is designed using GaN technology, which allows it to operate under cooler temperatures, meaning it won't get hot while charging your device.

Built-In Auto-Sensing Adjusts to Proper Power Level to Get Your Device to 100%

The USB-C ports feature auto-sensing technology that automatically adjusts to your devices' appropriate power level, allowing them to charge to full strength more quickly and efficiently. The charger protects against overheating, overcurrent, overcharging and short circuits, and it stops charging when your devices are at full capacity.

Folding Plug Design Perfectly Sized for Travel

The U280-WF2-65C2-G fits in the palm of your hand, so it is easy to carry in your purse, suitcase, backpack or laptop bag for convenient use anywhere. The USB-C ports are located on the bottom of the charger, which is ideal for plugging devices into outlets that are tucked behind furniture and would normally be difficult to get to with standard chargers. The NEMA 1-15P plug folds into the charger when not in use to shield it from damage and prevent it from snagging or scratching your bag's contents.

Highlights

- Low-profile design allows convenient charging of phones and tablets while traveling
- USB-C PD 3.0 port supports up to 65W for fast, efficient charging of compatible devices
- GaN technology ensures high-efficiency charging with less heat and smaller footprint
- Connects to an AC wall outlet in almost every office, home, hotel, dorm, airport or café
- Protects your connected devices against hazardous overheating and short circuits

Package Includes

U280-WF2-65C2-G USB-C 2-Port Wall Charger

Specifications

OVERVIEW	
UPC Code	037332294630
Charging Form Factor	Direct Plug-In
Product Type	Wall Charger
Charger Functions	Charge
Device Compatibility	Chromebook; Laptop; Phone; Tablet
Technology	USB
INPUT	
Nominal Input Voltage(s) Supported	120V AC; 240V AC
Maximum Input Amps	2
Input Connection Type	NEMA 1-15P
Voltage Compatibility (VAC)	100; 110; 120; 125; 127; 200; 208; 220; 230; 240
Input Frequency	50/60 Hz
Input Plug Type	NEMA 1-15P (NON-POLARIZED)
Input Current	100-240V, 2A (Max)
OUTPUT	
Output Capacity (Watts)	65
Frequency Compatibility	50 / 60 Hz
Continuous Output Capacity (Watts)	65
Overload Protection	Yes
POWER	
Power Consumption (Watts)	0.08
USB Power Delivery (PD) Charging Support	Yes
USB Power Delivery (PD) Charging Specification	3.0
CONNECTIONS	
Number of Ports	2
Side A - Connector 1	NEMA 1-15P (NON-POLARIZED)
Side A - Connector 3	USB C (FEMALE)
Side B - Connector 1	USB C (FEMALE)
USER INTERFACE, ALERTS & CONTROLS	
Diagnostic LED(s)	Yes



Powering Business Worldwide

TRIPP LITE
SERIES

LED Indicators	Blue - Power
CHARGING	
Number of Charging Ports	2
Total Charging Amps	USB-C1: 5V3A, 9V3A, 15V3A, 20V3.25A (65W MAX); USB-C2: 5V2A, 9V2.22A (20W MAX)
Total Charging Watts	65
Charging Method	USB
Charging Method Detail	Supports:Power Delivery GAN Technology
Charging Port Type	(2) USB C (FEMALE)
Charging Ports Details	USB-C1: 5V3A, 9V3A, 15V3A, 20V3.25A (65W MAX); USB-C2: 5V2A, 9V2.22A (20W MAX); USB-C1+USB-C2: 45W MAX + 18W MAX
Charging Ports / Amps	3.25A; 2A; 3A; 2.22A
Wireless Charging	No
Compatible Devices	Chromebook; Laptop; Smartphone; Tablet
Charging Amps per Port	3A
PHYSICAL	
Color	White
Material of Construction	PC (PLASTIC)
Total Number of Ports	2
Unit Dimensions (hwd / in.)	3.330 x 1.910 x 0.750
Unit Dimensions (hwd / cm)	3.1 x 1.7 x 0.6
Unit Packaging Type	Box
Unit Weight (lbs.)	0.14
Unit Weight (kg)	0.06
ENVIRONMENTAL	
Operating Temperature Range	23° to 77°F (-5° to 25°C)
Storage Temperature Range	-22° to 158°F (-30° to 70°C)
Operating Humidity Range	10 to 90% RH, Non-Condensing
Storage Humidity Range	10 to 90% RH, Non-Condensing
Power Provided to Connected Device(s)	USB-C1: 65W MAX; USB-C2: 20W MAX; USB-C1+USB-C2: 45W MAX + 18W MAX
FEATURES & SPECIFICATIONS	
GaN Technology	Yes
Overcurrent Protection	Yes
Overvoltage Protection	Yes



Powering Business Worldwide

TRIPP LITE
SERIES

Over Current Protection	Yes
Quick Charge Compliant	No
Driver Required	No
Over Temperature Protection	Yes
STANDARDS & COMPLIANCE	
Product Certifications	CAN/CSA-C22.2 No. 62368-1 (Canada); UL 62368-1; UL Listed
Product Compliance	FCC (USA); FCC Part 15 Class B (USA)
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	2-year limited warranty

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2026 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.