


7-Port USB-A Mini Hub - USB 3.2 Gen 1, International Plug Adapters, Aluminum Housing

MODEL NUMBER: U360-007-AL-INT

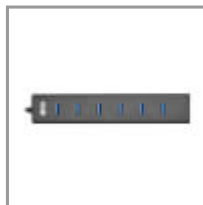

USB 3.2 Gen 1 portable hub adds 7 USB-A ports to your PC, laptop, Chromebook, tablet or other USB-enabled device.

Features

USB-A Hub Connects 7 USB Peripherals to Your Computer, Laptop or Tablet

This USB mini hub connects up to seven USB peripherals to your computer, laptop, Ultrabook, Chromebook, tablet or other device with a USB-A port. It expands the potential of your device by connecting peripherals that can help you do your job faster, easier and better, such as a printer, power meter, keyboard/mouse and external hard drives for uploading and downloading important files.

Transfers Data at Fast USB 3.2 Gen 1 Speeds

All seven USB ports transfer images, video and other data at speeds up to 5 Gbps, which is 10 times faster than USB 2.0. The USB ports are backward compatible with previous USB generations, so you can continue using older peripherals while getting high-speed performance from new devices.

Ideal for Charging Multiple Mobile Devices

The included external power supply provides 5V 3A to be shared among all seven USB ports. Each port is capable of providing up to 1.5A for fast charging of your phone, tablet, music player and other mobile devices.

Ready to Use Right Out of the Package

The plug-and-play USB hub connects to your computer via its built-in USB cable, saving you the expense and effort of buying and carrying extra cables. It requires no drivers or other software. The included power supply comes with international plug adapters that allow you to connect to almost any AC outlet. The slim aluminum housing fits easily into a pocket, briefcase or laptop bag, so you can set up your workstation anywhere.

Specifications

OVERVIEW	
UPC Code	037332272041

Highlights

- Accepts up to 7 USB peripherals, turning your computer into a mini workstation
- Supports USB 3.2 Gen 1 speeds up to 5 Gbps to ensure fast data transfer
- 5V/1.5A ports quickly charge smartphones and other mobile devices
- Slim aluminum housing fits easily into backpack or bag for use anywhere
- Plug-and-play operation with no software required for immediate connection

Package Includes

- U360-007-AL-INT 7-Port USB-A Mini Hub
- External power supply (Input: 100–240V, 50/60 Hz, 0.6A; Output: 5V 3A)
- (3) International plug adapters (U.K., Europe, Australia)

Product Type	Hub
Technology	USB
Host Connector	USB A (MALE)
DATA	
Data Ports	(7) USB A (FEMALE)
Data Ports Details	(7) USB-A - USB 3.2 Gen 1 (5 Gbps)
INPUT	
AC Power Adapter Plug(s)	AS/NZS 3112 Australia; BS 1363 UK; IEC-320-C14
AC Power Adapter Input Specs (V / Hz / A)	100-240V / 50/60Hz / 0.6A
AC Power Adapter Output Specs (V / A)	5V / 3A
AC Power Adapter Cord Length (ft.)	5
AC Power Adapter Cord Length (m)	1.5
Voltage Compatibility (VAC)	100; 110; 120; 125; 127; 200; 208; 220; 230; 240
Built-In Cable Length (ft.)	1.31
Built-In Cable Length (m)	0.4
Built-In Cable Length (in.)	15.75
Built-In Cable Length (cm)	40
Bus Powered	No
Product Length (in.)	21.6
Product Length (cm.)	54.86
Product Length (ft.)	1.8
Product Length (m.)	0.548
BATTERY	
Battery Charging (5V/1.5A Port)	Yes
POWER	
Power Source Type	AC Adapter
AC Adapter	Input: 100-240V, 50/60Hz, 0.6A; Output: 5V, 3A
DC Barrel Plug	OD: 3.5 x 1.35 x 10mm, Positive Pin, Negative Sleeve
Power Consumption (Watts)	1.40
USB Power Delivery (PD) Charging Support	No
USER INTERFACE, ALERTS & CONTROLS	

LED Indicators	White (Connection to Power)
CHARGING	
Charging Ports	USB-A: 5V 1.5A (7.5W)
Charging Ports Details	All USB-A ports provide 5V/1.5A to quickly charge connected devices
Charging Ports / Amps	(7) 1.5A
PHYSICAL	
Color	Black
Material of Construction	Aluminum
Cable Jacket Rating	VW-1
Unit Dimensions (hwd / in.)	0.830 x 6.200 x 1.180
Unit Dimensions (hwd / cm)	2.1 x 15.74 x 3.0
Unit Packaging Type	Box
Unit Weight (lbs.)	0.53
Unit Weight (kg)	0.24
ENVIRONMENTAL	
Operating Temperature Range	32° to 104°F (0° to 40°C)
Storage Temperature Range	14° to 158°F (-10° to 70°C)
Relative Humidity	10% to 90% RH, Non-Condensing
BTUs	4.7 BTU/Hr
Power Provided to Connected Device(s)	5V 1.5A (7.5W) Output per USB Port
CONNECTIONS	
Number of Ports	7
Side A - Connector 1	USB A (MALE)
Side B - Connector 1	(7) USB A (FEMALE)
Connector Plating	Nickel
FEATURES & SPECIFICATIONS	
USB Specification	USB 3.2 Gen 1 (up to 5 Gbps)
UASP Support	No
Auto MDIX Support	No
Full Duplex Support	No
Suspend Mode Support	No
Remote Wakeup Support	No

Driver Required	No
STANDARDS & COMPLIANCE	
External Power Supply Certifications	CE; GS; PSE; TUV; UL; WEEE; cUL
Product Compliance	CE (Europe); REACH; RoHS; UKCA; WEEE
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	1-year limited warranty