


7-Port USB-C Hub - USB 3.2 Gen 1 (5 Gbps) USB-A Ports with On/Off Buttons, Optional USB-A Adapter, Gray

MODEL NUMBER: U360-007-SW

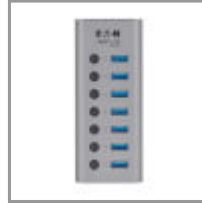

Adds 7 USB-A ports to your PC, tablet, smartphone, MacBook, Chromebook or Windows laptop for connecting hard drives, webcams and other USB devices.

Features

Powered USB Hub Connects 7 USB Peripherals to Your Computer, Laptop or Tablet

The U360-007-SW adds as many as seven USB-A devices to your computer, tablet, smartphone, laptop, MacBook, Surface or Chromebook, turning it into a mini workstation. The hub expands the potential of your host device by connecting peripherals that can help you do your job faster, easier and better, such as USB headset/microphones, barcode scanners, webcams, keyboards/mice, power meters and external storage drives for uploading and downloading important files.

Supports the Latest USB Devices at Fast USB 3.2 Gen 1 Speeds

This slim hub features seven USB-A ports that support USB 3.2 Gen 1 data transfer speeds up to 5 Gbps and 5V 1.5A (7.5W) fast-charging for smartphones and tablets. Each USB-A port is controlled by its own off/on button, which allows you to power down individual ports to ensure devices like webcams and microphones are only in use when intended. The USB ports are backward compatible with previous USB generations, so you can continue using older peripherals while getting high-speed performance from new devices.

Ready to Use Right Out of the Package

The plug-and-play U360-007-SW is specifically designed for use with the MacBook Pro, Windows laptops and other computers, tablets and devices equipped with a USB-C or Thunderbolt 3 port. It requires no drivers or other software to download or install. The included power supply comes with international plug adapters that allow you to connect to almost any AC outlet.

Flexible for Use at Home, Office or On the Go

The lightweight aluminum housing fits easily into a pocket, briefcase or laptop bag, making it ideal for work-from-anywhere applications. Just connect the included USB-C cable between the hub and your host device. A USB-A cable adapter is included for connecting to a laptop or other host without USB-C or Thunderbolt ports.

Specifications

Highlights

- Accepts up to 7 USB peripherals, turning your computer into a mini workstation
- 7 USB-A ports support USB 3.2 Gen 1 speeds up to 5 Gbps for fast data transfers
- Each port can be turned off when not in use for extra security and privacy
- Slim housing fits easily into backpack or bag for convenient work-from-anywhere use
- Plug-and-play operation with no software required for immediate connection

System Requirements

Host device with a USB-C, Thunderbolt 3 or USB-A port (USB 3.2 Gen 1 port needed to achieve USB 3.2 Gen 1 speeds)

Package Includes

- U360-007-SW 7-Port USB-C Hub
- USB-C host cable with optional USB-A adapter, 3 ft. (0.9 m)
- External power supply (Input: 100–240V, 50/60 Hz, 0.6A; Output: 12V 2A 24W) with 5 ft. (1.5 m) cord
- (4) International plug adapters (North America, U.K., Europe, Australia)
- Installation instructions



Powering Business Worldwide

TRIPP LITE
SERIES

OVERVIEW	
UPC Code	037332293978
Product Type	Hub
Device Compatibility	Chromebook; Computer; Laptop; Tablet
Technology	Thunderbolt; USB 3.x
Country/Region	Global
Host Connector	USB C (FEMALE)
DATA	
Data Ports	(7) USB A (FEMALE)
Data Ports Details	(7) USB-A - USB 3.2 Gen 1 (5 Gbps)
INPUT	
AC Power Adapter Plug(s)	AS/NZS 3112 Australia; BS 1363 UK; CEE 7/7 Schuko; NEMA 1-15P North America
AC Power Adapter Input Specs (V / Hz / A)	100-240V, 50/60Hz, 0.6A
AC Power Adapter Output Specs (V / A)	12V, 2A
AC Power Adapter Cord Length (ft.)	5
AC Power Adapter Cord Length (m)	1.5
Voltage Compatibility (VAC)	100; 110; 120; 125; 127; 200; 208; 220; 230; 240
Product Length (in.)	4.65
BATTERY	
Battery Charging (5V/1.5A Port)	Yes
POWER	
Power Source Type	AC Adapter
AC Adapter	Input: 100-240V, 50/60Hz, 0.6A; Output: 12V, 2A, 5 ft.
DC Barrel Plug	OD: 5.5 x 2.5 x 10mm, Positive Pin, Negative Sleeve
Power Consumption (Watts)	1.40
USB Power Delivery (PD) Charging Support	No
CONNECTIONS	
Number of Ports	7
Side A - Connector 1	(7) USB A (FEMALE)
Side B - Connector 1	(1) USB C (FEMALE)
Connector Plating	Nickel



Powering Business Worldwide

TRIPP LITE
SERIES

USER INTERFACE, ALERTS & CONTROLS	
LED Indicators	(x7) White (Connection)
CHARGING	
Number of Charging Ports	7
Total Charging Watts	7.5
Charging Port Type	(5) USB A (FEMALE); (1) USB C (FEMALE)
Charging Ports	(7) USB-A: 5V 1.5A (7.5W)
Charging Ports Details	USB-A: All USB-A ports provide 5V 1.5A (7.5W) to connected devices
Charging Ports / Amps	1.5A
Compatible Devices	Chromebook; Laptop; Smartphone; Tablet
PHYSICAL	
Color	Gray
Material of Construction	ABS
Cable Jacket Color	Black
Cable Jacket Material	PVC
Cable Outer Diameter (OD)	5.0mm
Wire Gauge (AWG)	24/30/32
Total Number of Ports	8
Shipping Dimensions (hwd / in.)	2.36 x 6.30 x 4.72
Shipping Dimensions (hwd / cm)	5.99 x 16.00 x 11.99
Shipping Weight (lbs.)	0.86
Shipping Weight (kg)	0.39
Unit Dimensions (hwd / in.)	0.440 x 0.790 x 1.950
Unit Dimensions (hwd / cm)	2.0 x 4.95 x 11.8
Unit Packaging Type	Box
Unit Weight (lbs.)	0.39
Unit Weight (kg)	0.18
ENVIRONMENTAL	
Operating Temperature Range	32° to 122°F (0° to 50°C)
Storage Temperature Range	68° to 158°F (20° to 70°C)
Relative Humidity	10% to 90% RH, Non-Condensing
Operating Humidity Range	10% to 90% RH, Non-Condensing
Storage Humidity Range	0% to 95% RH, Non-Condensing



Powering Business Worldwide

TRIPP LITE
SERIES

Power Provided to Connected Device(s)	5V 1.5A
FEATURES & SPECIFICATIONS	
Over Current Protection	Yes
USB Hub Ports	Yes
Number of USB Hub Ports	7
USB Specification	USB 3.2 Gen 1 (up to 5 Gbps)
Data Transfer Rate	(7) 5 Gbps
Ethernet Support	No
UASP Support	No
Auto MDIX Support	No
Full Duplex Support	No
Suspend Mode Support	No
Remote Wakeup Support	No
Driver Required	No
STANDARDS & COMPLIANCE	
External Power Supply Certifications	C-Tick; CCC; CE; DOE; GS; TUV; UL; WEEE; cUL
Product Certifications	EN 55032; EN 55035; ICES (Canada)
Product Compliance	CE (Europe); FCC (USA); REACH; RoHS; UKCA; WEEE
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	3-year limited warranty

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2025 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.