


## 4-Port USB-C Hub with Laptop Stand - USB 3.x (5Gbps), 4x USB-A Ports, Thunderbolt 3 Compatible, 100W PD Charging, Silver

MODEL NUMBER: U460-ST4-4A-C

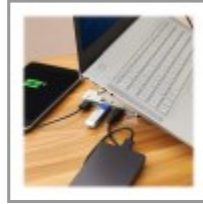

Folding portable laptop stand includes a 4-port USB-A hub to create a flexible mobile workstation for work-from-anywhere users.

### Features

#### USB 3.2 Hub Connects 4 USB-A Peripherals to Your USB-C Port

This USB-C hub allows you to connect up to four USB peripherals to your MacBook Pro, Windows laptop or other tablet, smartphone or computer with a USB-C or Thunderbolt 3 port. You can expand the capability of your device by connecting USB peripherals that help you do your job faster, easier and better, such as an external hard drive.

#### Transfers Data at Fast USB 3.2 Gen 1 Speeds

The four USB-A ports transfer data at speeds up to 5 Gbps and share 15W maximum power for charging mobile devices. One also supports 1.5A maximum for downstream charging. The USB ports are backward compatible with previous USB generations, so you can continue using older peripherals while getting high-speed performance from new devices.

#### PD Charging Port Charges Host Device via AC Wall Charger

The USB-C Power Delivery port supports power output up to 20V 5A (100W), which is more than sufficient for charging and powering the connected source device, such as a MacBook Pro, Windows laptop or Chromebook. Just connect the device's wall charger to both the USB-C PD port and an AC outlet. PD 3.0 Fast Role Swap technology ensures the connection remains stable if the wall charger becomes dislodged.

#### Allows a Choice of Viewing Angles to Match Your Personal Comfort Level

This USB-C hub is also a convenient laptop stand that adjusts to five different viewing angles from 15 to 36 degrees. Its bottom bracket design helps create a more ergonomic workspace for work-from-anywhere users. The U460-ST4-4A-C folds into a compact unit for easy transport and storage and quickly unfolds for immediate use. Its built-in USB-C cable wraps neatly beneath the hub to avoid cord clutter when not in use.

#### Ready to Use Right from the Package

The plug-and-play USB-C hub is specifically designed for use with the MacBook Pro, Google Chromebook Pixel and other laptops, tablets and devices equipped with a USB-C or Thunderbolt 3 port. It requires no drivers or external power.

### Highlights

- Accepts up to 4 USB peripherals, turning your laptop into a mini workstation
- Supports USB 3.2 Gen 1 speeds up to 5 Gbps to ensure fast data transfers
- USB-C PD 3.0 port supports 20V 5A (100W) power output for charging host device
- Hub folds neatly into a compact unit for convenient transport and storage
- Bottom bracket design creates ergonomic workspace that adjusts to your comfort level

### Applications

- Work from anywhere by adjusting the laptop stand to a comfortable angle and connecting up to 4 USB peripherals, such as a hard drive and MP3 player
- Save data from your computer to a USB thumb drive
- Charge your notebook or laptop by connecting its wall charger to the USB-C PD Charging port
- Connect a USB microphone/headset to record a podcast or listen to music

### System Requirements

Source device with USB-C or Thunderbolt 3 port (USB 3.2 Gen 1 capability required for 5 Gbps speeds)

### Package Includes

- U460-ST4-4A-C 4-Port USB-C Hub with Laptop Stand
- Quick Start Guide



Powering Business Worldwide

TRIPP LITE  
SERIES

## Specifications

OVERVIEW	
UPC Code	037332265869
Technology	USB 3.x
Host Connector	USB C (MALE)
VIDEO	
Extended Mode	No
Mirror Mode	No
DisplayPort Alt Mode	No
DATA	
Data Ports	(4) USB A (FEMALE)
BATTERY	
Battery Charging (5V/1.5A Port)	Yes
POWER	
Power Consumption (Watts)	85.00
USB Power Delivery (PD) Charging Support	Yes
USB Power Delivery (PD) Charging Specification	100W; 3.0
CONNECTIONS	
Number of Ports	4
Side A - Connector 1	USB C (MALE)
Side B - Connector 1	(4) USB A (FEMALE)
Side B - Connector 2	USB C (FEMALE)
CHARGING	
Total Charging Watts	15
Charging Ports / Amps	(1) 1.5A
PHYSICAL	
Color	Silver
Material of Construction	PC + ABS
Shipping Dimensions (hwd / in.)	1.10 x 10.43 x 2.75
Shipping Weight (lbs.)	0.71



Powering Business Worldwide

TRIPP LITE  
SERIES

Unit Dimensions (hwd / in.)	9.920 x 2.360 x 0.700
Unit Packaging Type	Box
Unit Weight (lbs.)	0.646
Unit Weight (kg)	0.29
<b>ENVIRONMENTAL</b>	
Operating Temperature Range	32° to 113°F (0° to 45°C)
Storage Temperature Range	32° to 158°F (0° to 70°C)
Relative Humidity	10 to 90% RH, Non-Condensing
Power Provided to Connected Device(s)	USB-A (x4): 15W, USB-C PD 3.0: 85W
<b>FEATURES &amp; SPECIFICATIONS</b>	
USB Hub Ports	Yes
Number of USB Hub Ports	4
USB Specification	USB 3.0 (up to 5 Gbps); USB 3.1 Gen 1 (up to 5 Gbps); USB 3.2 Gen 1 (up to 5 Gbps)
Driver Required	No
<b>STANDARDS &amp; COMPLIANCE</b>	
TAA Compliant Option	N
Product Compliance	RoHS; CE (Europe); REACH; FCC (USA)
<b>WARRANTY &amp; SUPPORT</b>	
Product Warranty Period (Worldwide)	1-year limited warranty

1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.  
Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.