

MODEL:

# PDU3MV6L2130

## 3-Phase Metered Rackmount PDU



**208V  
3-Phase Input**



**L21-30P  
Plug**



**208V and 120V  
Single-Phase  
Output**



**48 Outlets**



**8.6kW Load  
Capacity**



**Digital Load  
Meter**




**0U  
Rackmount**





**Toolless  
Mounting  
Buttons**

- A** Digital Load Meter
- B** C13 and C19 Outlets
- C** NEMA 5-15/20R Outlets
- D** 20A 2-Pole Hydraulic Magnetic Circuit Breakers
- E** Removable Cord Retention Brackets
- F** Removable Mounting Brackets
- G** Toolless Mounting Buttons with Removable 90° Rotation Brackets
- H** 6-ft. Input Power Cord
- I** L21-30P Twist-Lock Input Plug
- J** Durable Metal Case



Also Includes: Cable Ties, Owner's Manual

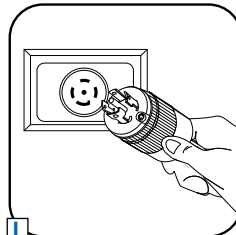


AC Input Connection: Insert L21-30P twist-lock plug into compatible L21-30R utility, generator or UPS outlet.

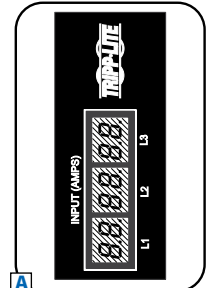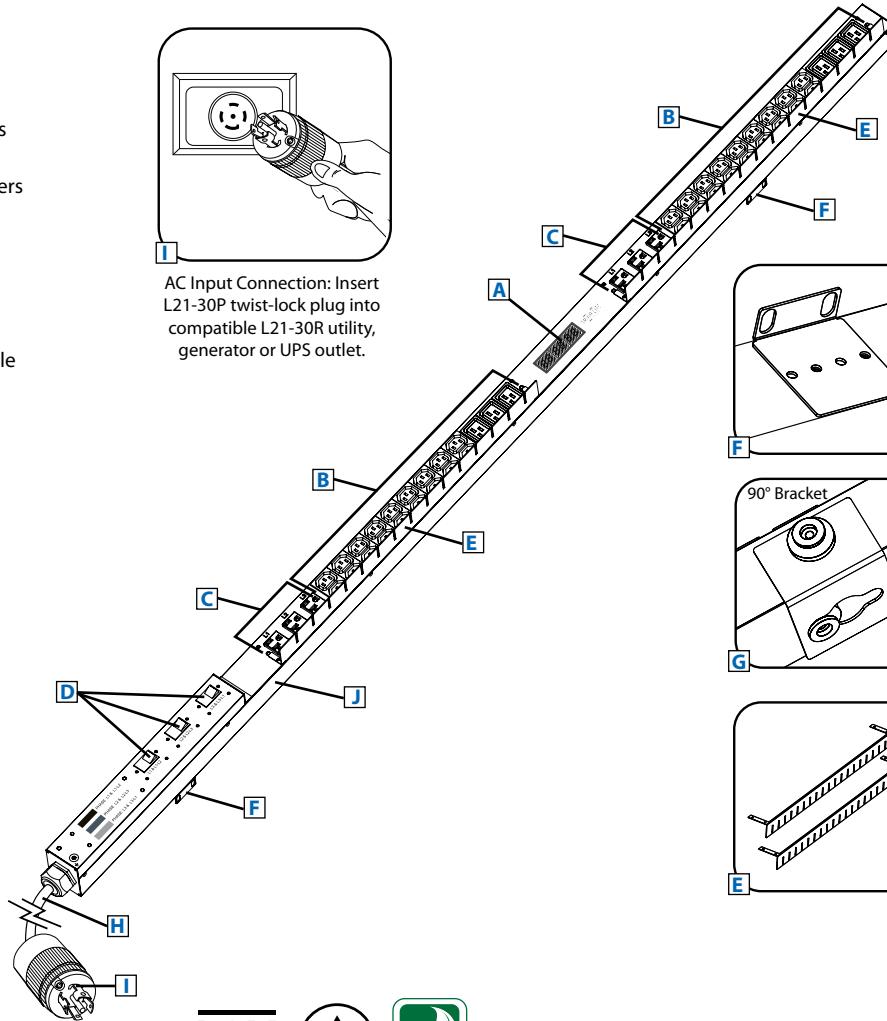

Digital Load Meter: The input current per phase is displayed separately for easy reference.

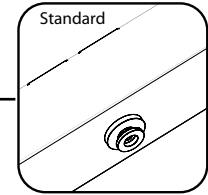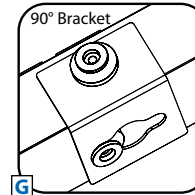

Note: Installed 17.67 mm toolless mounting buttons can be replaced with included 14.17 mm buttons for additional compatibility.

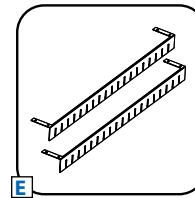

### Specifications

Model	PDU3MV6L2130
Voltage	208V 3-Phase Input / 208V and 120V Single-Phase Output
Frequency	50/60Hz
Load Capacity	8.6kW
Input Plug	L21-30P
Input Cord Length	6 ft.
Outlets	48 (36 C13 / 6 C19 / 6 5-15/20R)
Primary Mounting Option	0U (Vertical) Rackmount
Unit Weight & Dimensions	13.9 lbs / 70 x 2.65 x 2.2 in. <i>See next page for detailed unit measurements.</i>
Standards	Tested to UL 60950-1 (US & Canada), NOM (Mexico), FCC Class A

Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.









- Distributes power to 48 outlets (12 C13, 2 C19 and 2 5-15/20R per phase)
- Displays input current for each phase in real time
- Perfect for rackmount server, network and telecom applications

**SEE NEXT PAGE FOR DETAILED UNIT MEASUREMENTS**



1111 W. 35th Street  
Chicago, IL 60609 USA  
773.869.1234  
www.tripplite.com

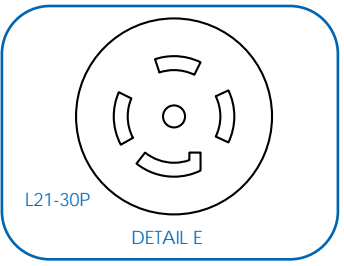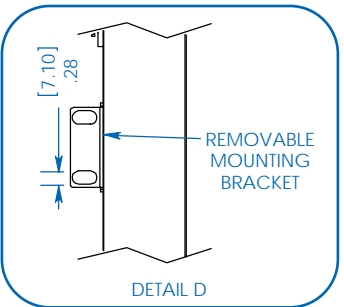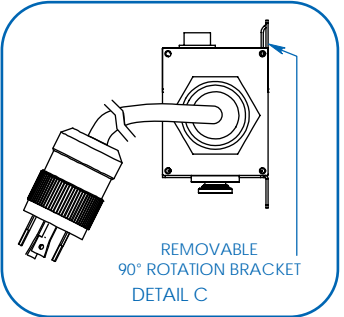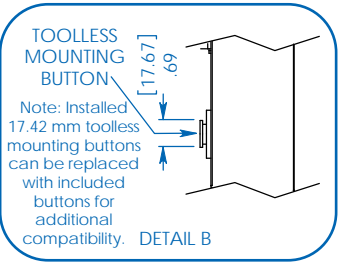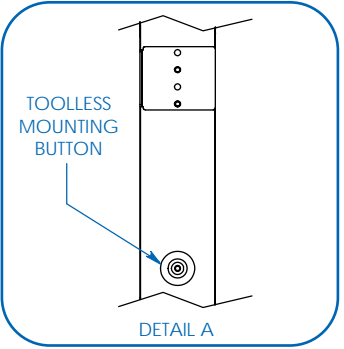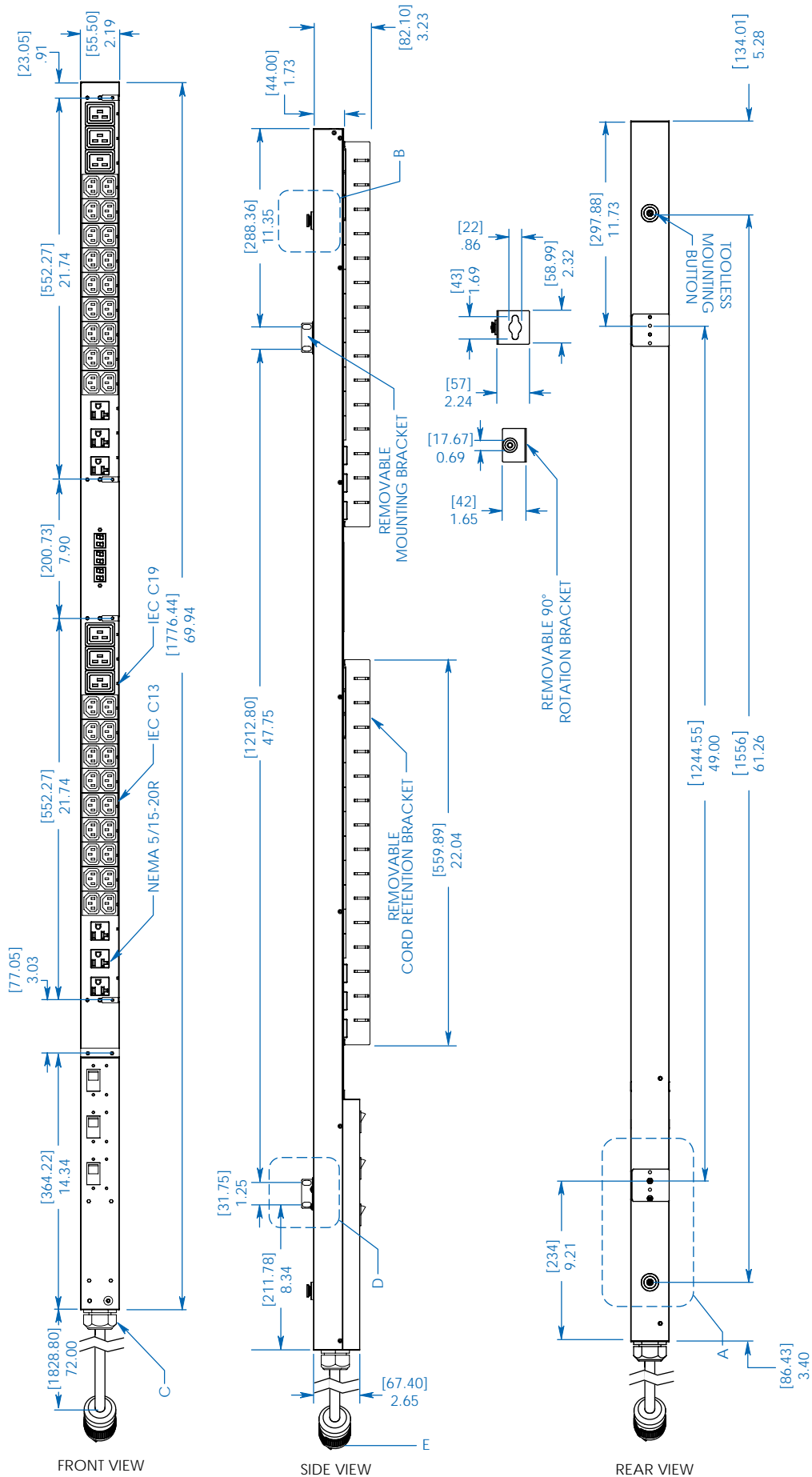

Dimensions: [mm] INCHES

Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.

MODEL:  
**PDU3MV6L2130**



1111 W. 35th Street  
Chicago, IL 60609 USA  
773.869.1234

www.tripplite.com