

 
MODEL:

PDU3V602D354B

3-Phase Power Strip for PDU360AT6G60 ATS Installations



208V
3-Phase Input



8-Position Input
Connector



208V
Single-Phase
Output



17.3kW
Load Capacity



54 Outlets





0U
Rack-Mount



Toolless
Mounting Buttons

- A** Interlaced C13 and C19 Outlets
- B** 20A Double-Pole Magnetic Circuit Breakers (x6)
- C** 2.5 ft. Input Power Cord (x2)
- D** Input Plugs with Proprietary 8-Position Connector (x2)
(Plugs into PDU360AT6G60 ATS)
- E** 3 ft. Circuit Detection Cable
(Plugs into PDU360AT6G60 ATS)
- F** Toolless Mounting Buttons
- G** Grounding Screw

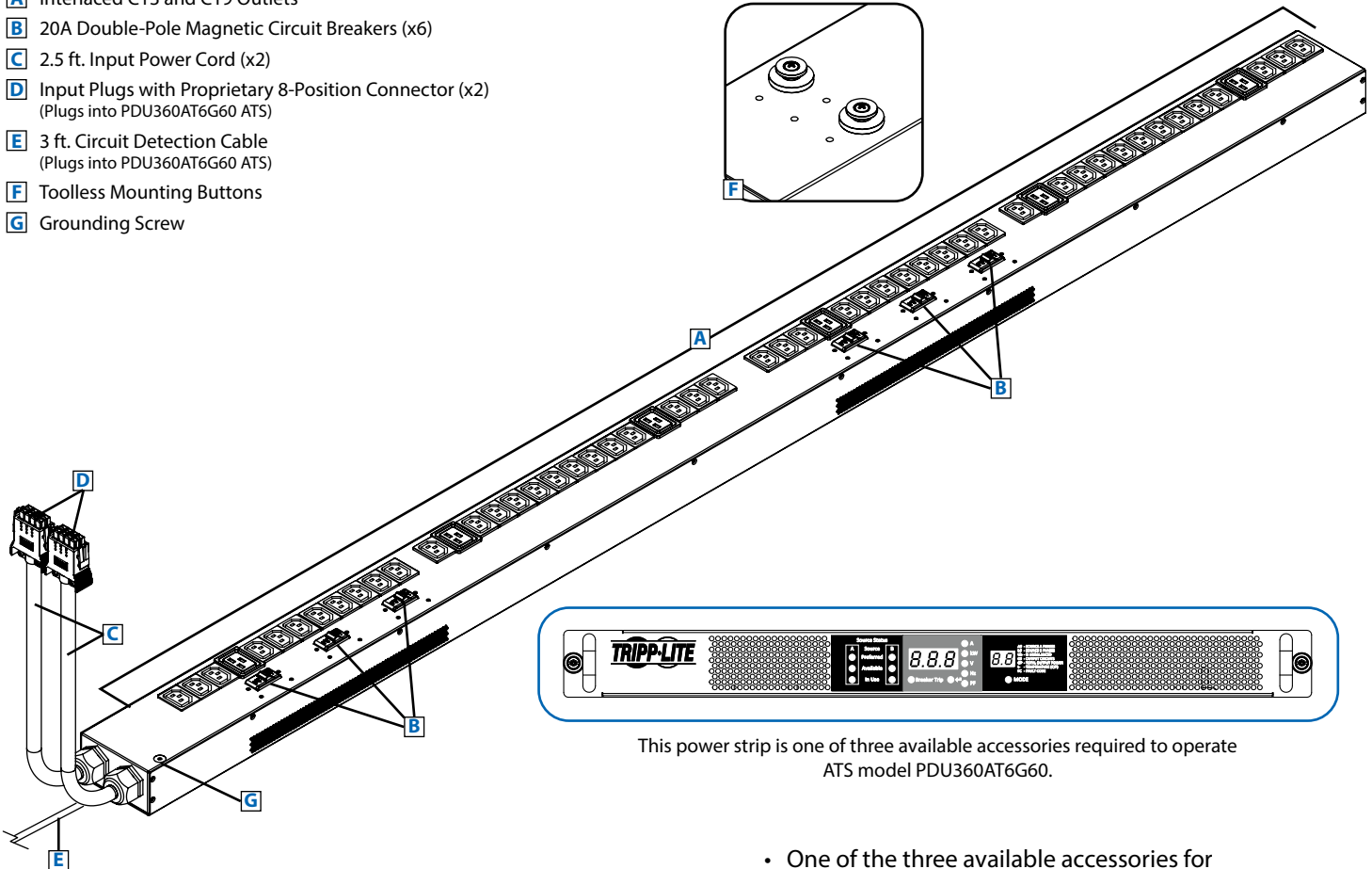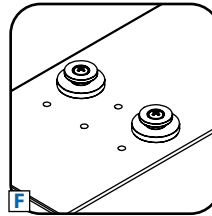

This power strip is one of three available accessories required to operate
ATS model PDU360AT6G60.

Specifications

| | |
|--------------------------|---|
| Model | PDU3V602D354B |
| Voltage | 208V |
| Frequency | 50/60 Hz |
| Load Capacity | 17.3kW |
| Input Plug | Proprietary 8-Position Connector (x2) |
| Input Cord Lengths | 2.5 ft. (0.8 m) |
| Outlets | 54 (48 C13, 6 C19) |
| Primary Mounting Options | 0U (Vertical) |
| Unit Weight & Dimensions | 19 lb. / 70 x 4 x 2.17 (HxWxD in inches) 8.62 kg / 1778 x 101.6 x 55.1 (HxWxD in mm) |
| Standards | Tested to UL/CSA 60950-1 (USA, Canada), FCC Class A (Emissions), NOM (Mexico), RoHS |







- One of the three available accessories for PDU360AT6G60 and other select Tripp Lite 3-phase ATS units
- Saves rack space, improves airflow and reduces cord clutter by locating outlets closer to connected devices
- Ideal for high-density equipment racks in data centers and server rooms

SEE NEXT PAGE FOR DETAILED UNIT MEASUREMENTS



1111 W. 35th Street
Chicago, IL 60609 USA
773.869.1234
www.tripplite.com

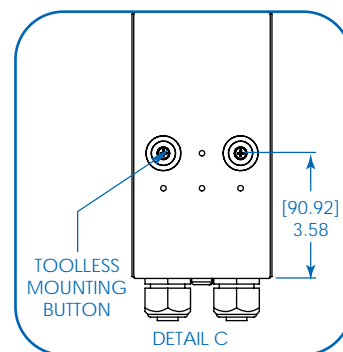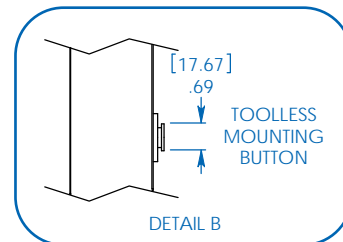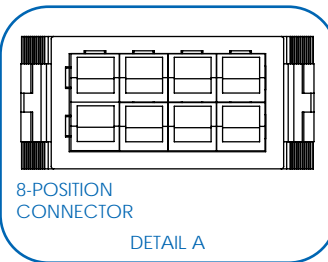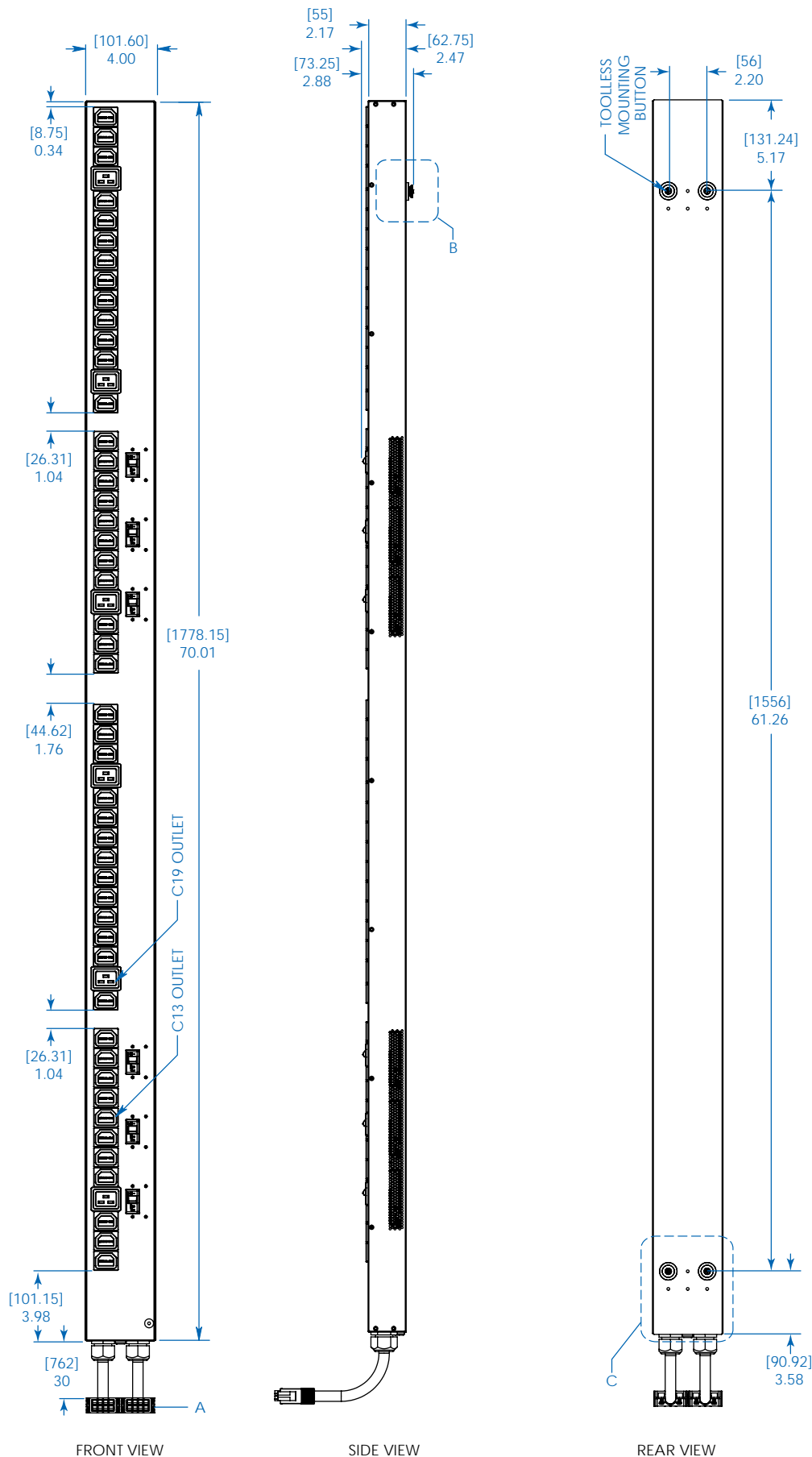

Dimensions: [mm] INCHES

Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.

MODEL:
PDU3V602D354B

TRIPP·LITE

1111 W. 35th Street
Chicago, IL 60609 USA
773.869.1234
www.tripplite.com