

MODEL:

# PDUMV20HVNET2LX

## Single-Phase Switched 0U Vertical PDU



208/230V  
Single-Phase  
Input/Output



8 Outlets



3.3-3.7kW



20A Max  
Capacity



L6-20P  
Plug



Load  
Meter



Network  
Interface



0U  
Rack-  
mount



Toolless  
Mounting  
Buttons



AC Inlet  
Supports




International Plugs




TAA  
Compliant

- A** Digital Load Meter
- B** C13 and C19 Outlets with On/Off LEDs
- C** C20 Inlet
- D** C13 (x7) and C19 (x1) Plug-Lock Insert Sleeves
- E** Removable Mounting Brackets
- F** Toolless Mounting Buttons with Removable 90° Rotation Brackets
- G** 10-ft. Detachable Input Power Cord
- H** L6-20P Twist-Lock Input Plug
- I** Durable Metal Case
- J** LX Platform Interface
- K** RJ45 Ethernet Port
- L** RJ45 Configuration Port
- M** USB-A Port
- N** Reset Button
- O** Status LED




Also includes: Configuration Cable, PDUMVROTATEBRKT, Owner's Manual

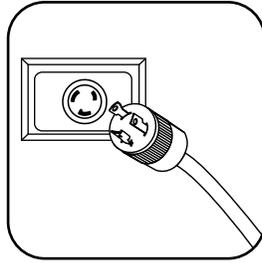

AC Input Connection: Insert L6-20P twist-lock plug into compatible L6-20R utility, generator or UPS outlet. For international applications, connect a user-supplied power cord with a country-specific plug to the C20 power inlet.

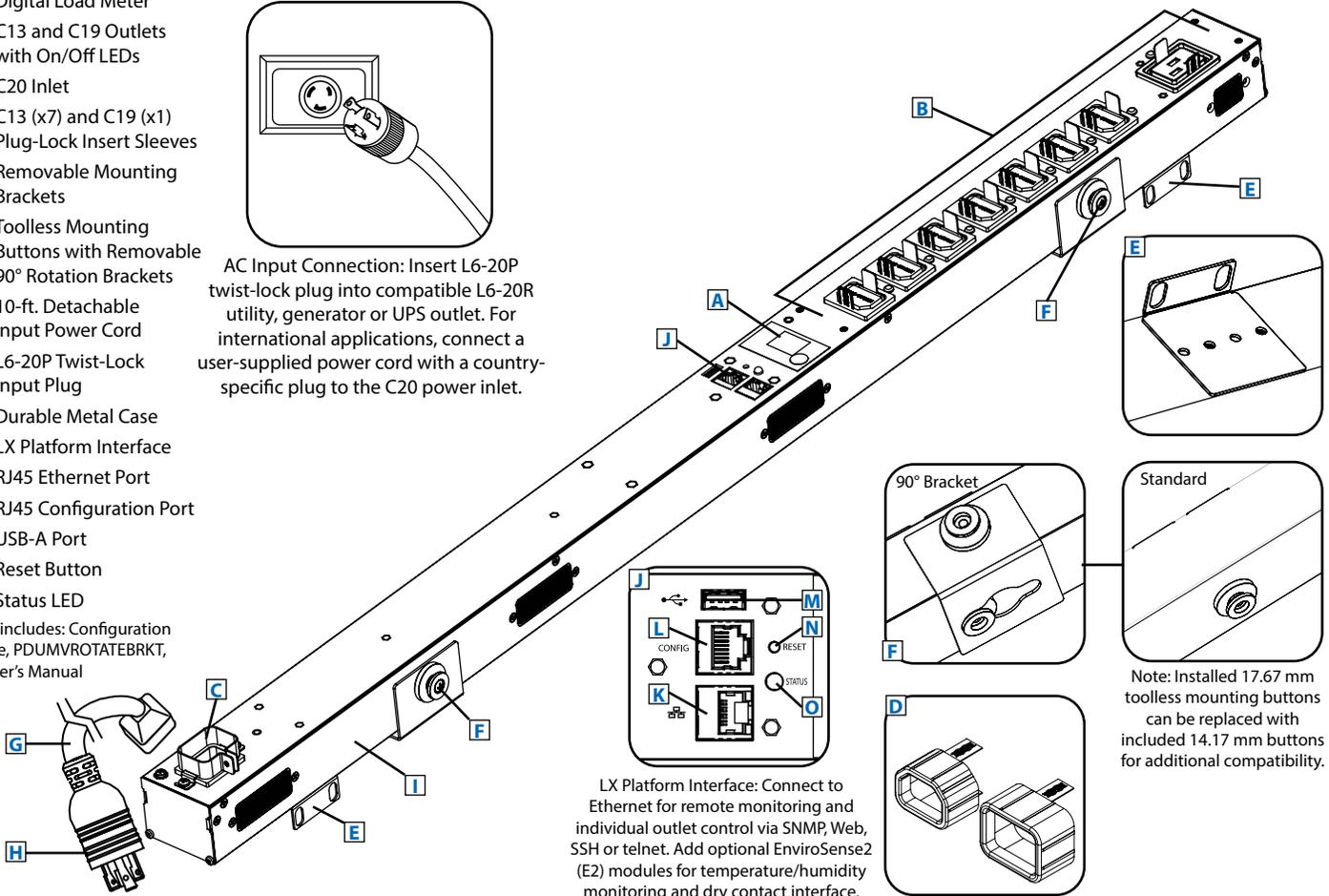

LX Platform Interface: Connect to Ethernet for remote monitoring and individual outlet control via SNMP, Web, SSH or telnet. Add optional EnviroSense2 (E2) modules for temperature/humidity monitoring and dry contact interface.

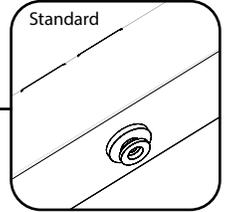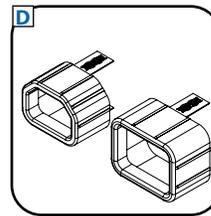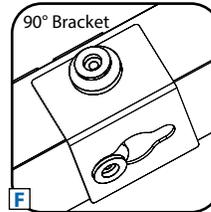

Note: Installed 17.67 mm toolless mounting buttons can be replaced with included 14.17 mm buttons for additional compatibility.

### Specifications

Model	PDUMV20HVNET2LX
Voltage	208/230V
Frequency	50/60 Hz
Maximum Capacity	20A
Agency-Derated Capacity	16A
Input Connector	L6-20P (C20 inlet)
Cord Length	10 ft. / 3 m
Outlets	8 (7 C13 / 1 C19)
Primary Mounting Option	0U (Vertical) Rack Mount
Unit Dimensions (H x W x D)	38.9 x 2.2 x 1.9 in. / 988 x 56 x 49 mm See next page for detailed unit measurements.
Unit Weight	3.9 lb. / 1.8 kg
Standards	Tested to UL 60950-1 (US & Canada), CE, NOM (Mexico), FCC & CE Class A (Emissions)









- Distributes power to 8 outlets
- Java-free HTML5-based network interface allows for remote monitoring and control via SNMP, Web, SSH or telnet
- Displays total load in real time
- Perfect for rack-mount server, network and telecom applications

SEE NEXT PAGE FOR DETAILED UNIT MEASUREMENTS



1111 W. 35th Street  
Chicago, IL 60609 USA  
773.869.1234  
www.tripplite.com

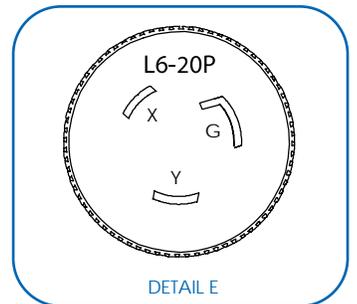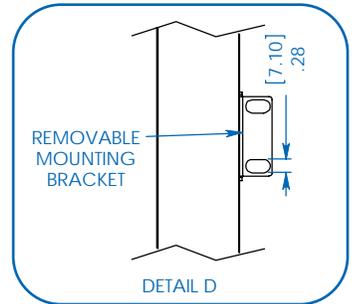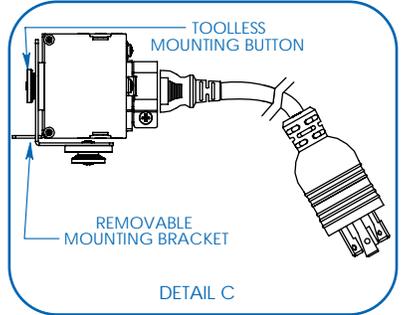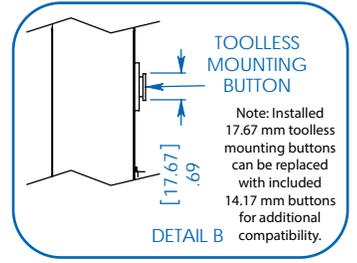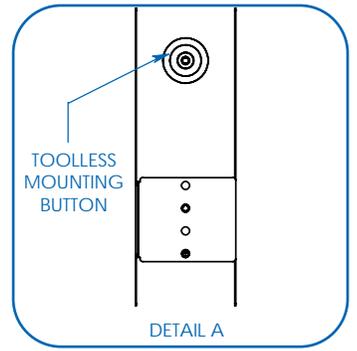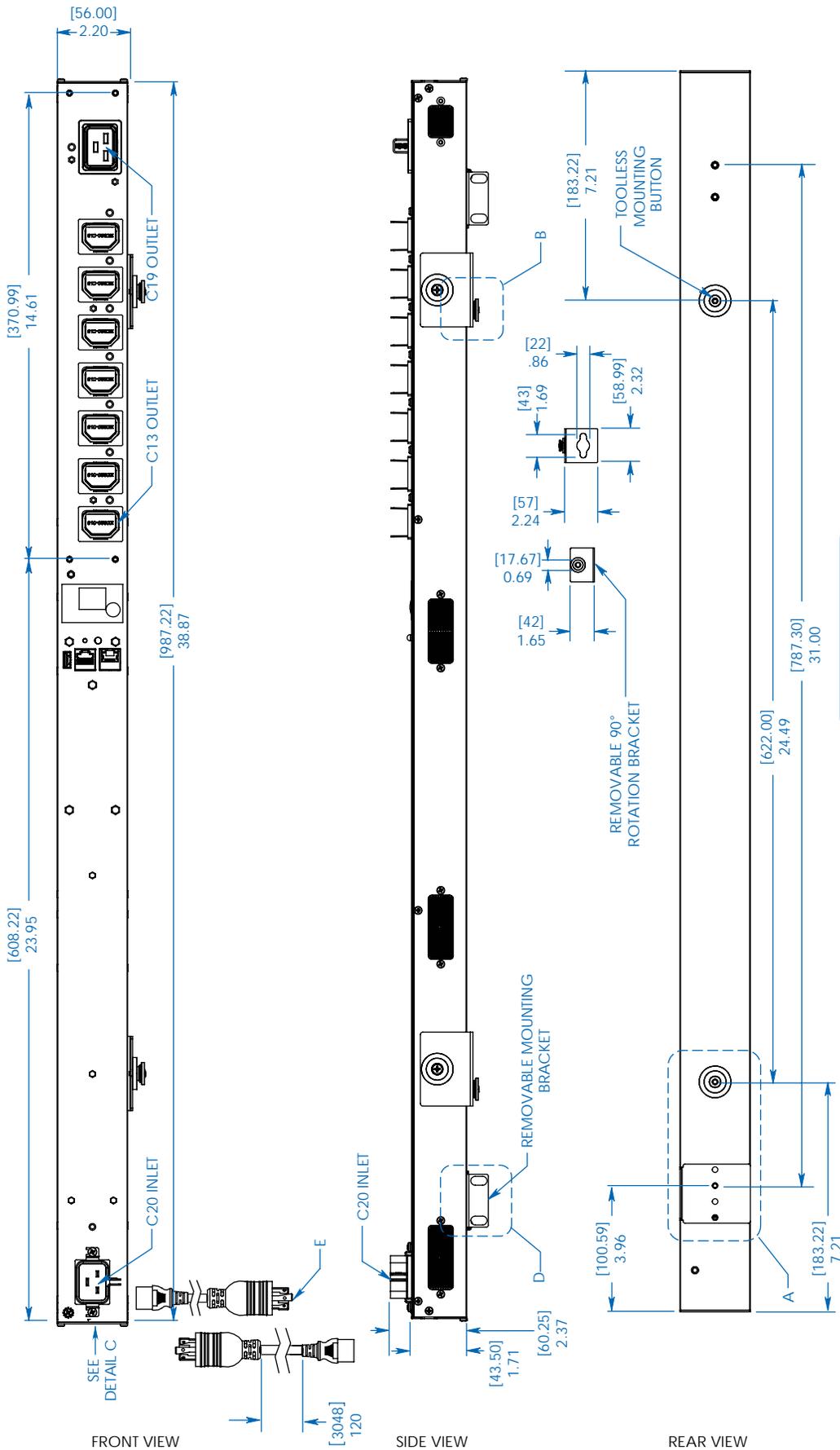

MODEL:  
**PDUMV20HVNET2LX**



1111 W. 35th Street  
Chicago, IL 60609 USA  
773.869.1234  
www.triplite.com

Dimensions: [mm] INCHES

Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.