

MODEL:

SK34USBB

Protect It!® Personal USB Charging Station with 3-Outlet Surge Protection



540 Joules
Surge Protection



Direct Plug-In
Design



3x 5-15R
AC Outlets



4.8A Total
USB Charging




\$10K Lifetime
Insurance



Lifetime
Warranty

- A** 5-15R Outlets
- B** USB Charging Ports (4.8A Total)
- C** Protected LED
- D** Slide-Out Phone/Tablet Holder
- E** Phone/Tablet Slot

Not shown:
5-15P Plug (On Rear of Housing)

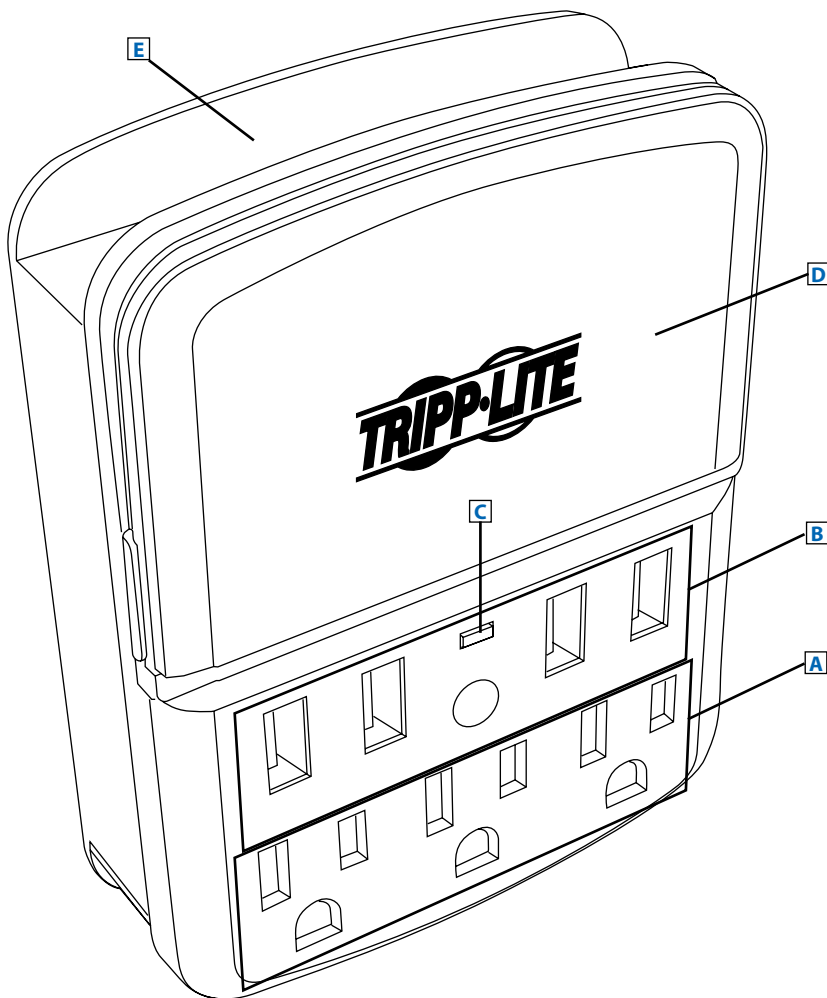

Specifications


Model	SK34USBB
Nominal Input Voltage Supported	120V AC 50/60Hz
Input Connection Type	5-15P (Direct-plug In)
Output Receptacles	3x 5-15R
Output (Watts)	1800W
Circuit Breaker (Amps)	15A
USB Charging Ports	4x USB A (Female)
Total USB Charging Capacity (Amps)	4.8A
Surge Suppression Rating (Joules)	540
Protection Modes	Includes full normal mode (H-N) and common mode (N-G / H-G)
Clamping Voltage (RMS)	600
Standards	UL 1449 3rd Edition; conforms to IEE 587/ANSI C62.41, RoHS

- Charges mobile devices, such as tablets, MP3 players and smartphones
- Built-in top slot and additional pull-out slot hold two devices while charging


SEE NEXT PAGE FOR DETAILED UNIT MEASUREMENTS




1111 W. 35th Street
Chicago, IL 60609 USA
773.869.1234
www.tripplite.com

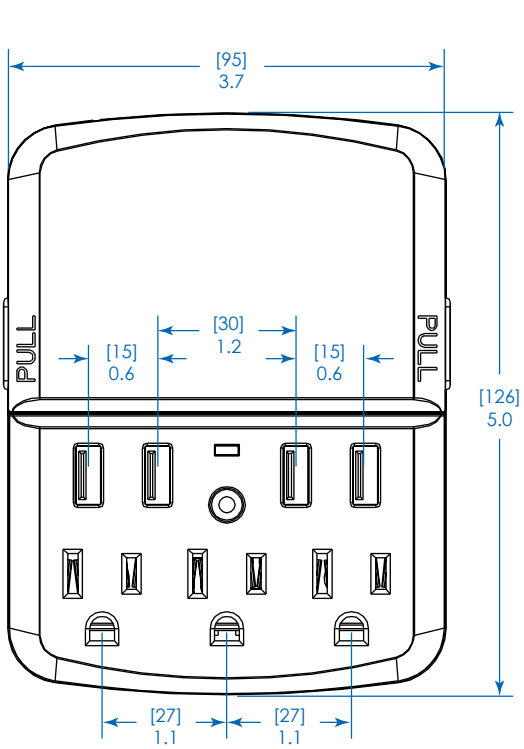


FRONT VIEW

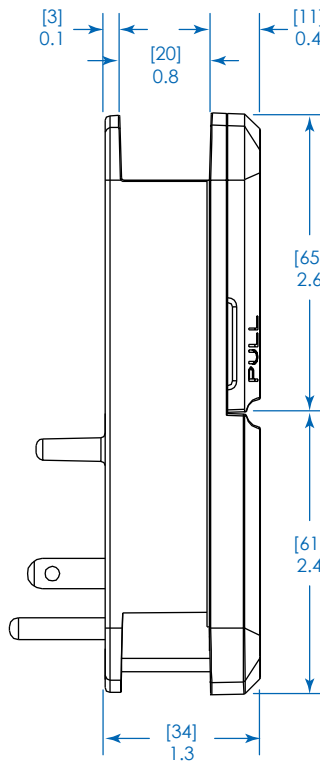

SIDE VIEW

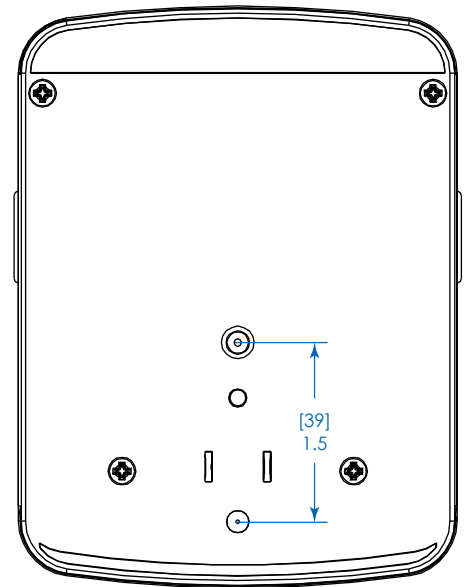

REAR VIEW

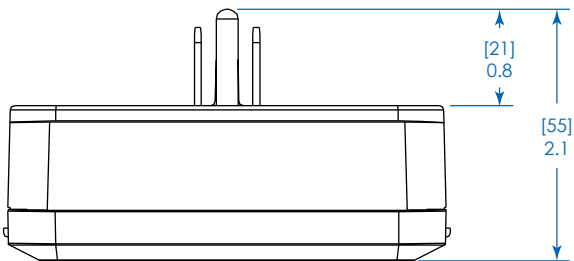

TOP VIEW

Dimensions: [mm] INCHES

Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.

MODEL:
SK34USB



1111 W. 35th Street
Chicago, IL 60609 USA
773.869.1234

www.tripplite.com