

MODEL:

# SR2POSTAA

## SmartRack® Open Frame Rack



45 Rack Units



800 lb.  
Stationary  
Load Capacity




Standard 19-inch  
Rack Width



Toolless  
Mounting Slots



 Integrated  
Baying Tabs




Square Hole  
Mounting



TAA-Compliant

- A** Mounting Rails (2)
- B** Toolless Button Holes  
(for vertical PDUs or cable managers)

Also Includes: Owner's manual, installation hardware, rackmount equipment mounting hardware (28 screws, 28 washers) and cable management hooks.

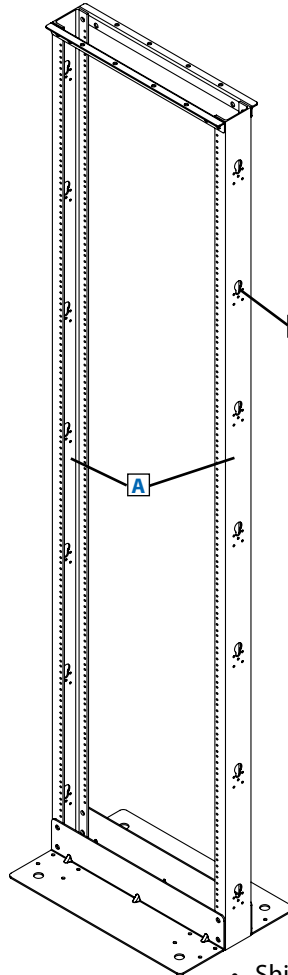

- Ships disassembled for easy transport and assembly in tight spaces
- Modular design optimized for quick configuration and reconfiguration
- Multiple units can be bolted together side by side
- Ideal for space-constrained or cost-conscious 19-inch rackmount applications

### Specifications

Model	SR2POSTAA
Rack Spaces	45U
Stationary Load Capacity	800 lb. (362.9 kg)
Unit Dimensions (H x W x D)	84 x 20.3 x 4.75 in. (2133.6 x 515.62 x 120.7 mm)
Shipping Dimensions (H x W x D)	7 x 3 x 85 in. (177.8 x 76.2 x 2159 mm)
Unit Weight	29 lb. (13.15 kg)
Shipping Weight	31 lb. (14.06 kg)
Certifications	Tested to EIA-310-D, NOM (Mexico), IEC 60297-3-100, DIN 41494, RoHS


Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.




SEE NEXT PAGE FOR DETAILED UNIT MEASUREMENTS




1111 W. 35th Street  
Chicago, IL 60609 USA  
773.869.1234  
www.tripplite.com

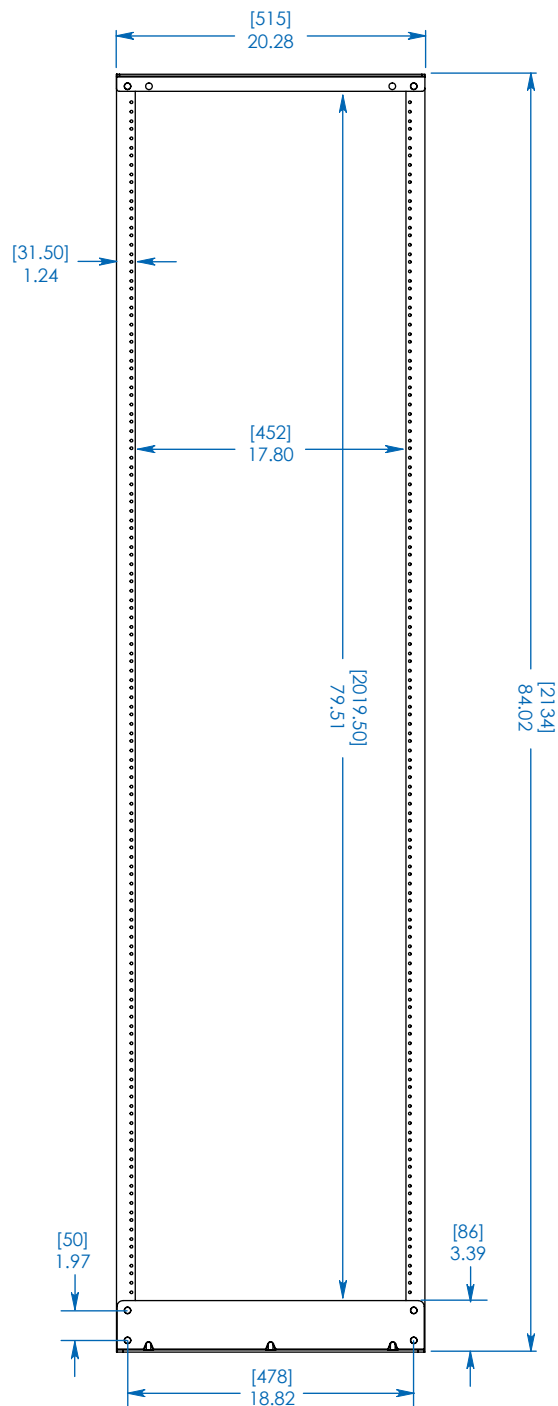

FRONT VIEW

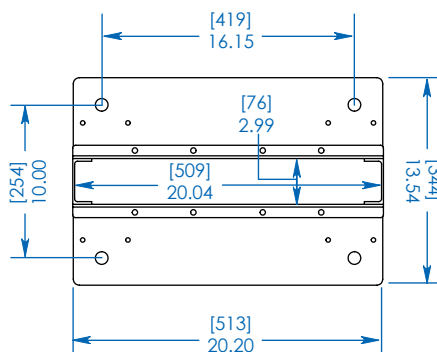

TOP VIEW

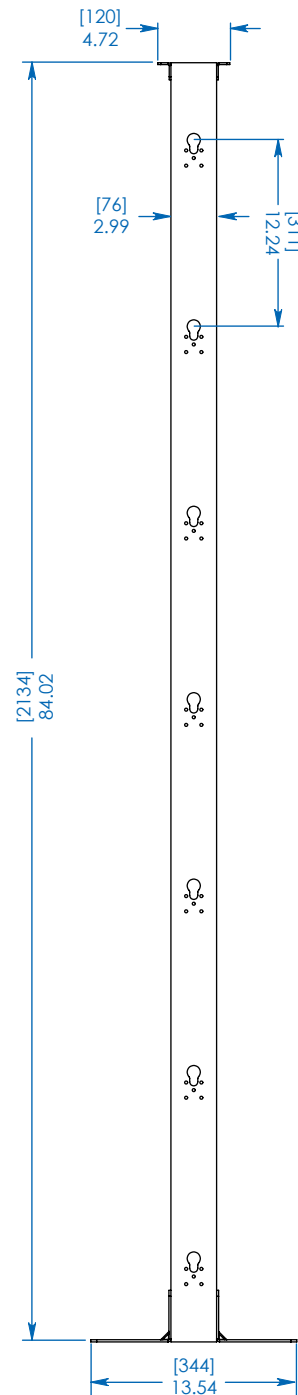

SIDE VIEW

Dimensions: [mm] INCHES

Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.

MODEL:  
**SR2POSTAA**  
**TRIPP·LITE**

1111 W. 35th Street  
Chicago, IL 60609 USA  
773.869.1234  
[www.tripplite.com](http://www.tripplite.com)