

MODEL:

SR4POSTAA

SmartRack® Open Frame Rack



45 Rack Units



1000 lb.
Stationary
Load Capacity



Standard 19-inch
Rack Width



 
Toolless
Mounting Slots



Adjustable
Rails with Easy-View
Depth Index



Integrated
Baying Tabs




Square Hole
Mounting



TAA-Compliant

- A** Adjustable Mounting Rails (4)
- B** Toolless Button Holes
(for vertical PDUs or cable managers)

Also Includes: Owner's manual, installation hardware, rackmount equipment mounting hardware (50 cage nuts, 50 screws, 50 washers) and cable management hooks.

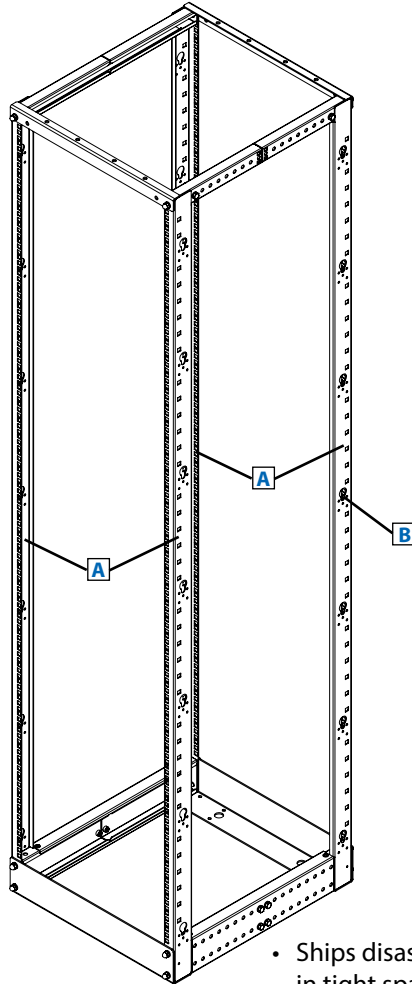

- Ships disassembled for easy transport and assembly in tight spaces
- Modular design optimized for quick configuration and reconfiguration
- Multiple units can be bolted together side by side
- Ideal for cost-conscious 19-inch rackmount applications

Specifications

Model	SR4POSTAA
Rack Spaces	45U
Stationary Load Capacity	1000 lb. (453.6 kg)
Unit Dimensions (H x W x D)	84.3 x 20.2 x 22-39.3 in. (2141.2 x 513.1 x 558.8-998.2 mm) (adjustable depth)
Shipping Dimensions (H x W x D)	6 x 4 x 85 in. (152.4 x 101.6 x 2159 mm)
Unit Weight	54 lb. (24.3 kg)
Shipping Weight	55 lb. (24.75 kg)
Certifications	Tested to EIA-310-D, NOM (Mexico), IEC 60297-3-100, DIN 41494, RoHS


Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.




SEE NEXT PAGE FOR DETAILED UNIT MEASUREMENTS




1111 W. 35th Street
Chicago, IL 60609 USA
773.869.1234
www.tripplite.com

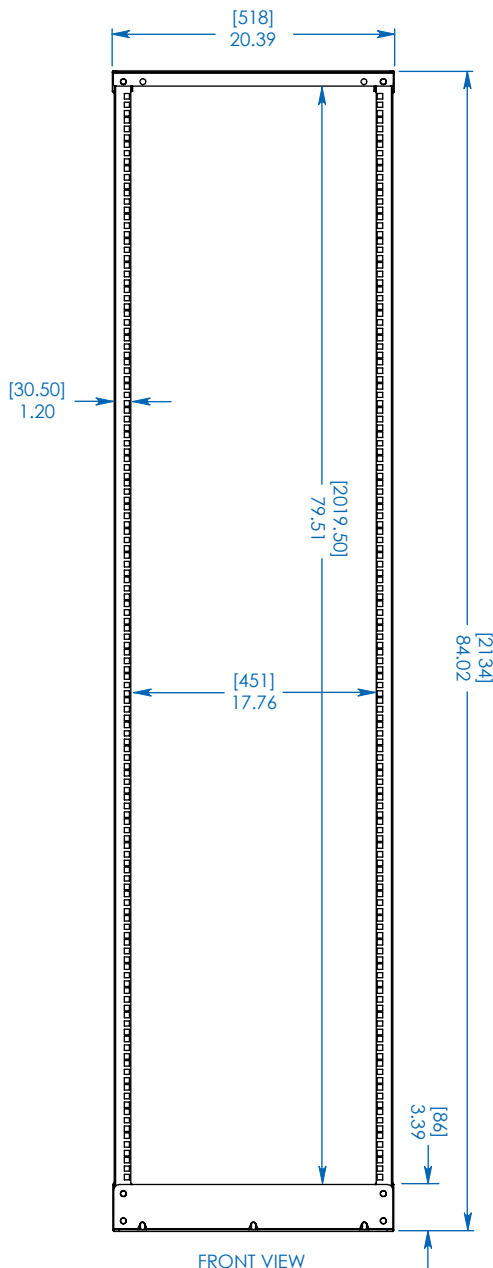

FRONT VIEW

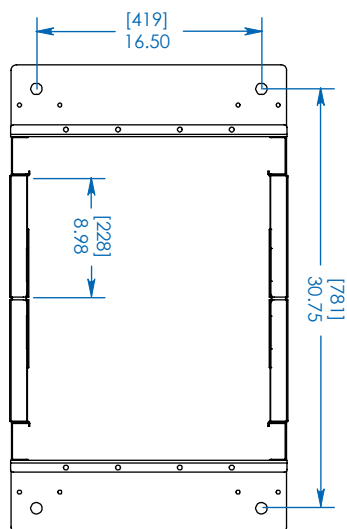

TOP VIEW

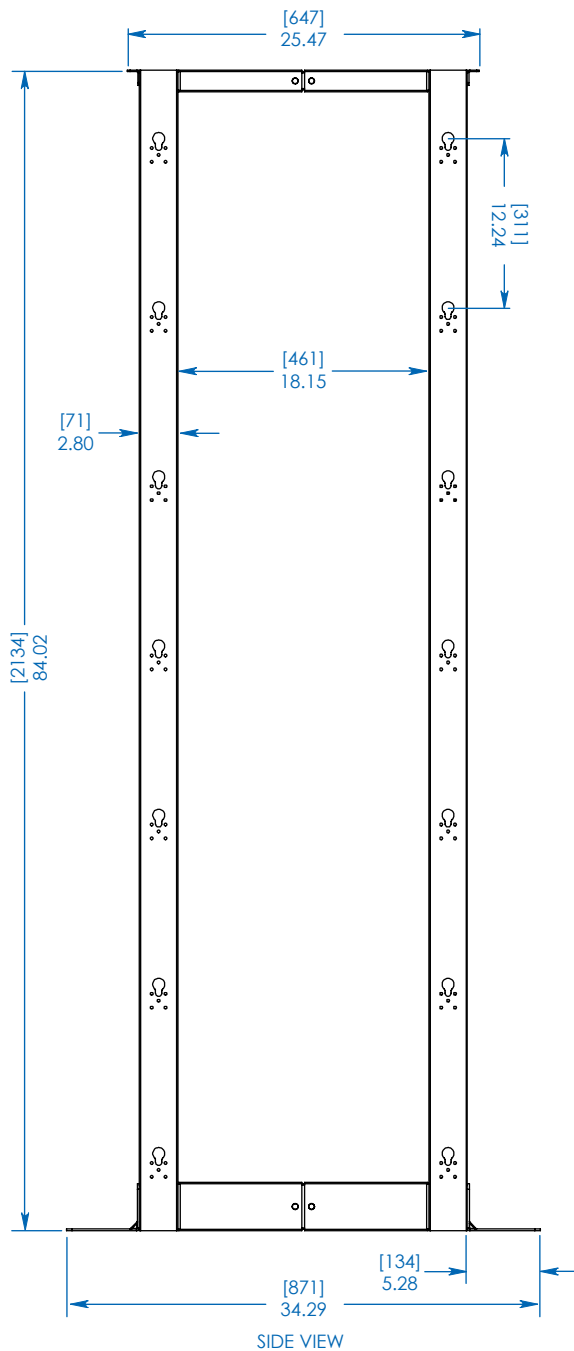

SIDE VIEW

Dimensions: [mm] INCHES

Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.

MODEL:
SR4POSTAA
TRIPP·LITE

1111 W. 35th Street
Chicago, IL 60609 USA
773.869.1234
www.tripp-lite.com