

MODEL:

SRSHELF4PHD

SmartRack® Heavy-Duty Fixed Shelf for 4-Post Racks



250 lb.
Load Capacity



25.5 in.
Platform Depth



Up to 40.75 in.
Mounting Depth




Sturdy Steel
Construction




Ventilated for
Ample Airflow

- A** 25.5 in. Platform Depth
 - B** Depth-Adjustable Mounting Brackets
 - C** Fixed Mounting Brackets
 - D** Up to 40.75 in. Mounting Depth
- Also includes mounting hardware.

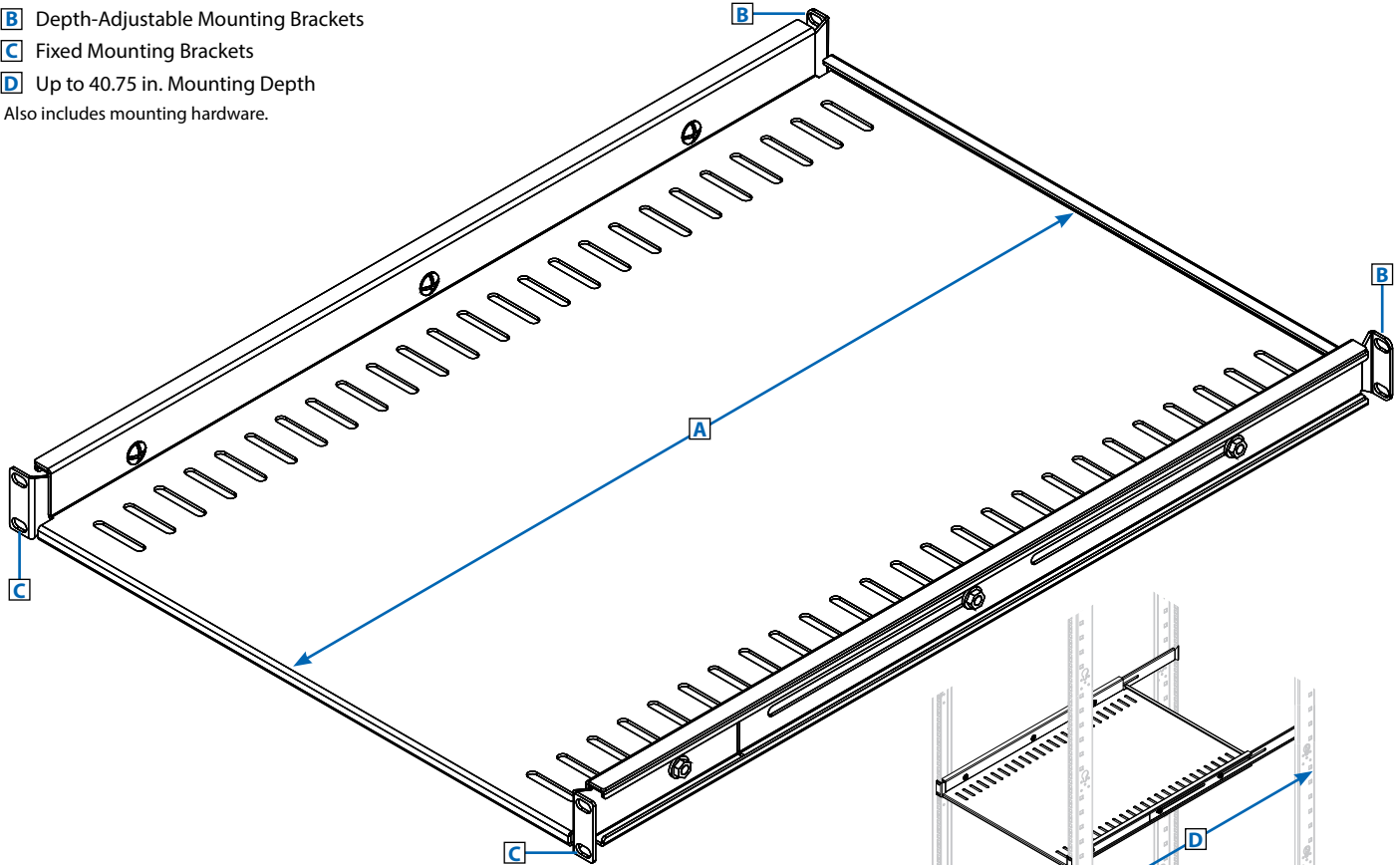

SRSHELF4PHD is a heavy-duty fixed shelf designed for installation in 4-post racks. It can support up to 250 lb. of equipment, such as tower servers and displays.

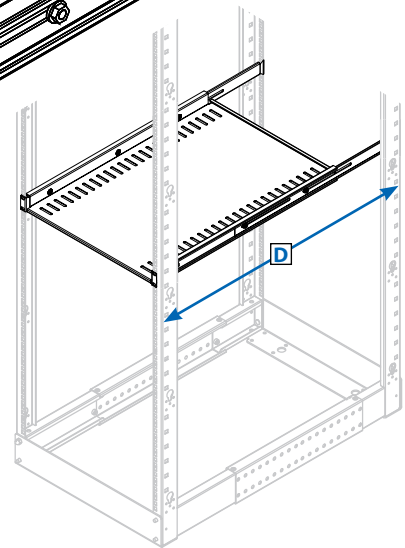

Specifications




Model	SRSHELF4PHD
Load Rating*	250 lb. / 113 kg
Mounting Depth	Fully Closed: 25.5 in. / 648 mm Fully Open: 40.75 in. / 1035 mm
Unit Dimensions (H x W x D)	1.73 x 19 x 26.1 in. / 44 x 483 x 663 mm
Shipping Dimensions (H x W x D)	4 x 20 x 27 in. / 102 x 508 x 686 mm
Unit Weight	16.5 lb. / 7.5 kg
Shipping Weight	18 lb. / 8 kg
Standards	GOST, RoHS

*The load rating includes the combined weight of the unit and installed equipment.


SEE NEXT PAGE FOR DETAILED UNIT MEASUREMENTS




1111 W. 35th Street
Chicago, IL 60609 USA
773.869.1234
www.tripplite.com

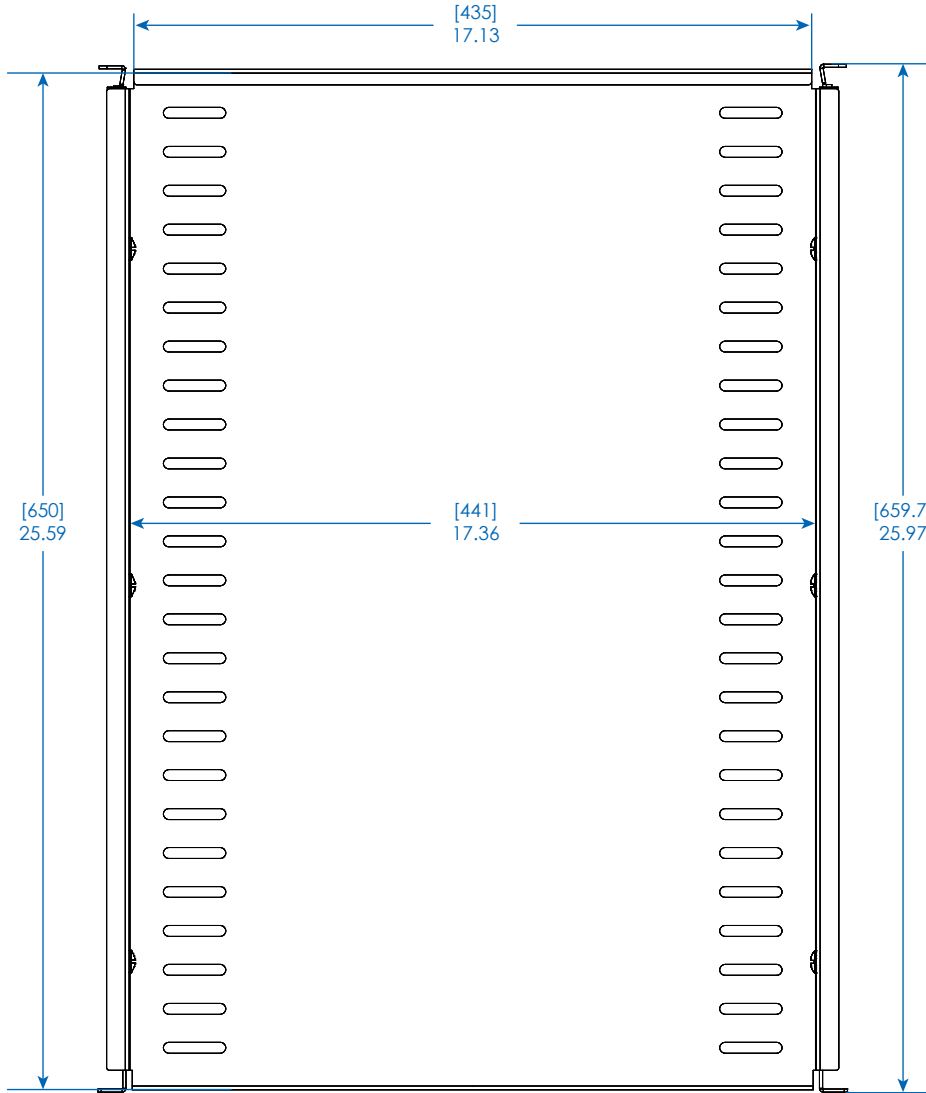

TOP VIEW

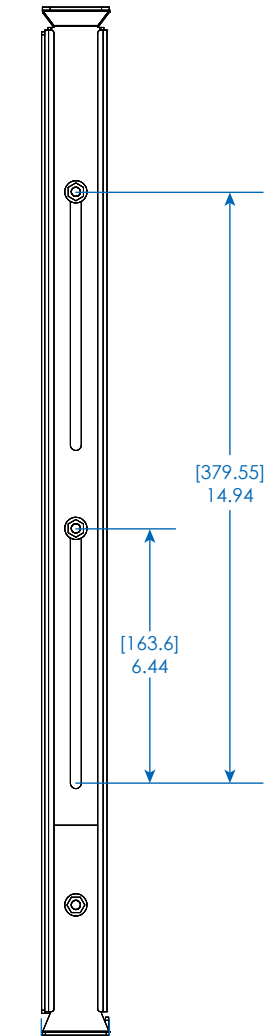

SIDE VIEW

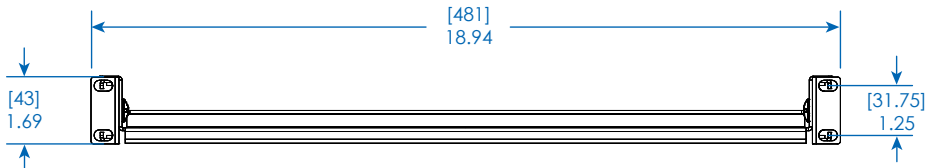

FRONT VIEW

Dimensions: [mm] INCHES

Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.

MODEL:
SRSHELF4PHD
TRIPP·LITE

1111 W. 35th Street
 Chicago, IL 60609 USA
 773.869.1234
 www.tripplite.com