

MODEL:

SRWX12USNEMA

SmartRack® Industrial Wall-Mount Rack Enclosure



12 Rack Units



90 kg
Stationary Load
Capacity



Standard
EIA
310-E
19-inch
(48.3 cm)
Rack Width



IP54
Protection
Rating



High-
Performance
Fans



SCHUKO



BS 1363



C14

Schuko, BS 1363 and C14
Power Cords Included



Hinged
Back Panel




Airflow
Exceeds
Server OEM
Requirements



Square Hole
Mounting

- A** Locking, Reversible Front Door
- B** Built-In, Removable Dust Filter
- C** High-Performance Fans
- D** Adjustable Mounting Rails
- E** Locking, Removable Side Panels
- F** Ventilating Louvers
- G** Hinged Back Panel
- H** Cable Routing Ports
- I** Keys
(For doors and side panels)

Also includes: owner's manual, rackmount equipment mounting hardware (20 cage nuts, 20 mounting screws, 20 nylon cup washers) and 1 removable/replaceable dust filter.

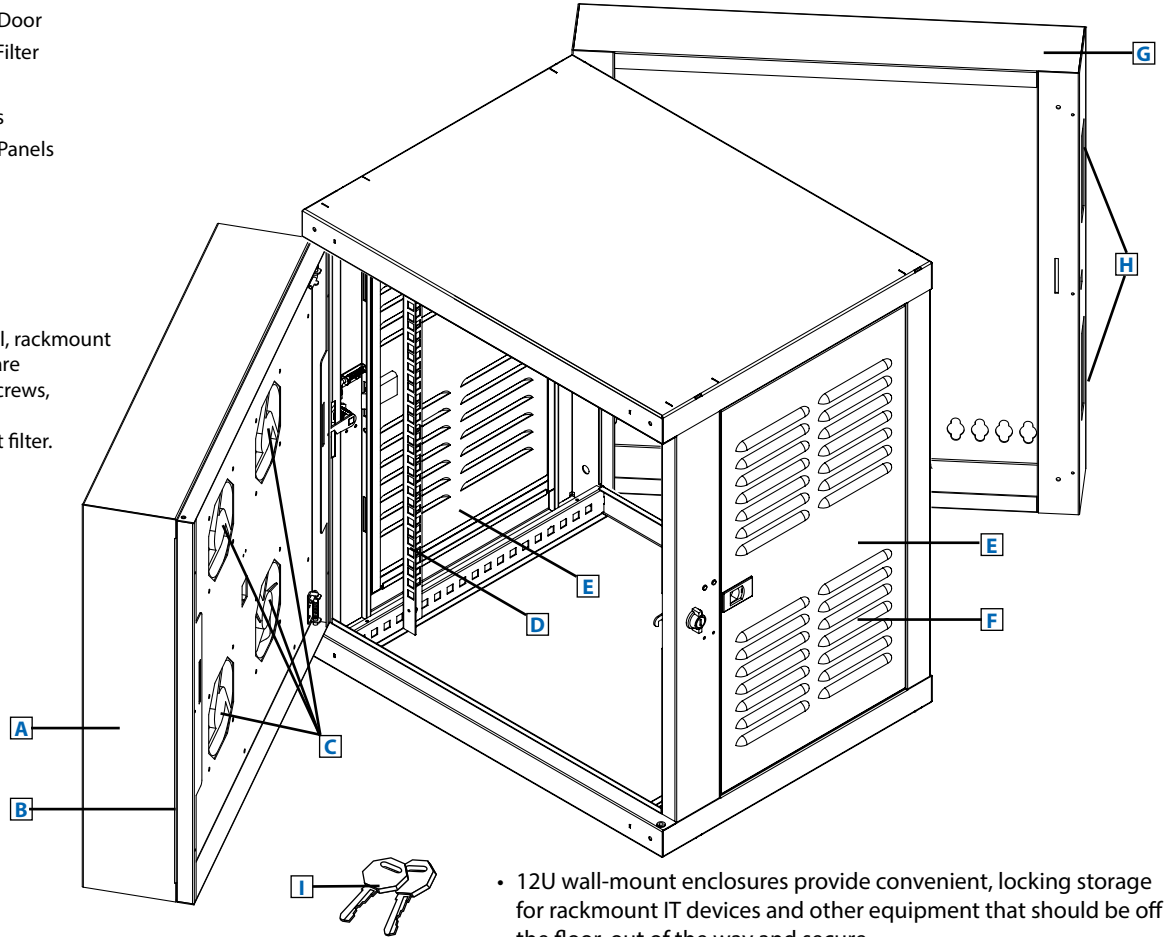

- 12U wall-mount enclosures provide convenient, locking storage for rackmount IT devices and other equipment that should be off the floor, out of the way and secure
- IP54 (NEMA 12) protection rating: sealed, locking enclosure protects against dust, falling dirt, drips and splashes
- Louvered side panels and front door with built-in replaceable dust filter maintains clean airflow by preventing airborne contaminants from entering the enclosure cabinet
- 4 high-performance intake fans

SEE NEXT PAGE FOR DETAILED UNIT MEASUREMENTS




1111 W. 35th Street
Chicago, IL 60609 USA
773.869.1234
www.tripplite.com

Specifications


Models	SRWX12USNEMA
Rack Spaces	12U
Equipment Mounting Depth	Up to 521 mm
Load Rating*	90.7 kg
Unit Dimensions (H x W x D)	637 x 624 x 545 mm
Shipping Dimensions (H x W x D)	734 x 753 x 692 mm
Unit Weight	27 kg
Shipping Weight	39 kg
Standards	Tested to EIA/ECA-310-E, IEC 60297-3-100, IP54, RoHS

*The load rating includes the combined weight of the unit and installed equipment. The unit must be mounted to a stable surface with user-supplied anchors capable of bearing the full load.




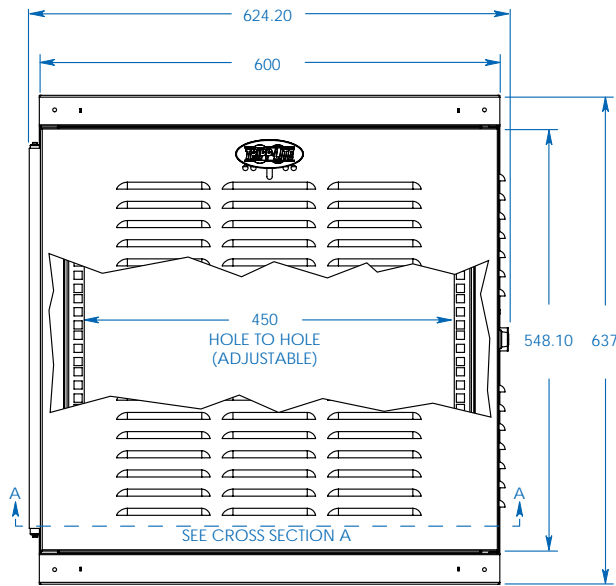


FRONT VIEW

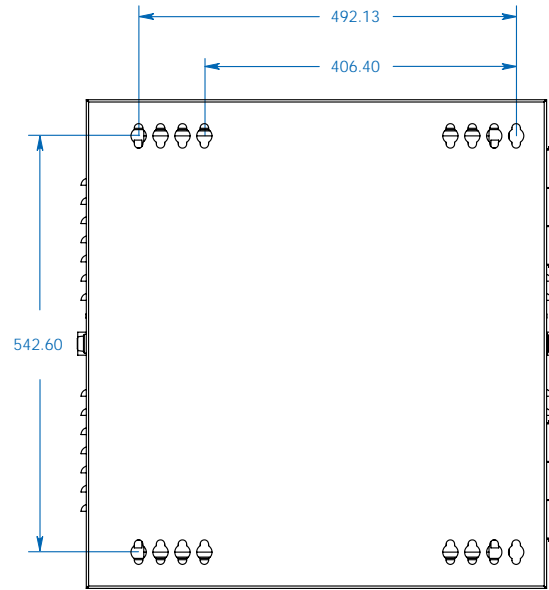


REAR VIEW

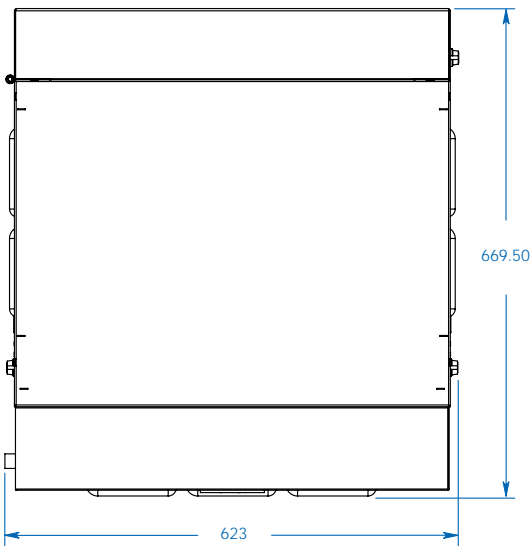

TOP VIEW

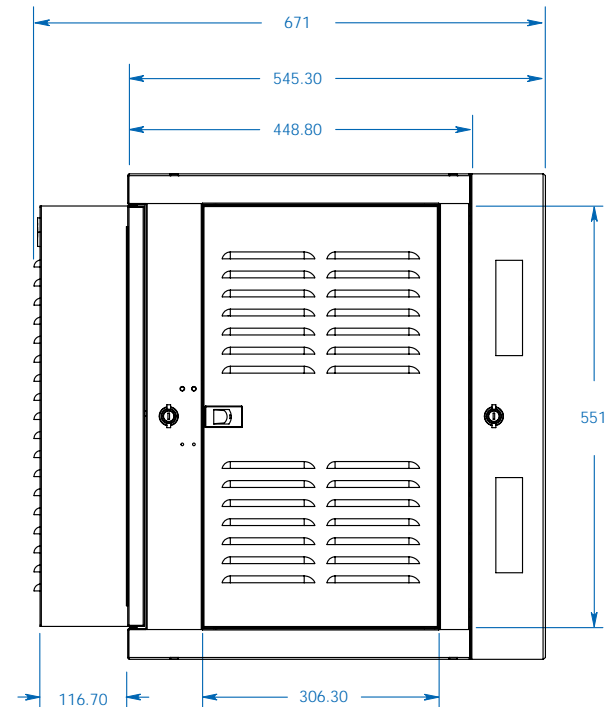

SIDE VIEW

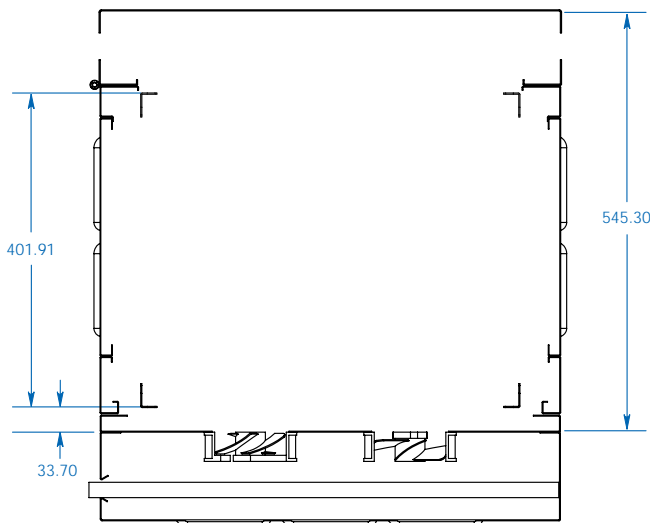

CROSS SECTION A
USABLE MOUNTING DEPTH

Dimensions: mm

Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.

MODEL:
SRWX12USNEMA
TRIPP·LITE

1111 W. 35th Street
Chicago, IL 60609 USA
773.869.1234
www.tripplite.com