

MODEL:

SR42UBDP48

SmartRack® Premium Extra-Deep Rack Enclosure



42 Rack Units



3,000 lb.
Stationary
Load Capacity



2,250 lb.
Rolling
Load Capacity



Heavy-Duty
Casters



Locking Doors &
Side Panels



48 in. Depth



Toolless
Mounting Slots



Adjustable
Rails with
Easy-View
Depth Index



Airflow
Exceeds
Server OEM
Requirements




Integrated
Baying Tabs



Square Hole
Mounting

- A** Adjustable Mounting Rails (4)
- B** Adjustable PDU Mounting Rails with Toolless Mounting Slots (2)
- C** Roof Panel (Removable)
- D** Front Door (Lockable/Removable/Reversible)
- E** Split Rear Doors (Lockable/Removable)
- F** Modular Side Panels (Lockable/Removable)
- G** Baying Tabs
- H** Heavy-Duty Casters (4)
- I** Heavy-Duty Levelers (4)
- J** Keys (for doors and side panels)

Also includes: owner's manual, 2 shipping/stabilizing brackets and equipment mounting hardware (50 M6 cage nuts, 50 M6 mounting screws, 50 M6 washers).

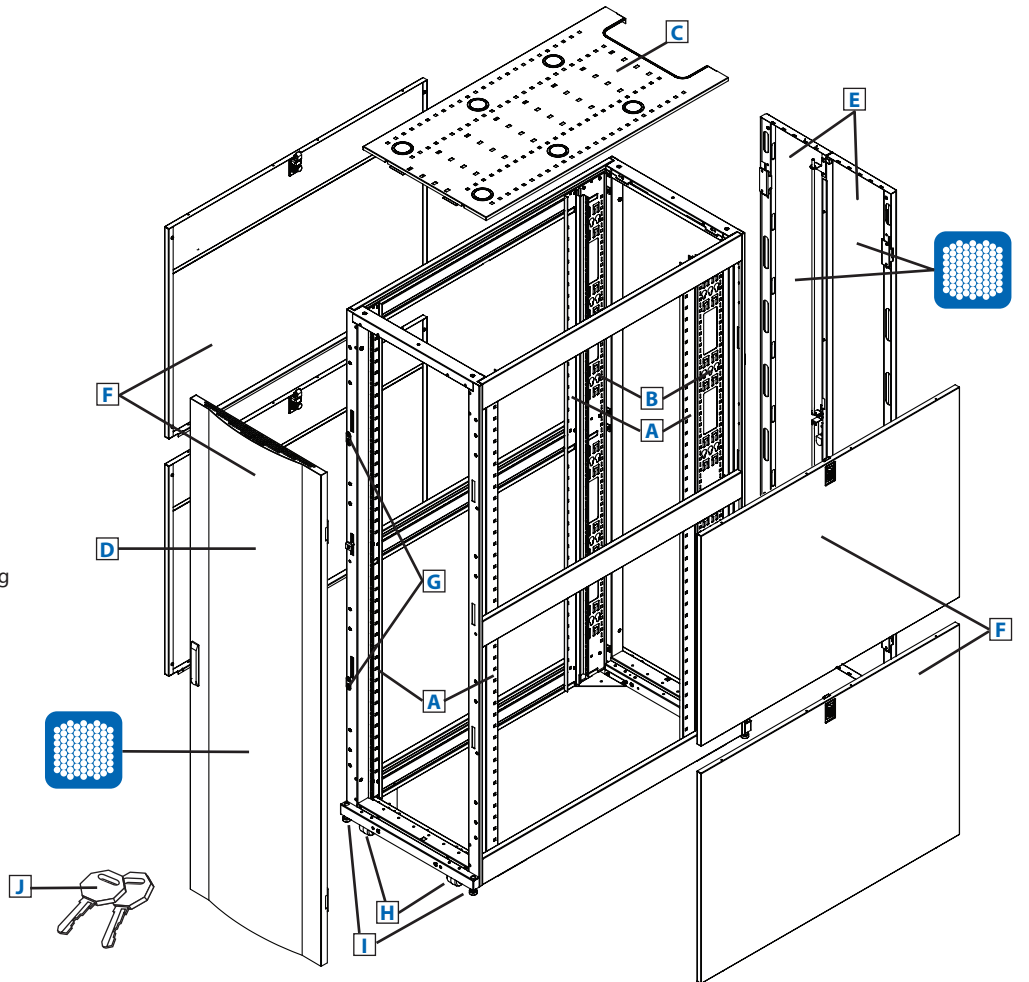

- Enclosure ships fully assembled for rapid deployment but can be knocked down for easy reassembly in confined spaces
- Extra cable management space for high-density server/network applications
- Extra room to remove hot-swap power supplies from the rear of mounted devices
- Ideal for rack-mount server, network and telecom applications


SEE NEXT PAGE FOR DETAILED UNIT MEASUREMENTS

Specifications


Model	SR42UBDP48
Rack Spaces	42U
Stationary Load Rating	3,000 lb. (1363 kg)
Rolling Load Rating	2,250 lb. (1022 kg)
Unit Dimensions (H x W x D)	78.5 x 23.6 x 51.3 in. / 1994 x 600 x 1303 mm
Shipping Dimensions (H x W x D)	85 x 33.5 x 52.75 in. / 2159 x 851 x 1340 mm
Unit Weight	315 lb. (143 kg)
Shipping Weight	397 lb. (180 kg)
Standards	CE (Europe), RoHS, UL 60950-1




TRIPP-LITE
by **EATON**

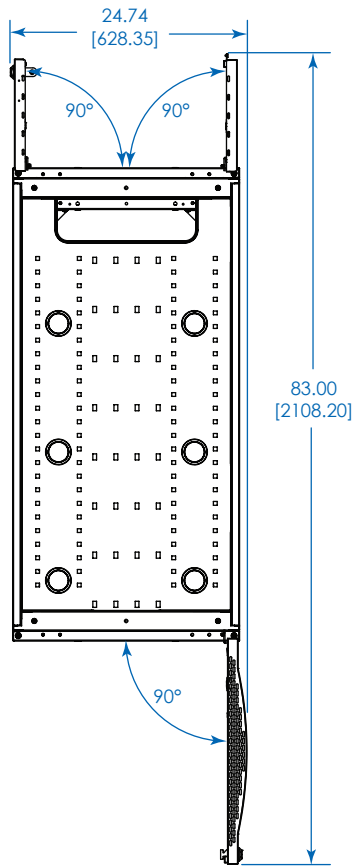

TOP VIEW

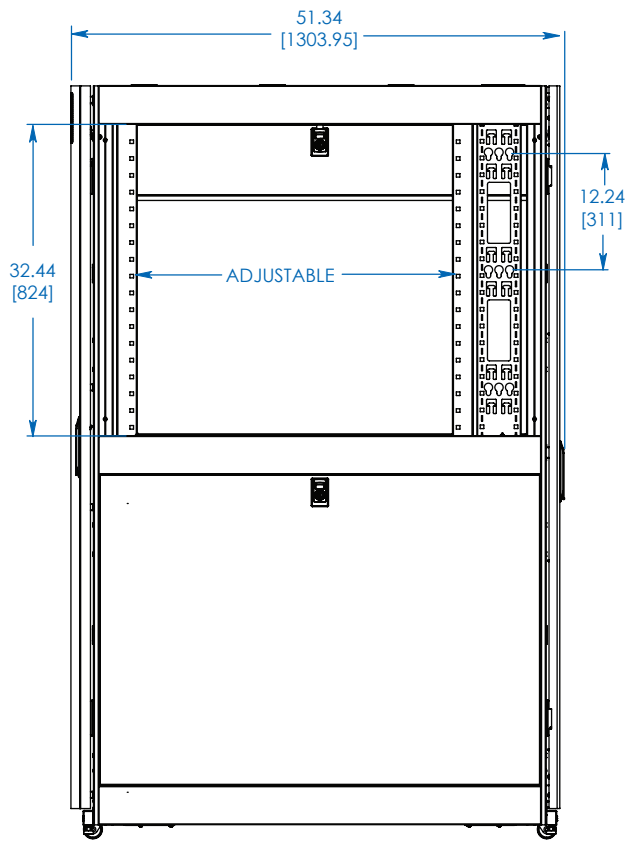


SIDE VIEW

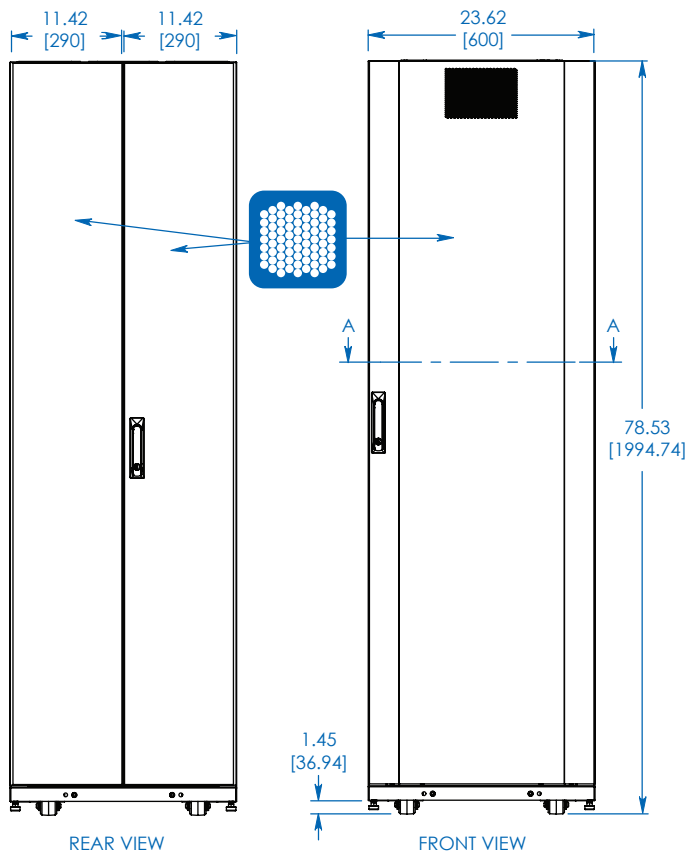

REAR VIEW

FRONT VIEW

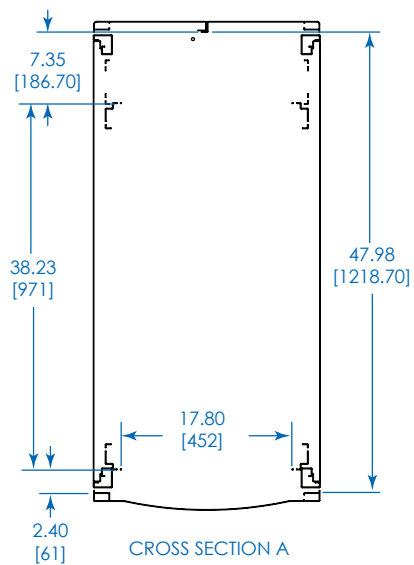


CROSS SECTION A


Model:
SR42UBDP48

TRIPP-LITE
by **EAT•N**


Dimensions: inches [mm]

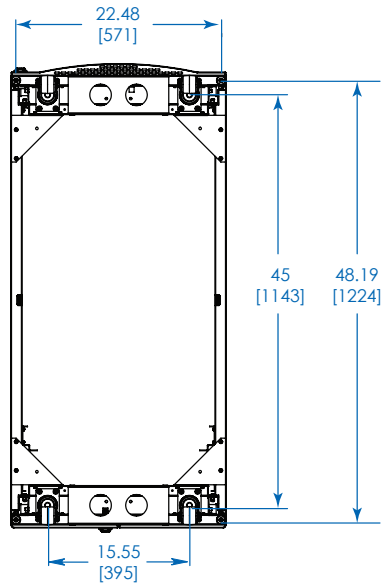


BOTTOM VIEW

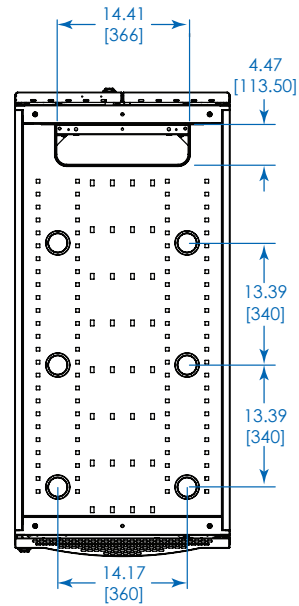


TOP VIEW

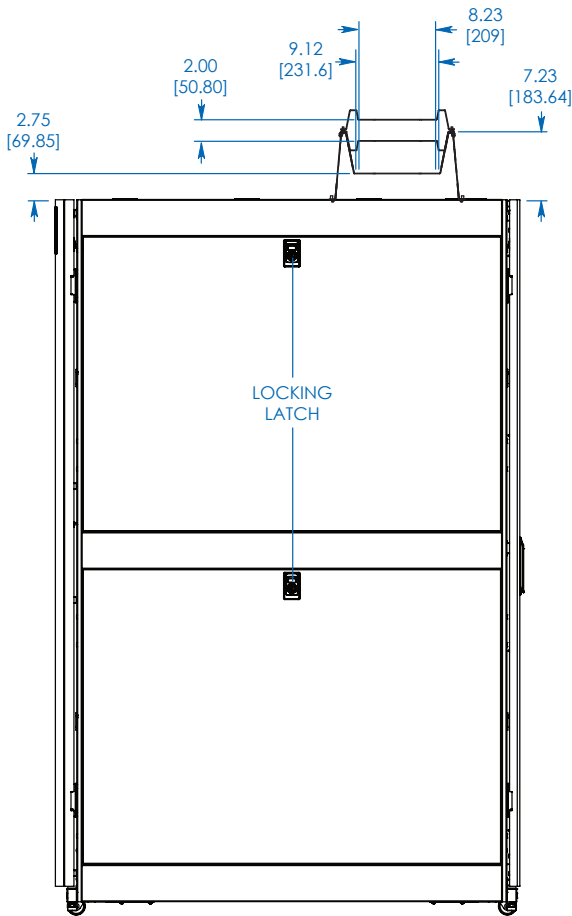

SIDE VIEW

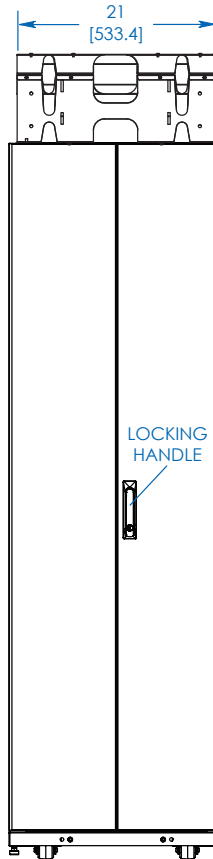

REAR VIEW

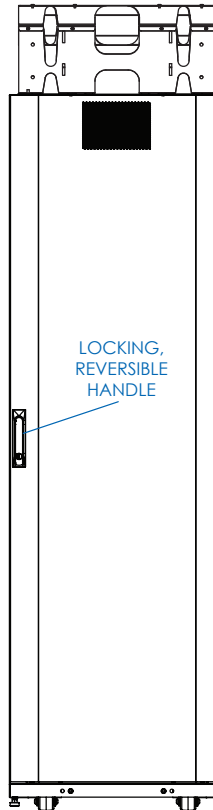

FRONT VIEW

OPTIONAL **SR**CABLETRAY AND **SR**CABLETRAYEXP CABLE MANAGEMENT ACCESSORIES SHOWN (MOUNTING POSITION ADJUSTS TO ACCOMMODATE A WIDE RANGE OF APPLICATIONS)

Model:
SR42UBDP48

TRIPP-LITE
by **EATON**

1111 W. 35th Street
Chicago, IL 60609 USA
773.869.1234
tripplite.com

Dimensions: inches [mm]

We have a policy of continuous improvement. Specifications are subject to change without notice.
Photos and illustrations may differ slightly from actual products.

About Tripp Lite by Eaton

Tripp Lite joined the Eaton family in March 2021. Eaton has long been a premier name in backup power and power management. The acquisition of Tripp Lite transforms Eaton's distributed IT infrastructure and connectivity equipment capabilities. Combining our product strengths and expert personnel allows us to offer comprehensive and innovative solutions for critical power and digital infrastructure applications, backed by quality, service and support you can trust. Learn more at tripplite.com/byEaton.