

SmartRack® 45U Deep and Wide Rack Enclosure Cabinet, Black (SR45UBDPWD)



45 Rack Units



3500 lb. Stationary Load Rating



2250 lb. Rolling Load Rating



Heavy-Duty Casters



Locking Doors and Side Panels



 
Accommodates Standard 19 in. Equipment




Toolless Mounting Slots




Adjustable Rails with Easy-View Depth Index



Airflow Exceeds Server OEM Requirements

 


Integrated Bypassing Tabs

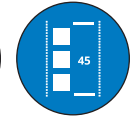

Square-Hole Mounting

- A Adjustable Mounting Rails**
- B Adjustable PDU Mounting Rails with Toolless Mounting Slots**
- C Roof Panel** (Removable)
- D Front Door** (Lockable/Removable/Reversible)
- E Split Rear Doors** (Lockable/Removable)
- F Side Panels** (Lockable/Removable)
- G Heavy-Duty Casters**
- H Heavy-Duty Levelers**
- I Keys** (For Doors and Side Panels)

Also Includes: Owner's manual, 2 stabilizing brackets and rack equipment mounting hardware (50 cage nuts, 50 mounting screws and 50 nylon cup washers)

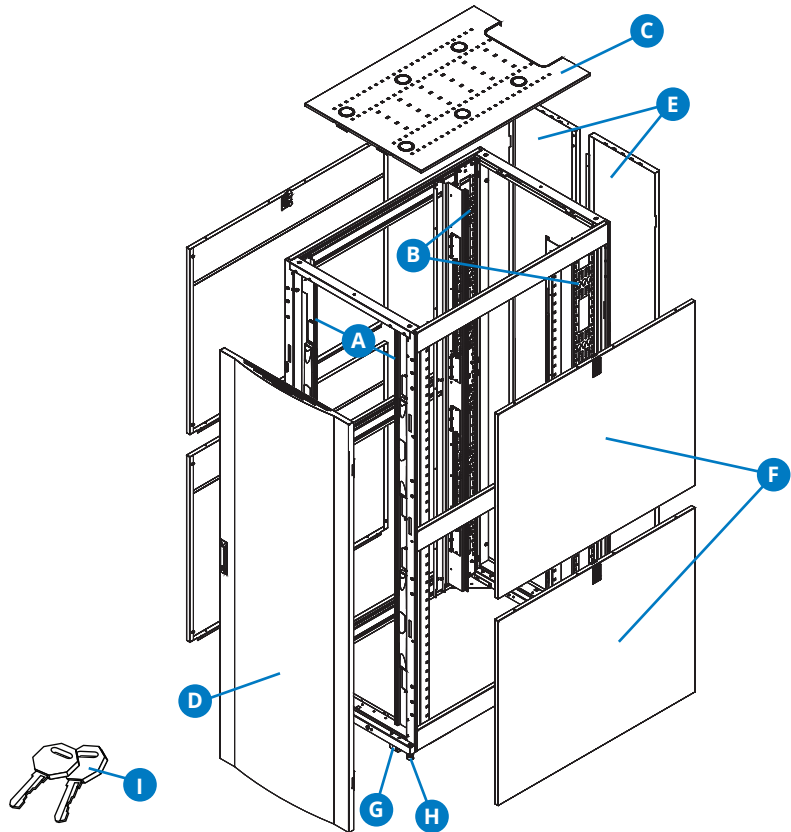


SPECIFICATIONS

| | |
|---------------------------------|--|
| Model | SR45UBDPWD |
| Rack Spaces | 45U |
| Stationary Load Rating | 3500 lb. / 1588 kg |
| Rolling Load Rating | 2250 lb. / 1022 kg |
| Unit Dimensions (H x W x D) | 83.76 x 29.53 x 48.55 in. / 2128 x 750 x 1233 mm |
| Shipping Dimensions (H x W x D) | 90.3 x 32 x 53 in. / 2294 x 813 x 1340 mm |
| Unit Weight | 370 lb. / 168 kg |
| Certifications | UL 60950-1, DIN 41494, IP20, TIA/EIA-310-D (Accommodates all standard 19 in. rack-mount equipment regardless of vendor) |


Part numbers and specifications are subject to change.




Powering Business Worldwide

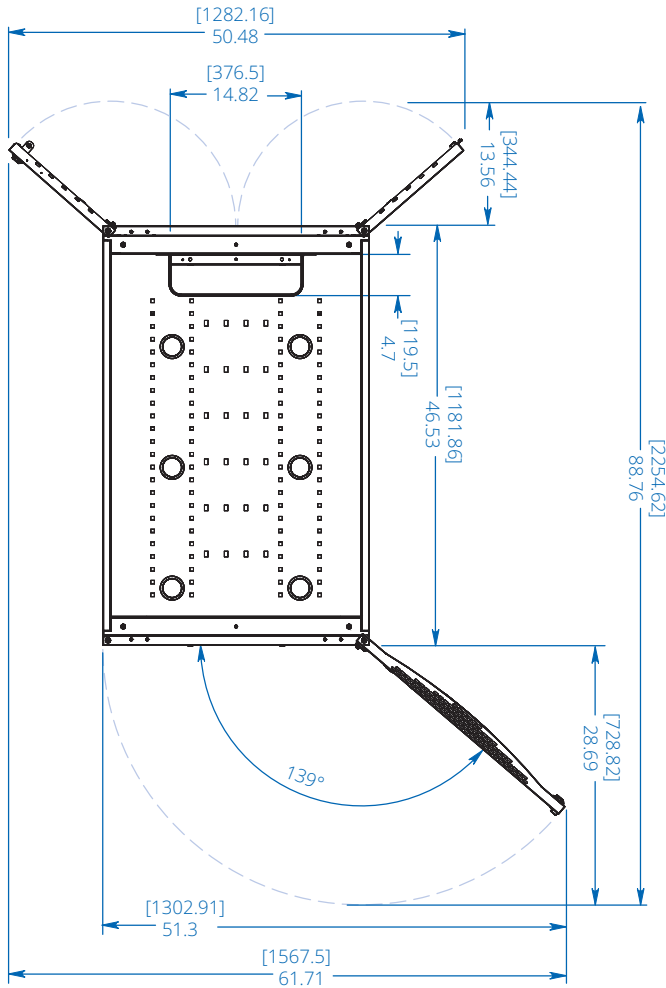


TOP VIEW

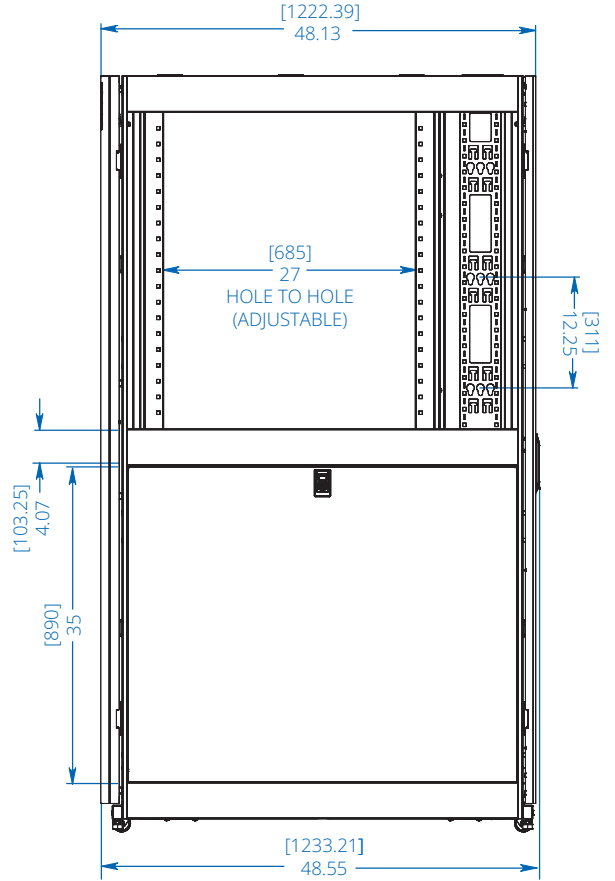

SIDE VIEW




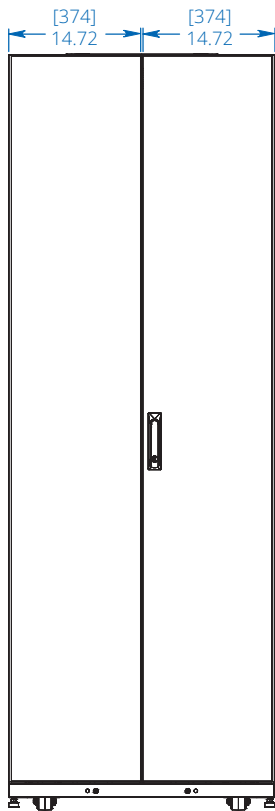


REAR VIEW

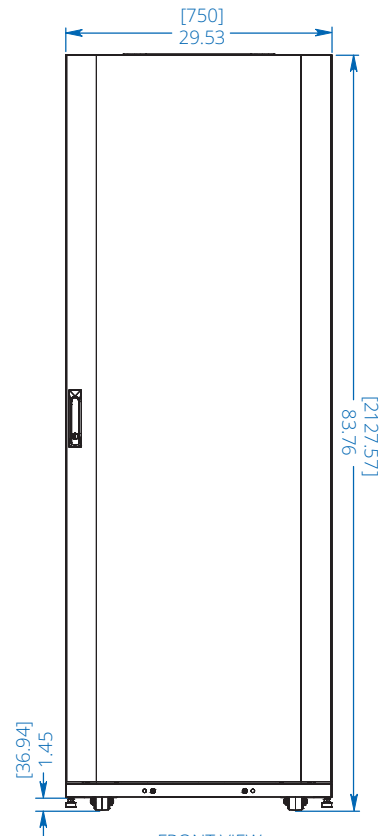

FRONT VIEW

Dimensions: INCHES [mm]

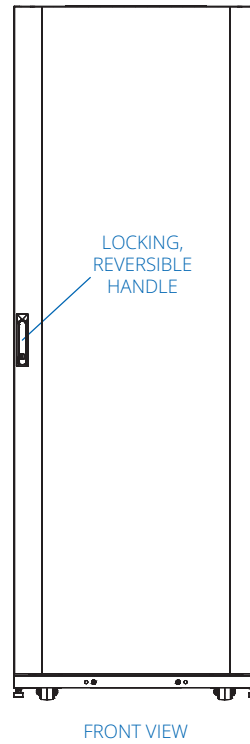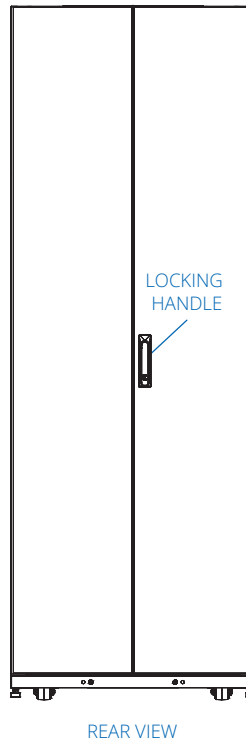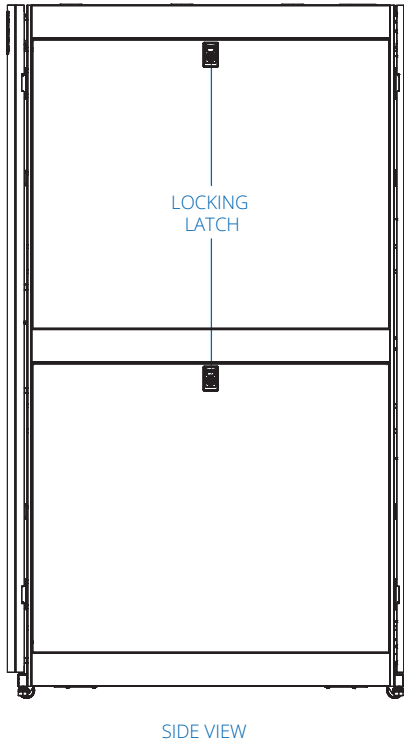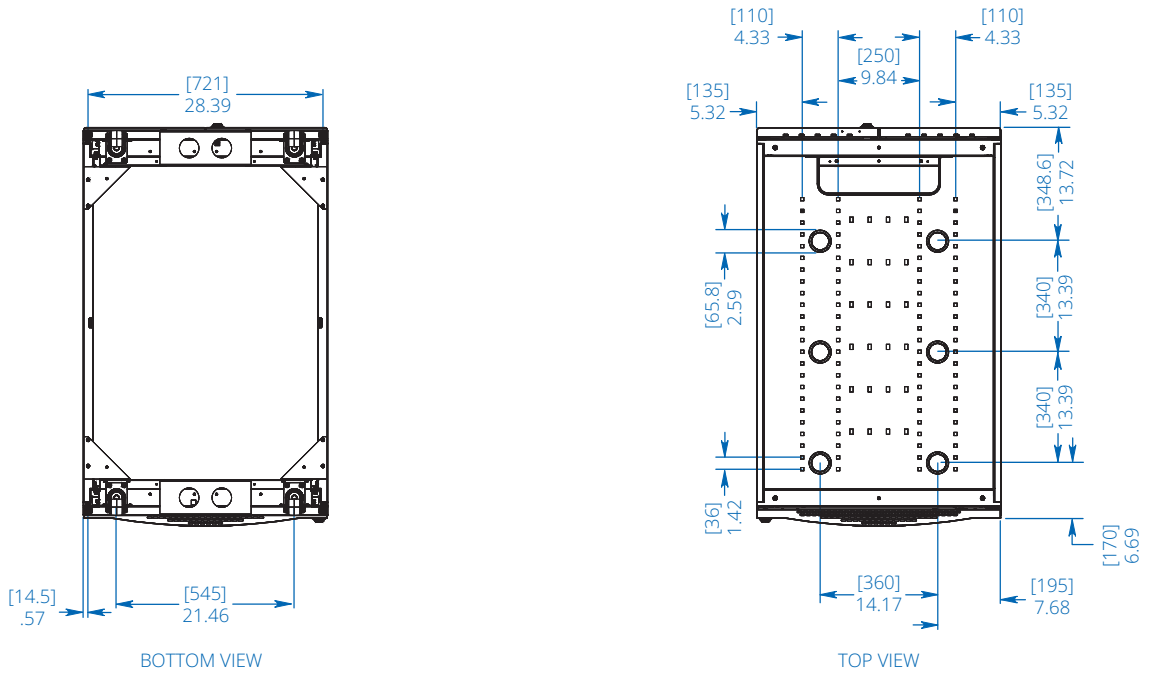

Dimensions: INCHES [mm]

Learn more at [Tripplite.Eaton.com](https://www.Tripplite.Eaton.com)



Eaton
 1000 Eaton Boulevard
 Cleveland, OH 44122
 United States
 Eaton.com

© 2025 Eaton
 All Rights Reserved
 23-11-072
 January 2025

No part of this document may be reproduced in any way without the express written approval of Eaton.

Eaton reserves the right to change specifications without prior notice. Eaton is a registered trademark of Eaton. All other trademarks are properties of their respective companies.

Follow us on social media to get the latest product and support information.

