

MODEL:

# SR50UB

## SmartRack® Premium 50U Standard-Depth Rack Enclosure Cabinet



50 Rack Units



3000 lb.  
Stationary  
Load Capacity



2250 lb.  
Rolling  
Load Capacity



Heavy-Duty  
Casters



Locking Doors &  
Side Panels



Standard  
19-inch  
Rack Width



Toolless  
Mounting Slots



 
Adjustable  
Rails with  
Easy-View  
Depth Index



Airflow  
Exceeds  
Server OEM  
Requirements




Integrated  
Baying Tabs



Square Hole  
Mounting

- A** Adjustable Mounting Rails
- B** Adjustable PDU Mounting Rails with Toolless Mounting Slots
- C** Roof Panel (Removable)
- D** Front Door (Lockable/Removable/Reversible)
- E** Split Rear Doors (Lockable/Removable)
- F** Side Panels (Lockable/Removable)
- G** Heavy-Duty Casters
- H** Heavy-Duty Levelers
- I** Keys (For doors and side panels.)

Also Includes: Owner's manual, 2 shipping/stabilizing brackets and equipment mounting hardware (50 cage nuts, 50 mounting screws, 50 nylon cup washers).

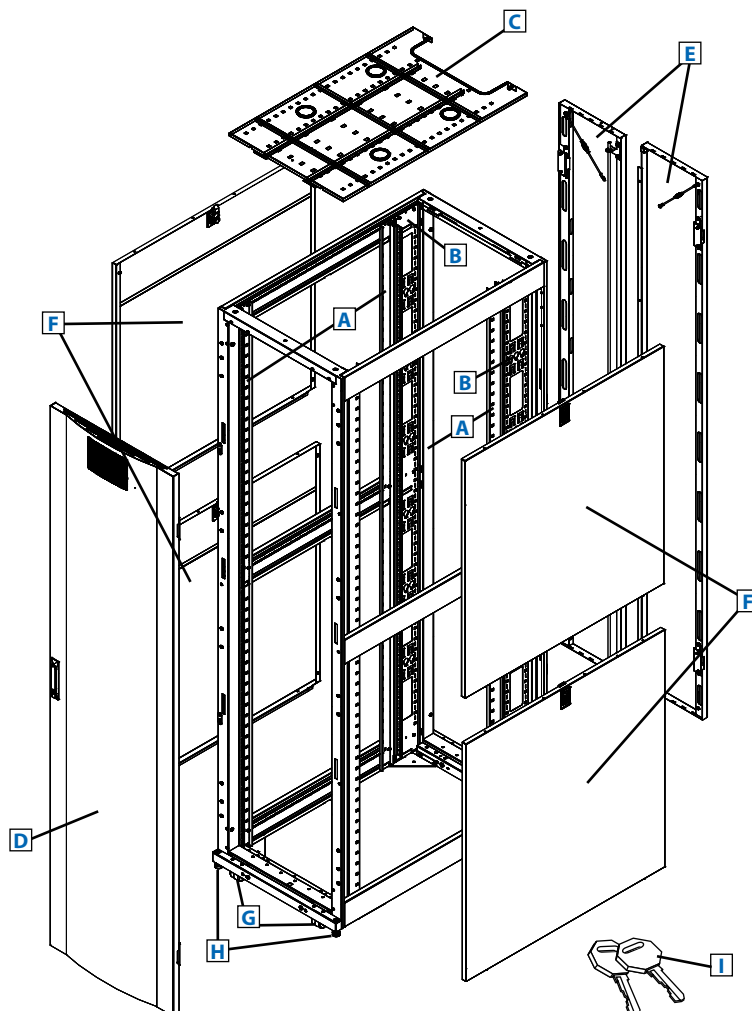

### Specifications





Model	SR50UB
Rack Spaces	50U
Stationary Load Capacity	3000 lb. (1363 kg)
Rolling Load Capacity	2250 lb. (1022 kg)
Unit Dimensions (H x W x D)	92.4 x 23.6 x 43 in. (234.75 x 60 x 109.2 cm)
Shipping Dimensions (H x W x D)	97.7 x 25.75 x 45.5 in. (248.2 x 65.4 x 115.6 cm)
Unit Weight	347.2 lb. (157.5 kg)
Shipping Weight	400.9 lb. (181.9 kg)
Certifications	UL 60950; RoHS; CE; IP20; EIA/ECA-310-E Compliant (Accommodates all standard 19-inch rack-mount equipment regardless of vendor.)



- Ships fully assembled for rapid deployment, but can be knocked down for easy reassembly in confined spaces
- Modular design optimized for quick configuration and reconfiguration
- Ideal for high-density server and IT networking areas

**SEE NEXT PAGE FOR DETAILED UNIT MEASUREMENTS**


**TRIPP-LITE**  
by **EATON**

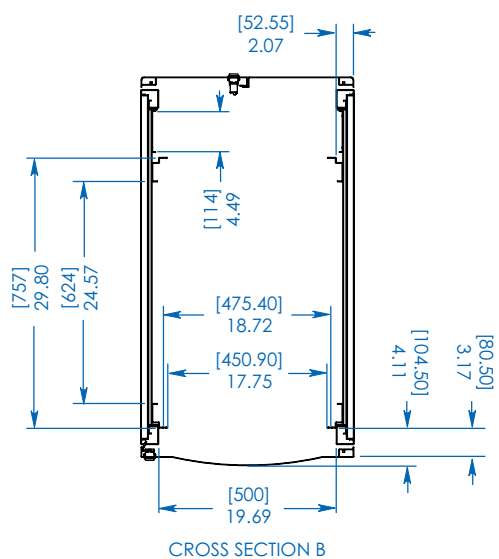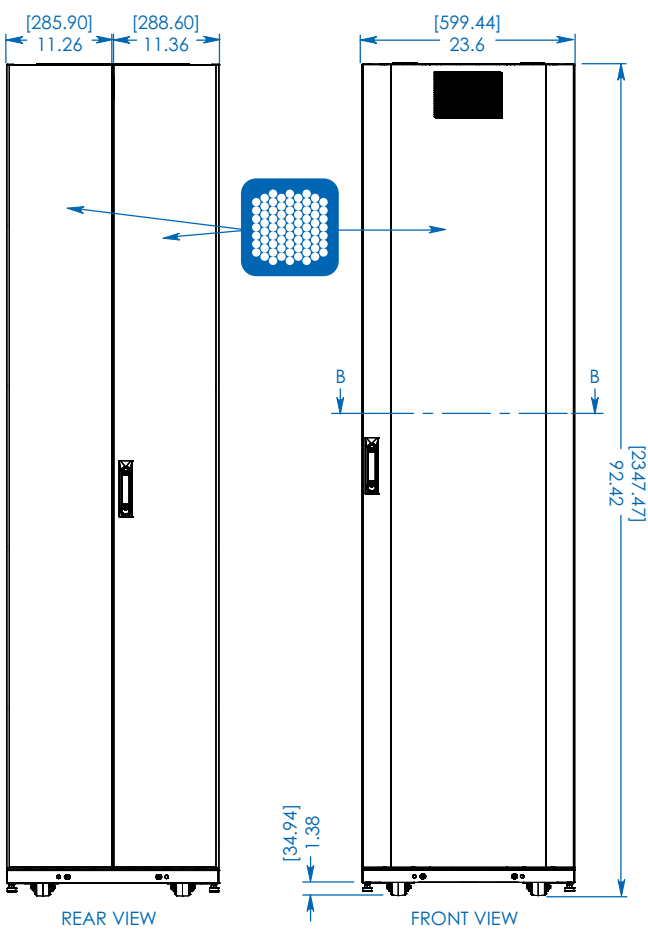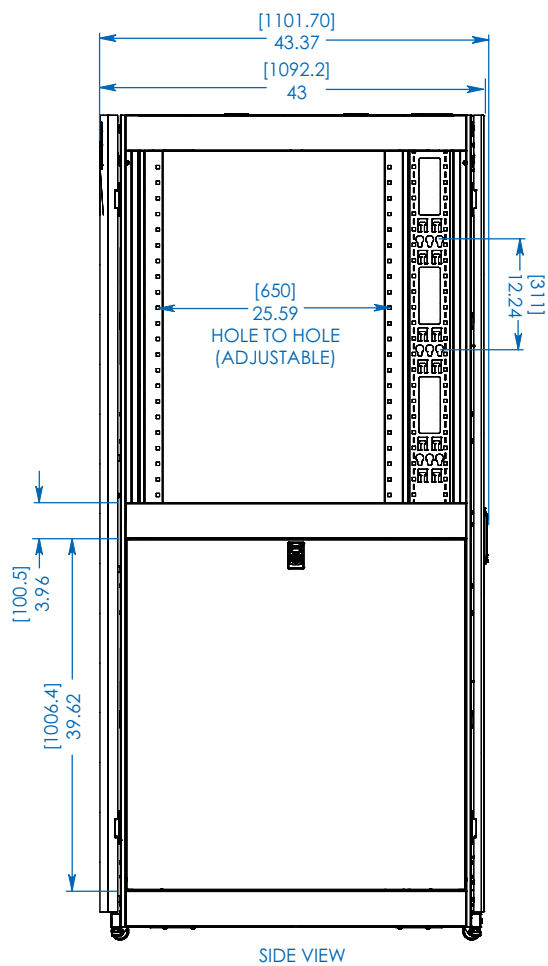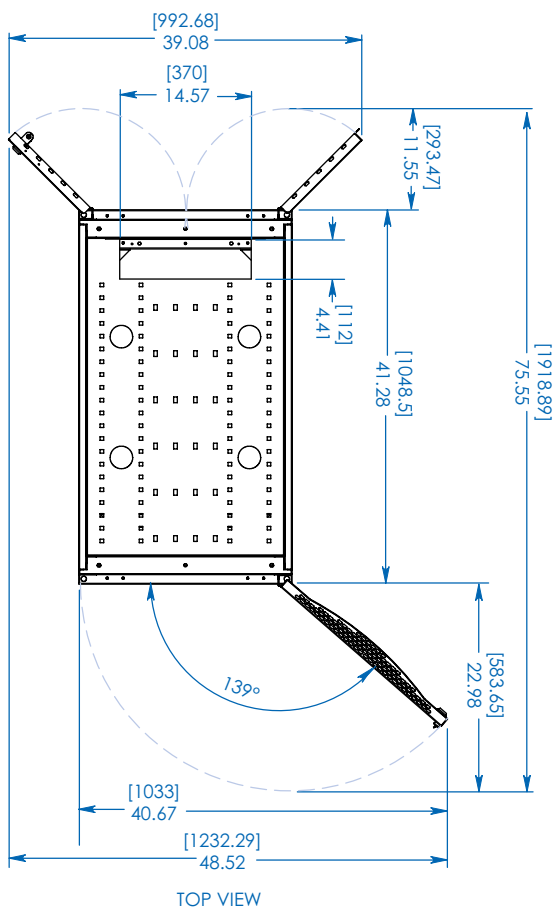


Model:  
**SR50UB**

**TRIPP·LITE**  
by **EAT·N**


Dimensions: [mm] INCHES

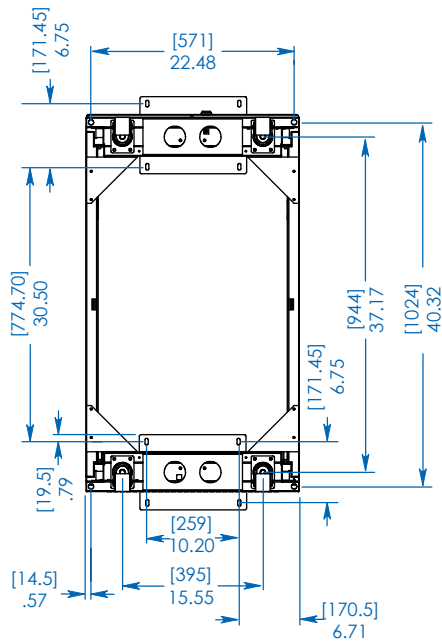


BOTTOM VIEW

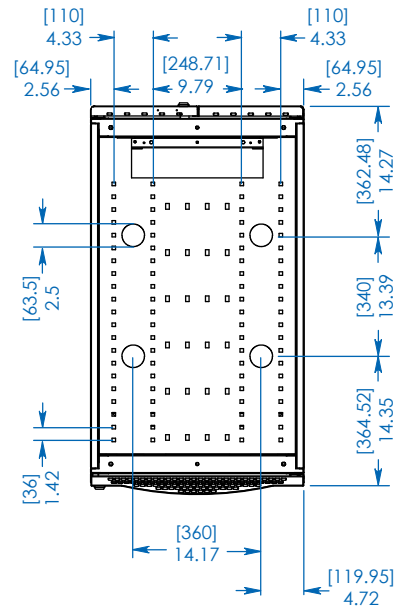


TOP VIEW

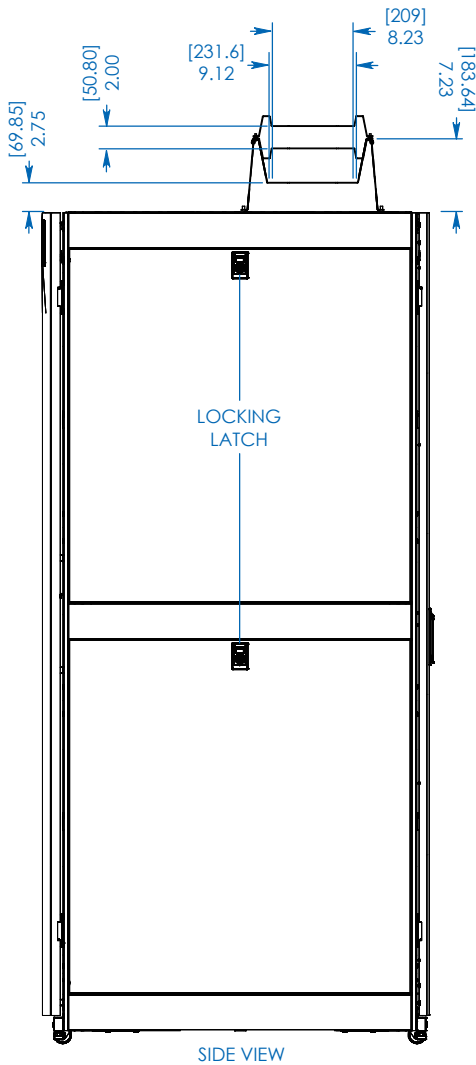

SIDE VIEW

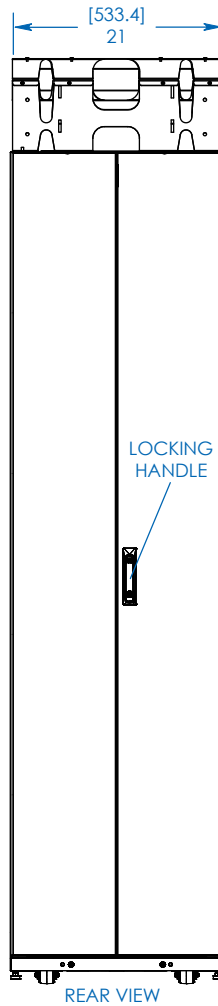

REAR VIEW

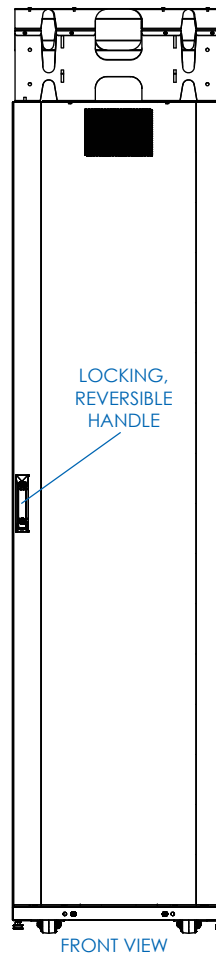

FRONT VIEW

OPTIONAL **SRCABLETRAY** AND **SRCABLETRAYEXP** CABLE MANAGEMENT ACCESSORIES SHOWN (MOUNTING POSITION ADJUSTS TO ACCOMMODATE A WIDE RANGE OF APPLICATIONS)

Model:  
**SR50UB**

**TRIPP-LITE**  
by **EATON**

1111 W. 35th Street  
Chicago, IL 60609 USA  
773.869.1234  
triplite.com

Dimensions: [mm] INCHES

We have a policy of continuous improvement. Specifications are subject to change without notice. Photos and illustrations may differ slightly from actual products.

#### About Tripp Lite by Eaton

Tripp Lite joined the Eaton family in March 2021. Eaton has long been a premier name in backup power and power management. The acquisition of Tripp Lite transforms Eaton's distributed IT infrastructure and connectivity equipment capabilities. Combining our product strengths and expert personnel allows us to offer comprehensive and innovative solutions for critical power and digital infrastructure applications, backed by quality, service and support you can trust. Learn more at [triplite.com/byEaton](https://triplite.com/byEaton).