

MODEL:

SR55UB

SmartRack® Premium 55U Standard-Depth Rack Enclosure Cabinet



55 Rack Units



3,000 lb.
Stationary
Load Capacity



2,250 lb.
Rolling
Load Capacity



Heavy-Duty
Casters



Locking Doors &
Side Panels



Standard
19 in.
Rack Width



Toolless
Mounting Slots



 
Adjustable
Rails with
Easy-View
Depth Index



Airflow
Exceeds
Server OEM
Requirements



Integrated
Baying Tabs



Square Hole
Mounting

A Adjustable Mounting Rails (4)

B Adjustable PDU Mounting
Rails with Toolless Mounting Slots
(2 rails hold up to 4 vertical PDUs.)

C Roof Panel
(Removable)

D Front Door
(Lockable/Removable/Reversible)

E Split Rear Doors (2)
(Lockable/Removable/Reversible)

F Side Panels (4)
(Lockable/Removable)


G Baying Tabs

H Heavy-Duty Casters (4)

I Heavy-Duty Levelers (4)

J Keys
(For doors and side panels.)

Also Includes: Owner's manual, 2 shipping/
stabilizing brackets and rack-mount equipment
mounting hardware (50 cage nuts, 50 mounting
screws, 50 nylon cup washers).

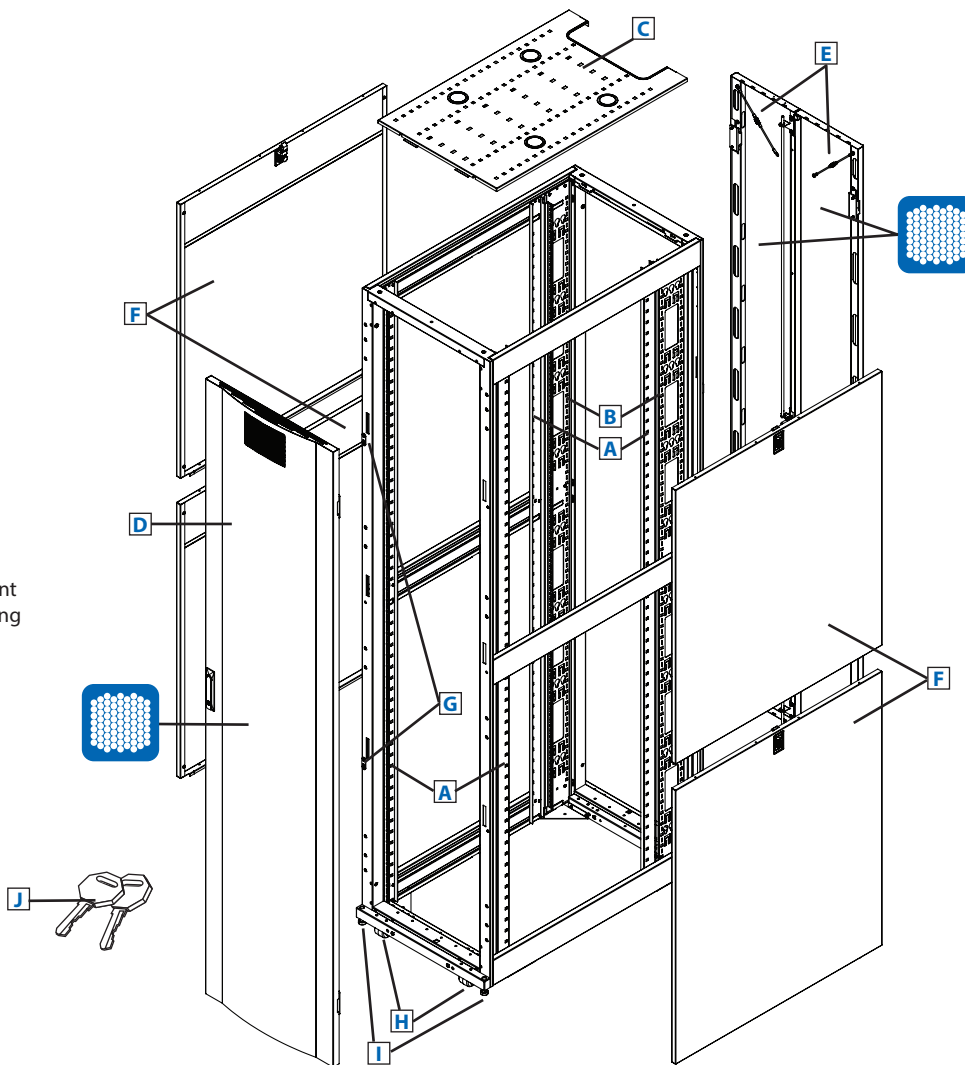

- Ships fully assembled for rapid deployment, but can be knocked down for easy reassembly in confined spaces
- Modular design optimized for quick configuration and reconfiguration
- Ideal for high-density server and IT networking areas





SEE NEXT PAGE FOR DETAILED UNIT MEASUREMENTS

Specifications

Model	SR55UB
Rack Spaces	55U
Stationary Load Capacity	3,000 lb. (1363 kg)
Rolling Load Capacity	2,250 lb. (1022 kg)
Unit Dimensions (H x W x D)	101.3 x 23.6 x 43.02 in. (2573 x 600 x 1092 mm)
Shipping Dimensions (H x W x D)	105.5 x 25.75 x 45.5 in. (2680 x 654 x 1156 mm)
Unit Weight	375.1 lb. (170.1 kg)
Shipping Weight	430.5 lb. (195.3 kg)
Certifications	UL 60950; RoHS; CE; IP20; EIA/ECA-310-E Compliant (Accommodates all standard 19-inch rack-mount equipment regardless of vendor.)




TRIPP-LITE
by **EAT•N**

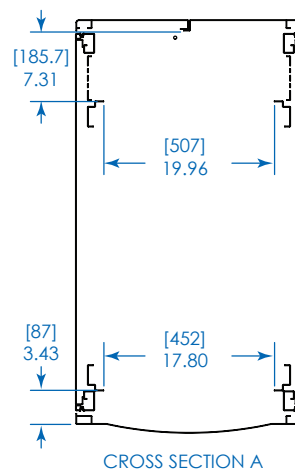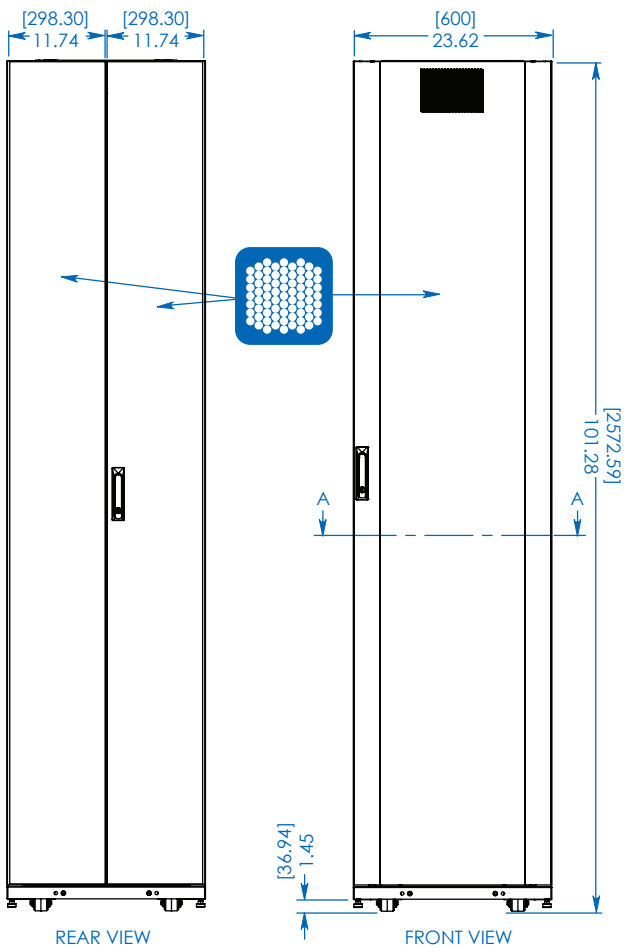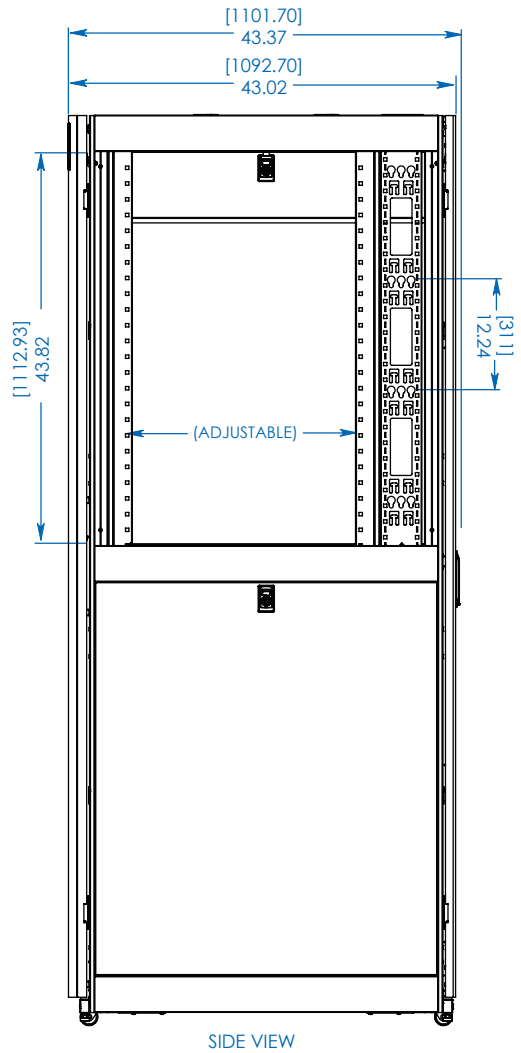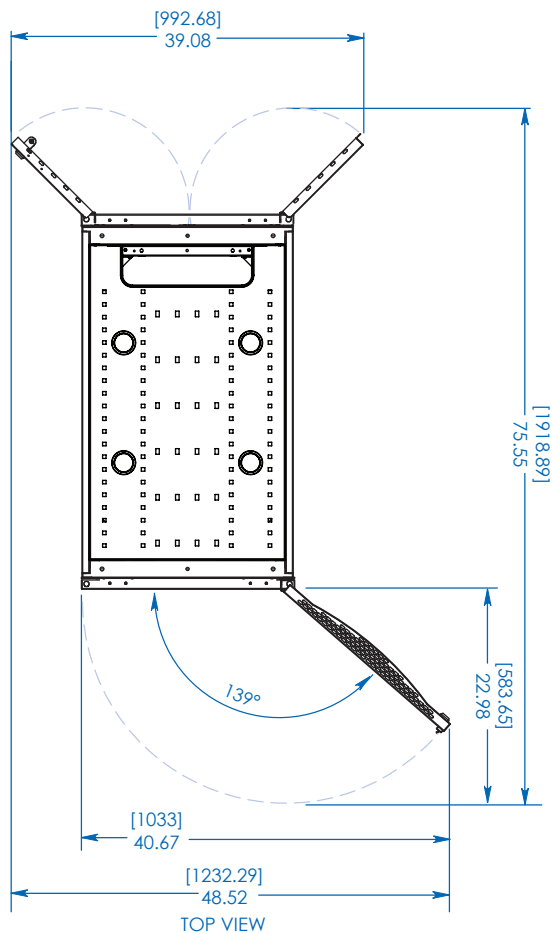


Dimensions: mm [inches]


Model:
SR55UB
TRIPP-LITE
by **EAT•N**

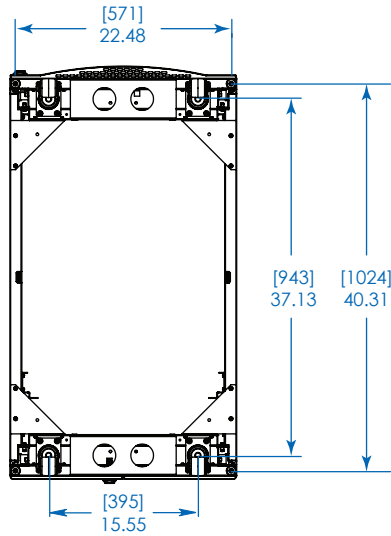


BOTTOM VIEW

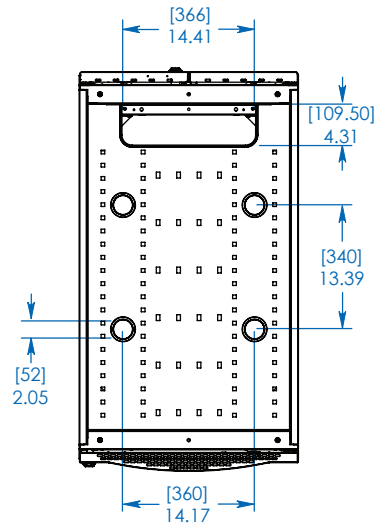


TOP VIEW

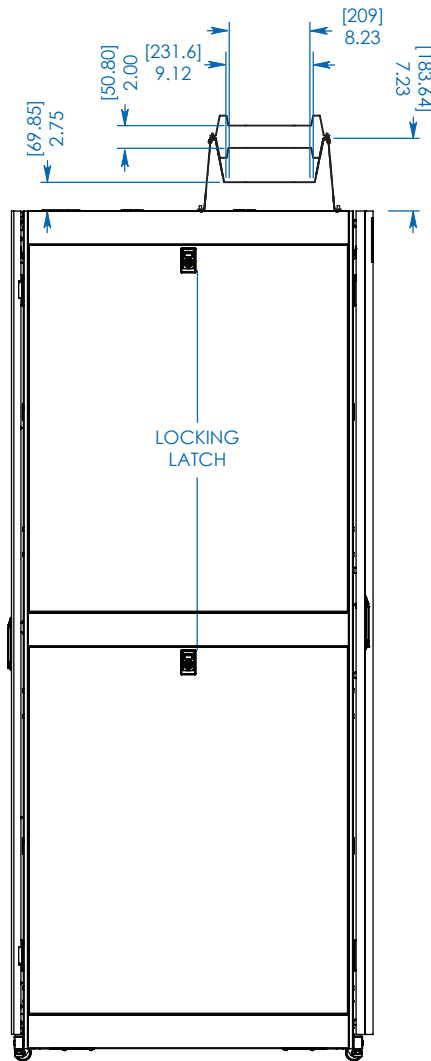

SIDE VIEW

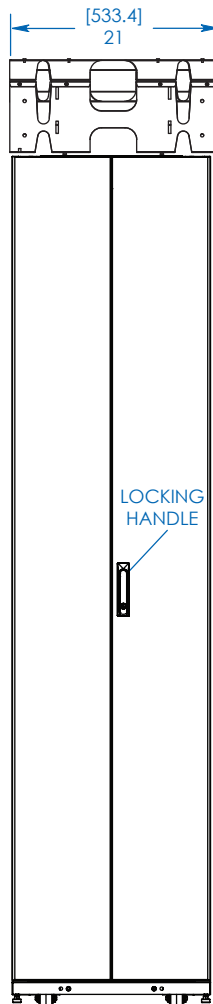

REAR VIEW

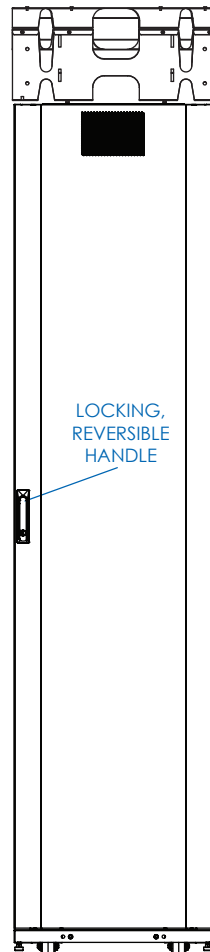

FRONT VIEW

OPTIONAL **SR**CABLETRAY AND **SR**CABLETRAYEXP CABLE MANAGEMENT ACCESSORIES SHOWN (MOUNTING POSITION ADJUSTS TO ACCOMMODATE A WIDE RANGE OF APPLICATIONS)

Model:
SR55UB

TRIPP-LITE
by **EATON**

1111 W. 35th Street
Chicago, IL 60609 USA
773.869.1234
tripplite.com

Dimensions: mm [inches]

We have a policy of continuous improvement. Specifications are subject to change without notice.
Photos and illustrations may differ slightly from actual products.

About Tripp Lite by Eaton

Tripp Lite joined the Eaton family in March 2021. Eaton has long been a premier name in backup power and power management. The acquisition of Tripp Lite transforms Eaton's distributed IT infrastructure and connectivity equipment capabilities. Combining our product strengths and expert personnel allows us to offer comprehensive and innovative solutions for critical power and digital infrastructure applications, backed by quality, service and support you can trust. Learn more at tripplite.com/byEaton.