 


Portable AC Unit for Server Rooms - 24,000 BTU / 7 kW (SRCOOL24KE)



24,000 BTU



Effective Spot Cooling



Non-Locking 6-20P
LCDI Plug with
Leakage Current
Protection




Filters and
Dehumidifies Air





Digital Temperature
Readout

- 1 Front Panel
- 2 Cool Air Outlet
- 3 Top Panel
- 4 Control Panel
- 5 Round-Type Exhaust Duct Adapter
- 6 Exhaust Duct
- 7 Side Panel
- 8 Hot Air Outlet without Exhaust Duct
(see 5 and 6)
- 9 Rear Panel
- 10 Upper Drain Hole (Drainage Plug Installed)
- 11 Cool Air Inlet Grill
- 12 Hot Air Inlet Grill
- 13 Side Panel (Removable with Pre-Installed Filter)
- 14 Lower Drain Hole (Drainage Plug Installed)

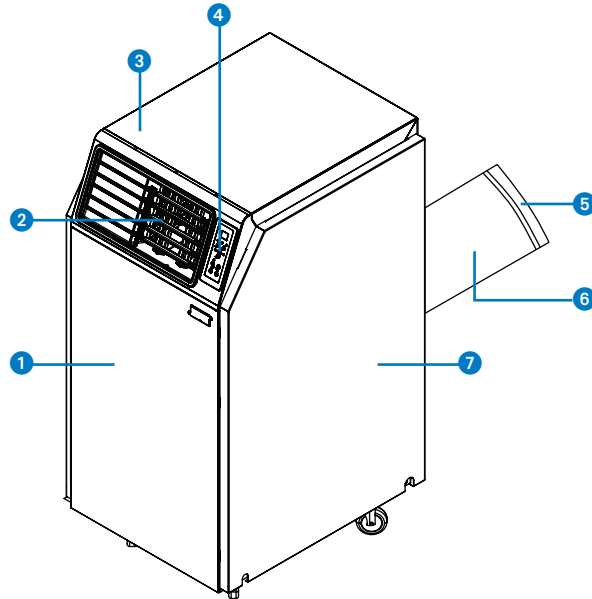


Control Panel


- 1 POWER Button
- 2 FUNCTION Button
- 3 Temperature Control Button
- 4 Temperature Control Button
- 5 Numeric Display
- 6 FAN SPEED Button
- 7 TIMER Button
- 8 QUIET Button

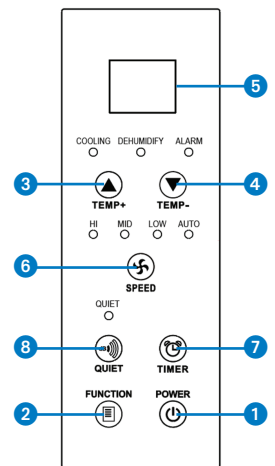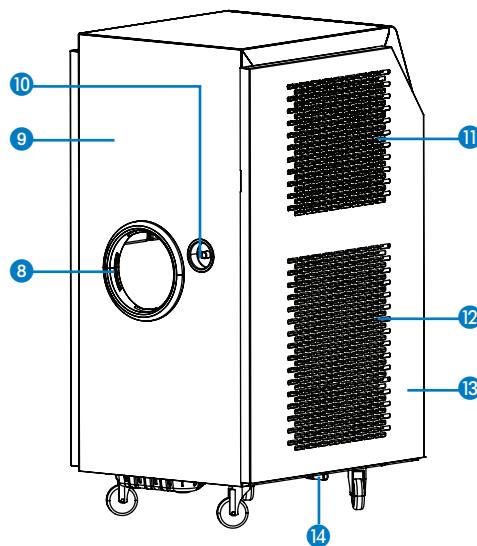


Powering Business Worldwide

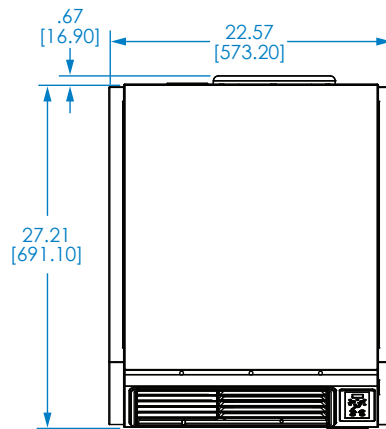


TOP VIEW

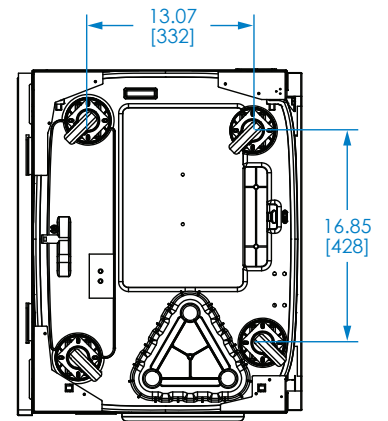


BOTTOM VIEW

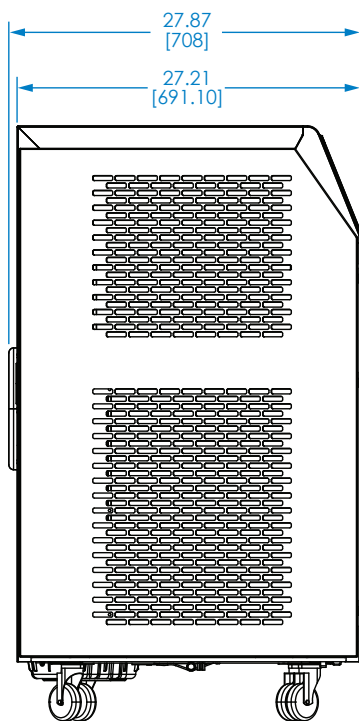

SIDE VIEW

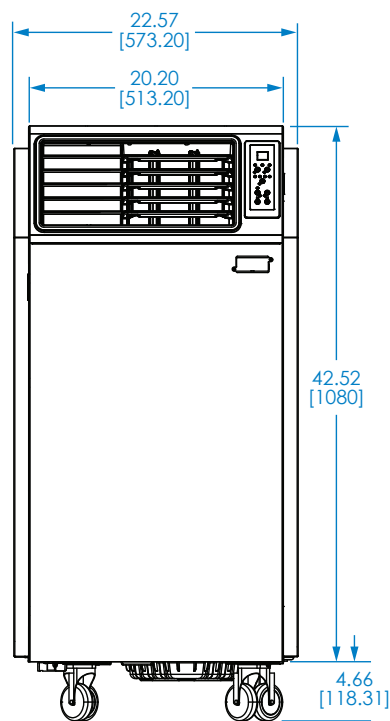

FRONT VIEW

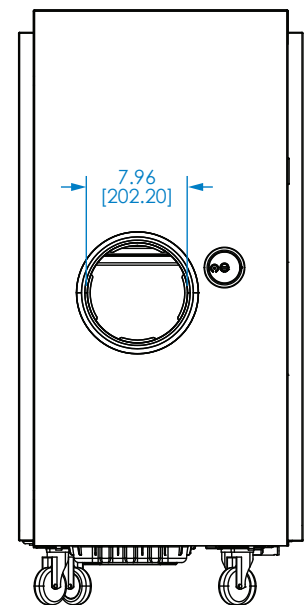

BACK VIEW

Dimensions: INCHES [mm]

Learn more at **Eaton.com**



Powering Business Worldwide

Eaton
1000 Eaton Boulevard
Cleveland, OH 44122
United States
Eaton.com

© 2025 Eaton
All Rights Reserved
Publication No. 24-11-156
June 2025

No part of this document may be reproduced in any way without the express written approval of Eaton.

Eaton reserves the right to change specifications without prior notice. Eaton is a registered trademark of Eaton. All other trademarks are properties of their respective companies.

Follow us on social media to get the latest product and support information.

