

SmartRack 42U Extra-Deep, Extra-Wide Heavy-Duty Rack Enclosure Cabinet, White (SRH423254W)



42 Rack Units



5000 lb.
Stationary
Load Rating



3500 lb.
Rolling
Load Rating



Heavy-Duty
Casters



Locking
Doors
& Side
Panels



Accommodates
Standard
19-inch
Equipment




Toolless
Mounting
Slots



Adjustable
Rails with
Easy-View
Depth Index



Airflow
Exceeds
Server OEM
Requirements

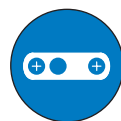


Integrated
Baying Tabs



Square Hole
Mounting

- A Adjustable Mounting Rails**
- B Adjustable PDU Mounting Rails with Toolless Mounting Slots**
- C Roof Panel** (Removable)
- D Front Door**
(Lockable/Removable/Reversible)
- E Split Rear Doors**
(Lockable/Removable)
- F Side Panels**
(Lockable/Removable)
- G Heavy-Duty Casters**
- H Heavy-Duty Levelers**
- I Keys** (For doors and side panels)

Also Includes: Owner's manual, 2 stabilizing brackets and rackmount equipment mounting hardware (50 cage nuts, 50 mounting screws, 50 nylon cup washers)

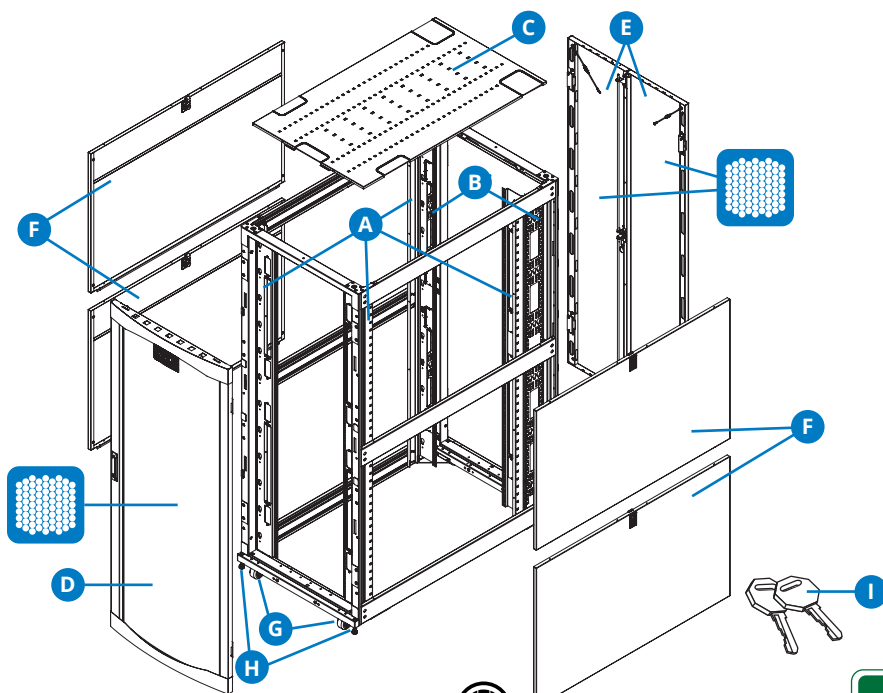


SPECIFICATIONS

Model	SRH423254W
Rack Spaces	42U
Stationary Load Rating	5000 lb. / 2268 kg
Rolling Load Rating	3500 lb. / 1588 kg
Unit Dimensions [H x W x D]	79.64 x 31.5 x 57.91 in. / 2023 x 800 x 1471 mm
Shipping Dimensions [H x W x D]	86.5 x 43.5 x 60 in. / 2197 x 1105 x 1524 mm
Unit Weight	560 lb. / 254 kg
Certifications	UL 2416, CSA C22.2 No 62368-1, IEC 60297-3-100, DIN 41494, IP20, TIA/EIA-310-D (Accommodates all standard 19-inch rackmount equipment regardless of vendor.)

* Part numbers and specifications are subject to change.



Powering Business Worldwide

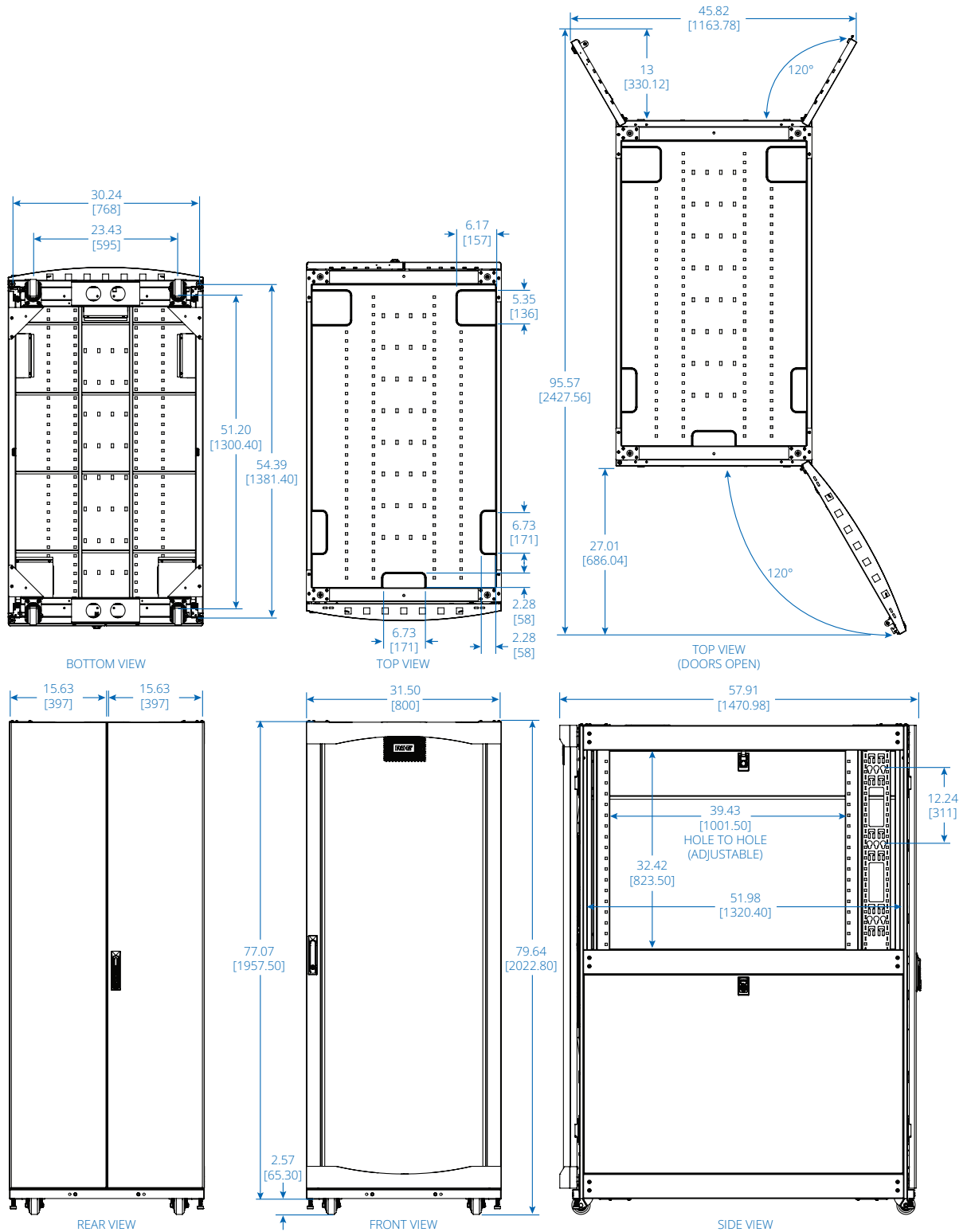

Dimensions: INCHES [mm]

Learn more at [Tripplite.Eaton.com](https://www.Tripplite.Eaton.com)



Powering Business Worldwide

Eaton
1000 Eaton Boulevard
Cleveland, OH 44122
United States
[Eaton.com](https://www.eaton.com)

© 2024 Eaton
All Rights Reserved
Publication No. 24-06-030
August 2024

No part of this document may be reproduced in any way without the express written approval of Eaton.

Eaton reserves the right to change specifications without prior notice. Eaton is a registered trademark of Eaton. All other trademarks are properties of their respective companies.

Follow us on social media to get the latest product and support information.

