

# SmartRack 48U Extra-Wide Heavy-Duty Rack Enclosure Cabinet, White (SRH483242W)



48 Rack Units



5000 lb. Stationary Load Rating



3500 lb. Rolling Load Rating



Heavy-Duty Casters



Locking Doors & Side Panels



 
Accommodates Standard 19-inch Equipment




Toolless Mounting Slots



Adjustable Rails with Easy-View Depth Index



Airflow Exceeds Server OEM Requirements

 


Integrated Baying Tabs



Square Hole Mounting

- A Adjustable Mounting Rails**
- B Adjustable PDU Mounting Rails with Toolless Mounting Slots**
- C Roof Panel** (Removable)
- D Front Door** (Lockable/Removable/Reversible)
- E Split Rear Doors** (Lockable/Removable)
- F Side Panels** (Lockable/Removable)
- G Heavy-Duty Casters**
- H Heavy-Duty Levelers**
- I Keys** (For doors and side panels)

Also Includes: Owner's manual, 2 stabilizing brackets and rackmount equipment mounting hardware (50 cage nuts, 50 mounting screws, 50 nylon cup washers)

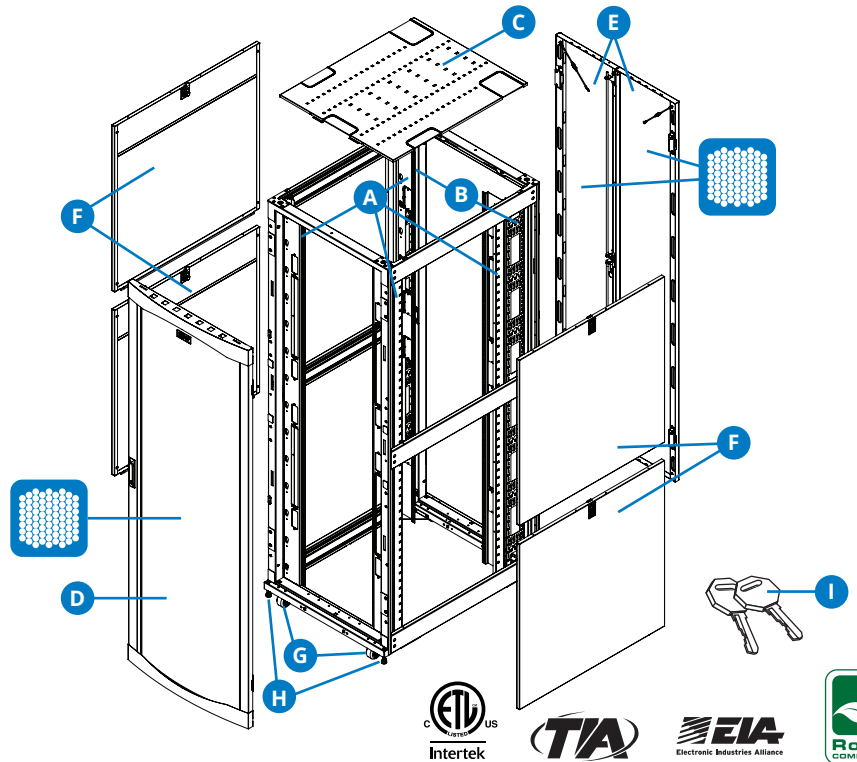

## SPECIFICATIONS

<b>Model</b>	<b>SRH483242W</b>
Rack Spaces	48U
Stationary Load Rating	5000 lb. / 2268 kg
Rolling Load Rating	3500 lb. / 1588 kg
Unit Dimensions [H x W x D]	90.16 x 31.50 x 44.09 in. / 2290 x 800 x 1119.78 mm
Shipping Dimensions [H x W x D]	96.5 x 43.5 x 45 in. / 2451 x 1105 x 1143 mm
Unit Weight	478 lb. / 216.8 kg
Certifications	UL 2416, CSA C22.2 No 62368-1, IEC 60297-3-100, DIN 41494, IP20, TIA/EIA-310-D (Accommodates all standard 19-inch rackmount equipment regardless of vendor.)

\* Part numbers and specifications are subject to change.



Powering Business Worldwide



**2**