

MODEL:

TLP128TTUSBB

Protect It!® 12-Outlet Surge Protector with USB Charging

4320
JOULES

4320 Joule Rating



12 Outlets



[2.1A] 2 USB
Charging Ports



Tel/Coax Protection




\$150K Ultimate
Lifetime Insurance



Lifetime
Warranty

- A** NEMA 5-15R Surge-Protected Outlets (12)
(4320 Joule Rating)
 - B** "PROTECTED" LED Light Bar
 - C** "GROUNDED" LED Light Bar
 - D** ON/OFF Switch with Integrated Circuit Breaker
 - E** USB Charging Ports (2)
(2.1A Total)
 - F** Coaxial Surge-Protected Connectors
 - G** RJ11 Surge-Protected Jacks
 - H** 8 ft. (2.4 m) Input Power Cord with NEMA 5-15P Right-Angle Plug
- Also Includes: Owner's manual.

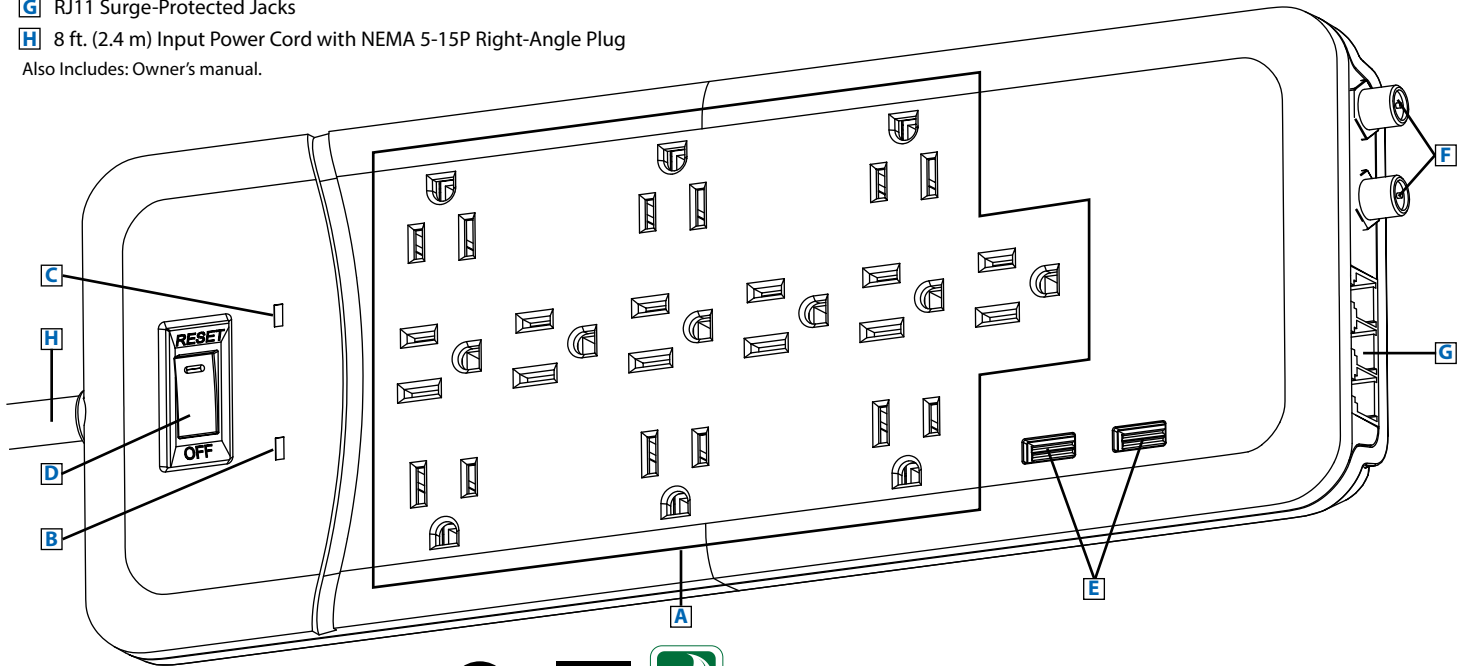

Specifications


Model	TLP128TTUSBB
Input Voltage	120V AC, 50/60 Hz
Outlets	(12) 5-15R
Plug Type/Cord Length	5-15P Right-Angle / 8 ft. (2.4 m)
Max Output	1800W
Output Amperage	15A
USB Charging Ports	2x USB-A (2.1A Total)
LED Indicators	Ground OK (Red); Protected (Green)
Switch Type	On/Off Rocker
Surge Protection Rating	4320 Joules
Protection Modes	Includes full normal mode (H-N) and common mode (N-G / H-G)
Unit Dimensions [H x W x D]	4.86 x 9.55 x 1.51 in. (123 x 243 x 38 mm)
Shipping Dimensions [H x W x D]	15.94 x 8.07 x 1.77 in. (405 x 205 x 45 mm)
Unit Weight	1.9 lb. (0.86 kg)
Shipping Weight	2.17 lb. (0.98 kg)
Standards	Tested to UL1449 3rd Ed., UL1363; UL497A, FCC Part 68; Industry Canada; Meets NOM (Mexico) and RoHS standards

- 4320 joules protect your valuable electronics against dangerous surges/spikes/line noise
- RJ11 and coaxial cable connectors protect phone/fax/modem/cable/satellite equipment
- 2 USB ports share 2.1A for fast charging of phone, laptop and other mobile devices


SEE NEXT PAGE FOR DETAILED UNIT MEASUREMENTS




1111 W. 35th Street
Chicago, IL 60609 USA
773.869.1234
www.tripplite.com

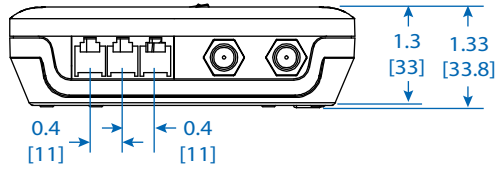


END VIEW

 


SIDE VIEW

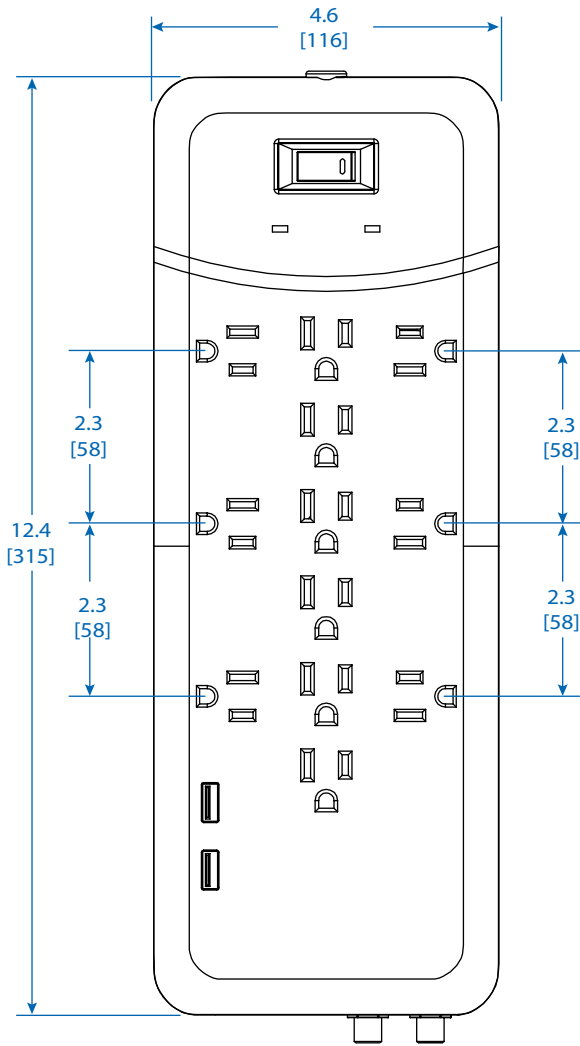

TOP VIEW

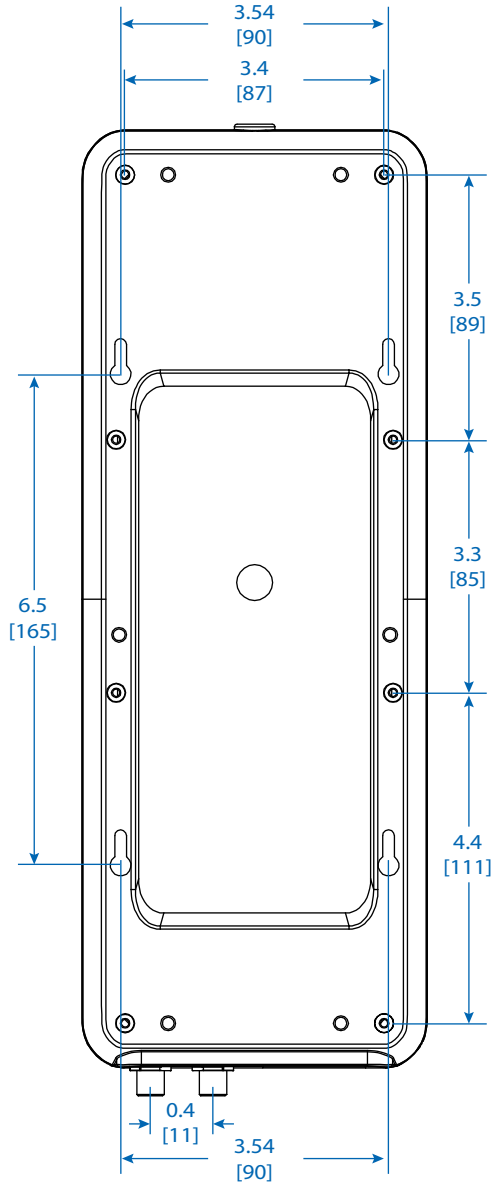

BOTTOM VIEW

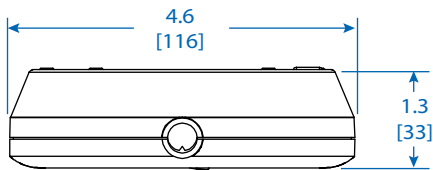

END VIEW

MODEL:
TLP128TTUSBB



1111 W. 35th Street
Chicago, IL 60609 USA
773.869.1234
www.tripplite.com

Dimensions: INCHES [mm]

Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.