

MODEL:

TLP66USBR

Protect It!® 6-Outlet Surge Protector with USB Charger

1080
JOULES

1080 Joule Rating



6 Outlets



4 USB
Charging Ports



Conforms to current
UL 1449 3rd Edition
safety standards



\$50K Ultimate
Lifetime Insurance




Lifetime
Warranty

A NEMA 5-15R Surge Protected Outlets (6)
(1080 Joule Rating)

B USB Charging Ports (4)
(Up to 3.4A total)

C 6 ft. (1.8 m) Input Power Cord
NEMA 5-15P Input Plug (Not Shown)

Also Includes: Owner's manual.

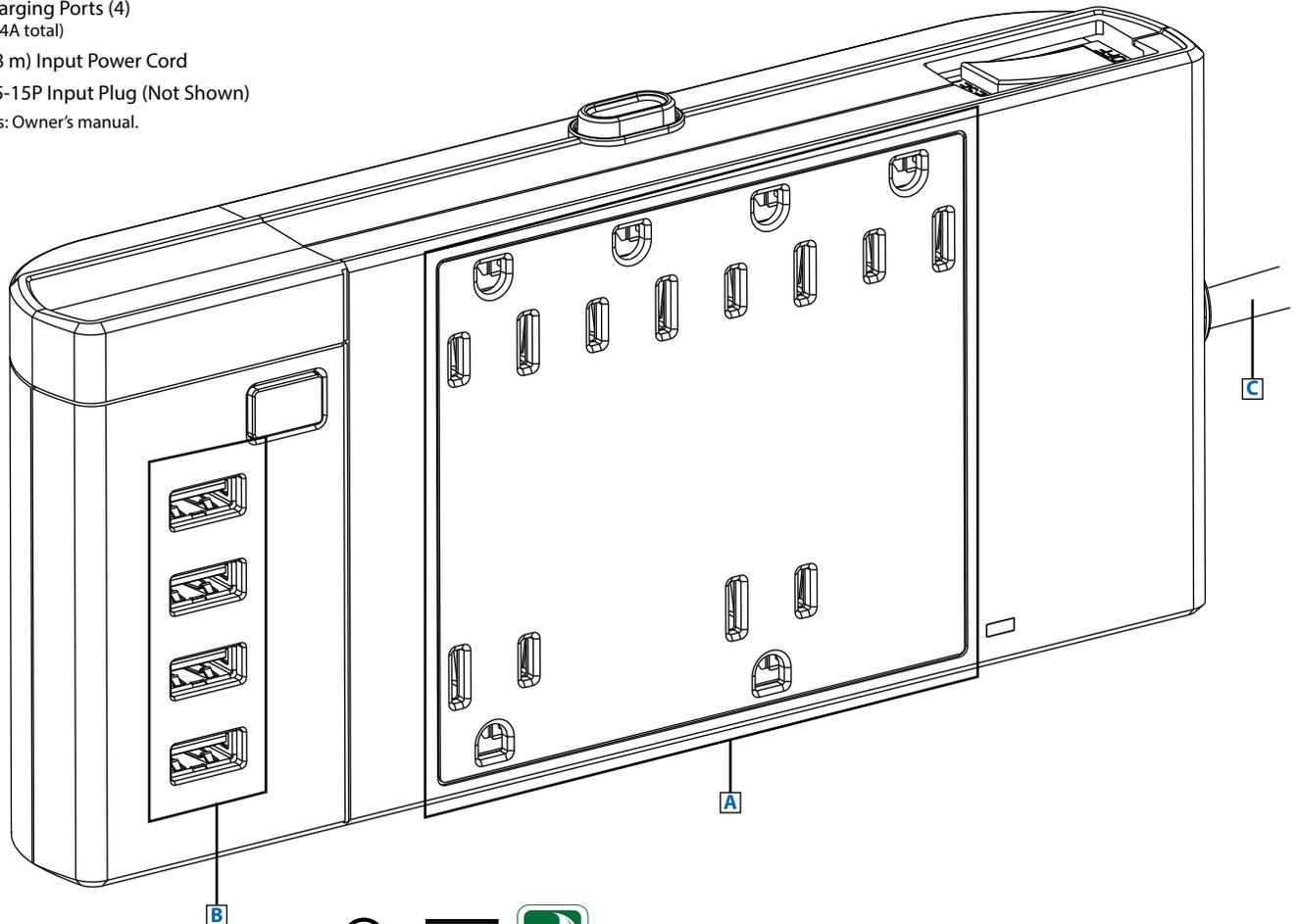

Specifications

Model	TLP66USBR
Input Voltage	120V, 60 Hz
Outlets	(6) 5-15R
Plug Type/Cord Length	5-15P / 6 ft. (1.8 m)
Max Output Watts	1800W
Output Amperage	15A
Surge Protection Rating	1080 Joules
Unit Dimensions (H x W x D)	8.3 x 3.6 x 1.4 in. / 211 x 91 x 36 mm
Shipping Dimensions (H x W x D)	9.7 x 6.7 x 1.8 in. / 246 x 170 x 46 mm
Unit Weight	1.6 lb. / 0.7 kg
Shipping Weight	1.8 lb. / 0.8 kg
Standards	Certified to UL 1449 & UL 962A; Meets NOM & RoHS Standards






- Conforms to current UL 1449 3rd Edition safety standards.
- In-desk (flush-mount) or under/on-desk mounting options

SEE NEXT PAGE FOR DETAILED UNIT MEASUREMENTS



1111 W. 35th Street
Chicago, IL 60609 USA
773.869.1234
www.tripplite.com

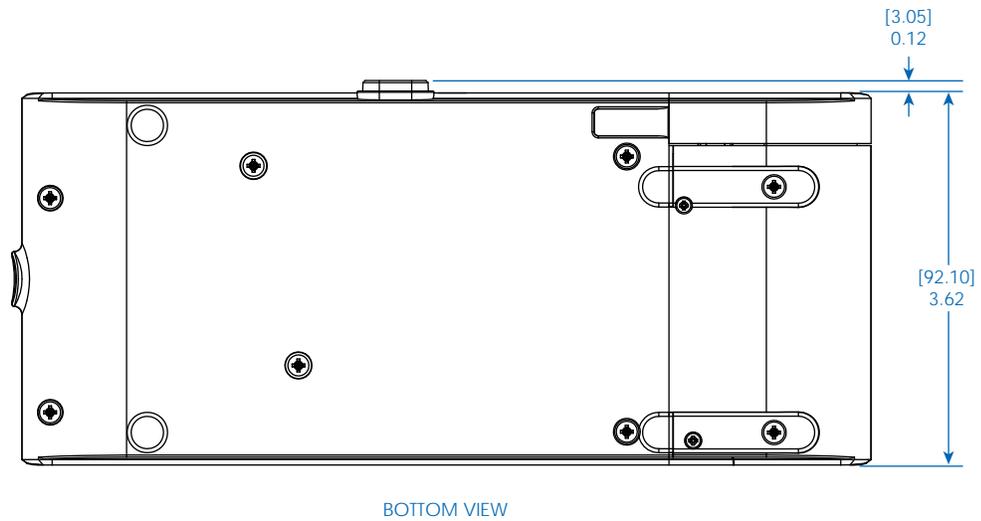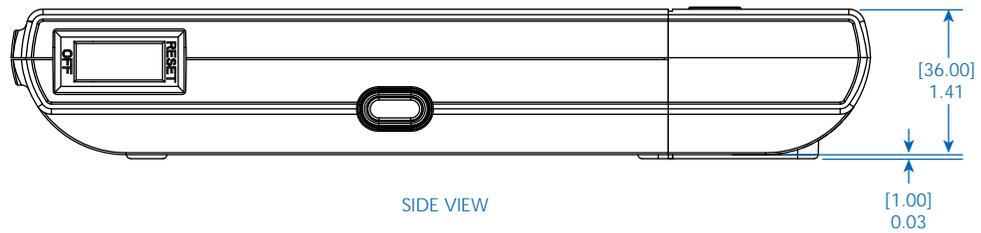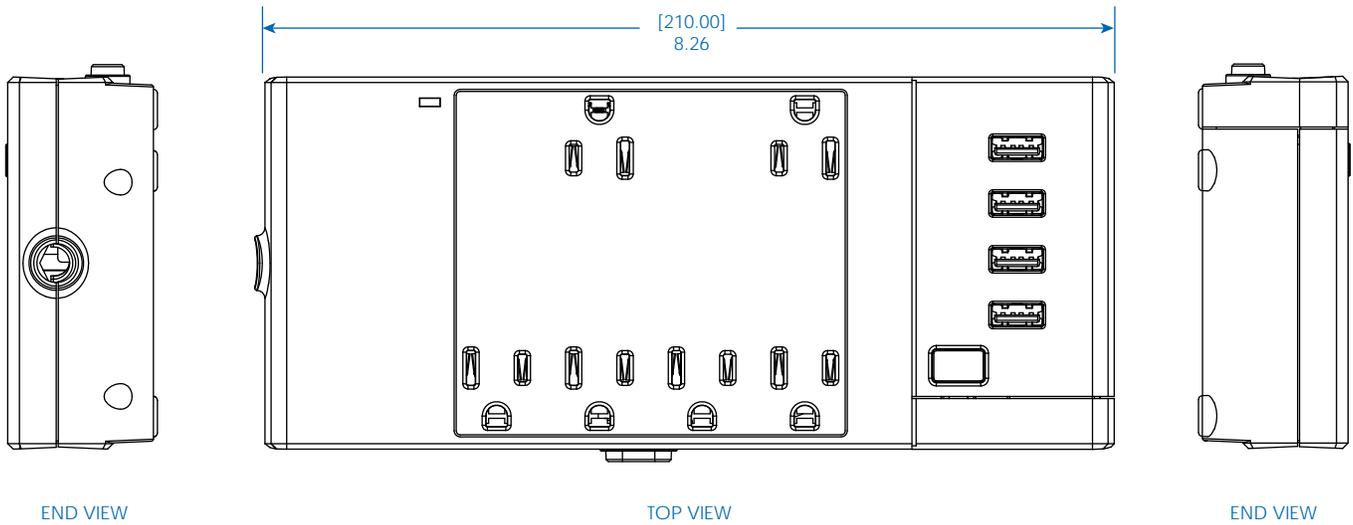

Dimensions: [mm] INCHES

Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.

MODEL:
TLP66USBR

TRIPP-LITE

1111 W. 35th Street
Chicago, IL 60609 USA
773.869.1234
www.tripplite.com