

MODEL:

TLP76MSGB

ECO-Surge 7-Outlet Surge Protector, 6 Individually Controlled Outlets, Black Housing

1080
JOULES

1080 Joule Rating



7 Outlets



Conforms to current
UL 1449 3rd Edition
safety standards.



\$25,000 Ultimate Lifetime
Insurance





Lifetime Limited
Warranty

- A** Six Energy-Saving Outlets
- B** One "Always On" Outlet
- C** 6-ft. Input Power Cord
- D** NEMA 5-15P Input Plug

Package Includes:

- TLP76MSGB ECO-Surge 7-Outlet Surge Protector
- Owner's manual

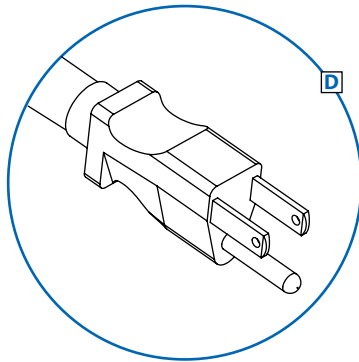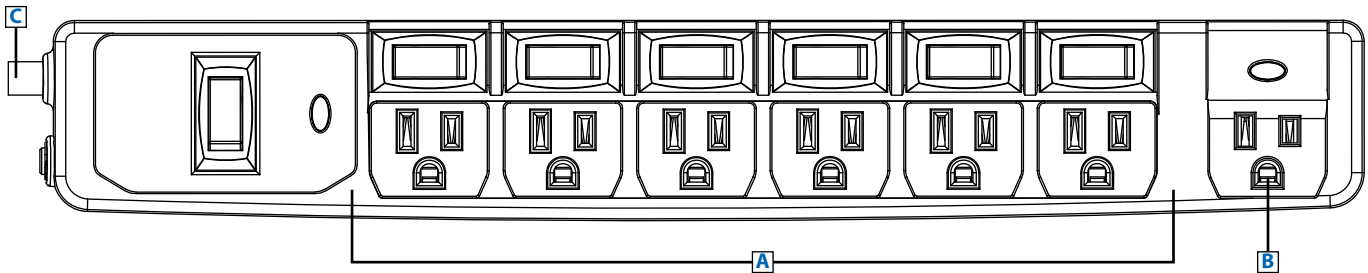

- Conforms to current UL 1449 3rd Edition safety standards
- Keyhole slots on bottom panel provide convenient wall or desk mounting options





SEE NEXT PAGE FOR DETAILED UNIT MEASUREMENTS

Specifications

Model	TLP76MSGB
Unit Dimensions (H x W x D)	1.4 x 3.4 x 15 in. / 35.6 x 86.4 x 381 mm
Shipping Dimensions (H x W x D)	2 x 4.2 x 17.1 in. / 50.8 x 106.6 x 434 mm
Unit Weight	1.54 lb. / 0.7 kg
Shipping Weight	1.80 lb. / 0.8 kg
Standards	Certified to UL 1449 & UL 1363; Meets NOM & RoHS Standards



1111 W. 35th Street
Chicago, IL 60609 USA
773.869.1234
www.tripplite.com

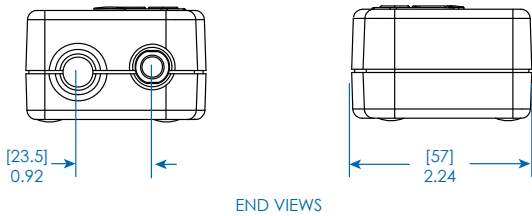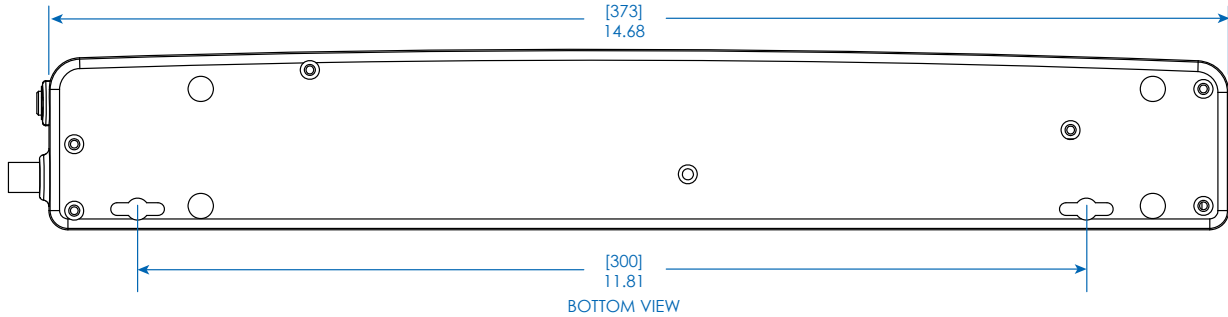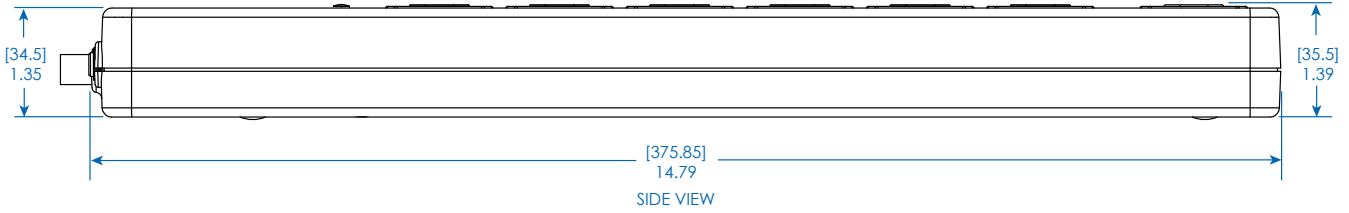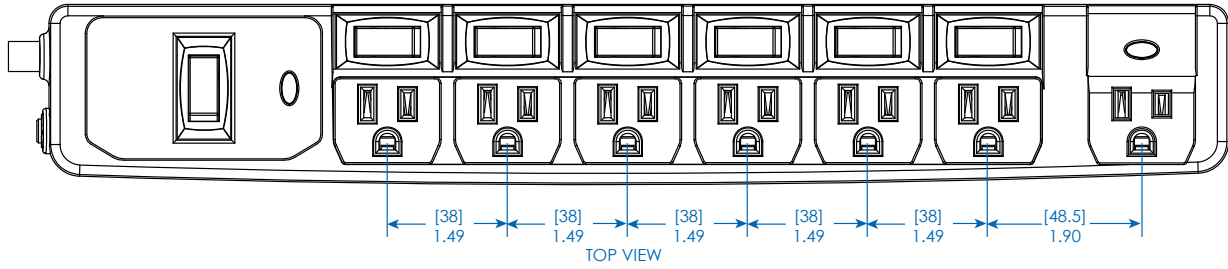

Dimensions: [mm] INCHES

Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.

